


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

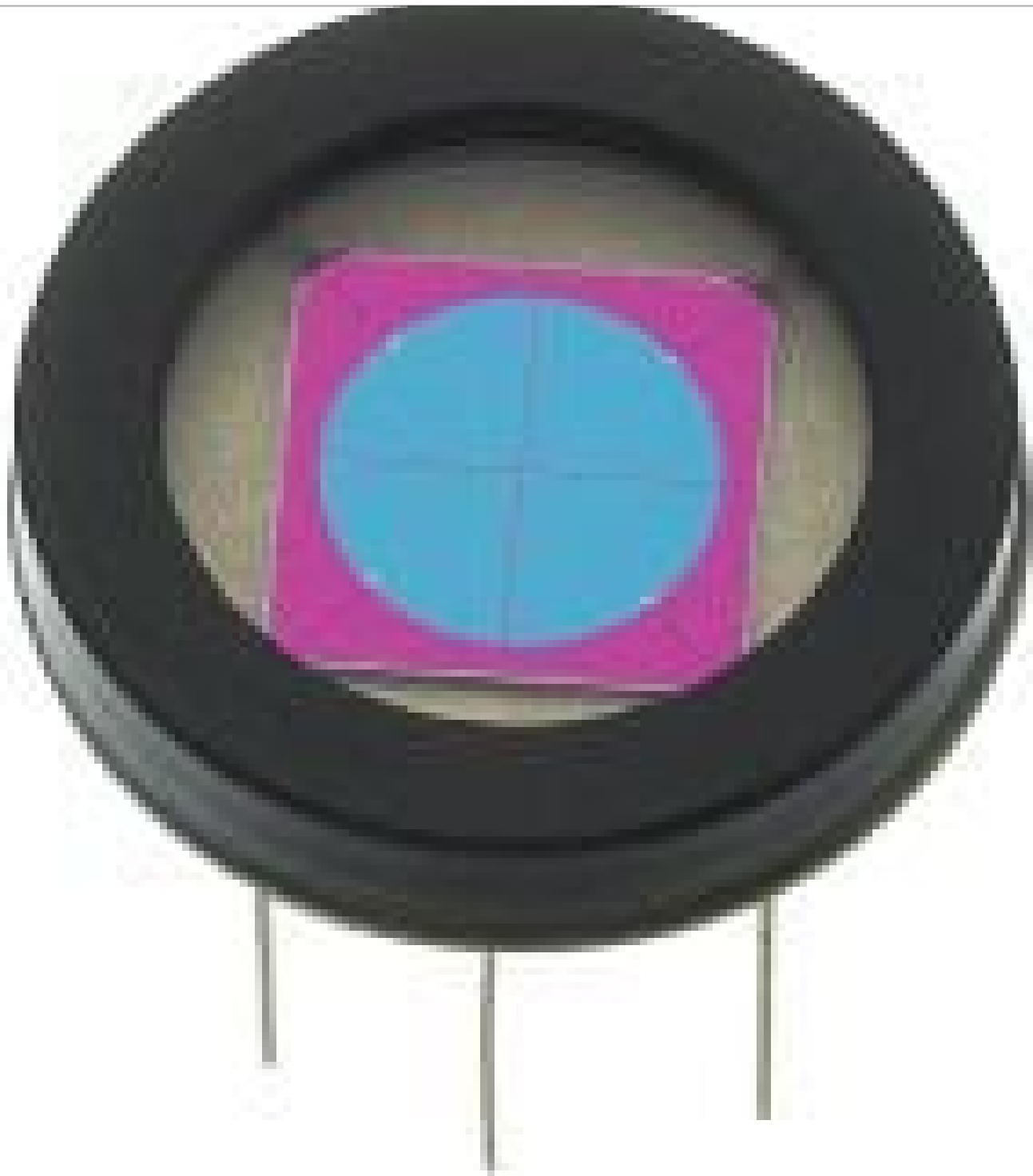

Stock #84-614 3-4 DAYS



1



€58,00

ADD TO CART

Qty 1-4

€58,00

Qty 5+

€50,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Operating Temperature (°C):

-40 to 100

Size of Active Area (mm):

0.5 x 0.5

Storage Temperature (°C):

-55 to 125

Rise Time (ns):

3.00
Responsivity @ 970nm (AW): Minimum: 0.6 Typical: 0.65
Capacitance @ V_R=-10V (pF): 1.00
Active Area (mm²): 0.25
Noise Equivalent Power NEP (W/ Hz^{1/2}): 2.8 x 10 ⁻¹⁵ @ -10 V, 970nm
Maximum Reverse Voltage (V): 30.00
Model Number: SPOT-4DMI
Connector: 41 / TO-5
Dark Current @ V_R=-10V (nA): Maximum: 0.5 Typical: 0.01
Element Gap (mm): 0.013

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View