


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

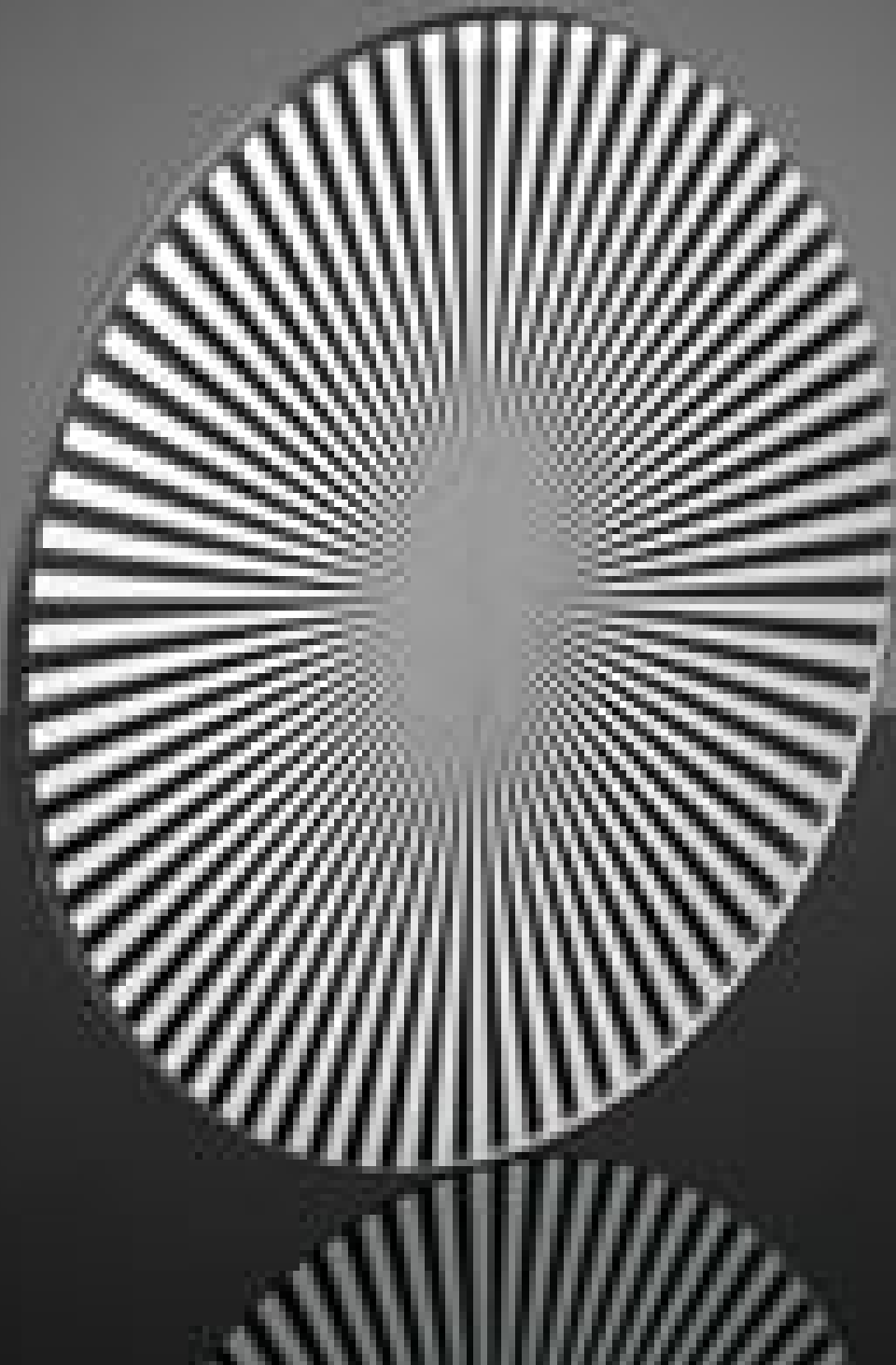

Glass Star Target

Stock #58-832 3-4 DAYS



1



€435,00

ADD TO CART

Qty 1-4

€435,00

Qty 5+

€413,60

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
Physical Vapor Deposition (Chromium Coating)

Diameter (mm):
60.00 ±0.1

Frequency (lp/mm):
0.229 - 114.6

Substrate: Float Glass
Line Width (mm): 2.2 - 0.004
Number of Sectors: 36
Optical Density OD (Average): >3.5
Pattern Diameter (mm): 50.00
Thickness (mm): 1.50 ±0.05
Wedge Angle: 10°
Unresolved Core Diameter (mm): 0.1
NIST Certification: No

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View