


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 10mm Diameter, Aluminum Coated, Cone Mirror

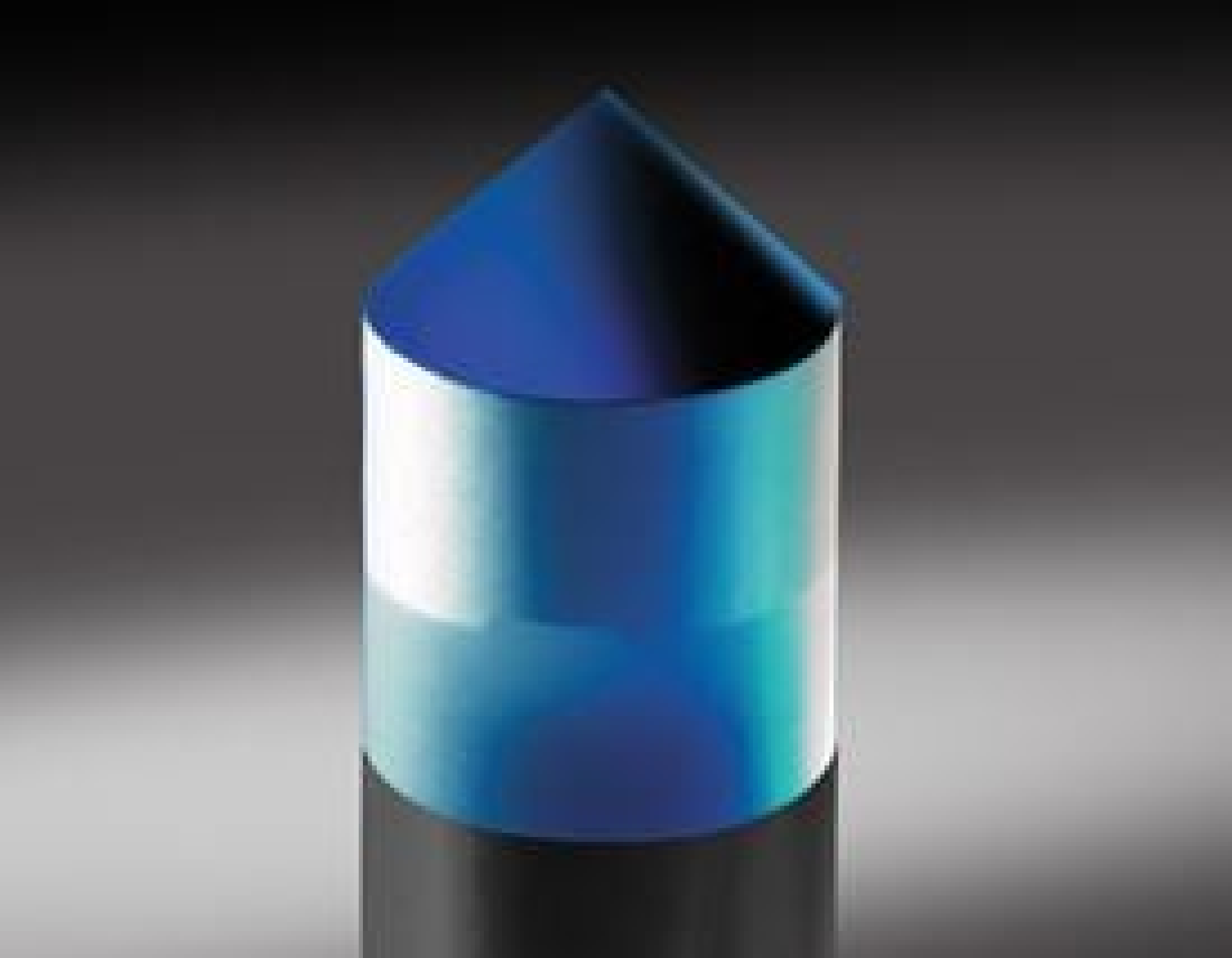

Stock #45-939 3-4 DAYS



1



€377,50

ADD TO CART

Qty 1-5

€377,50

Qty 6+

€302,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):  
10.00 +0.00/-0.05

Length (mm):  
10.00

Angle Tolerance (arcmin):  
±6

Coating:

|                                                                     |
|---------------------------------------------------------------------|
| Protected Aluminum (400-700nm)                                      |
| <b>Coating Specification:</b><br>R <sub>avg</sub> >85% @400 - 700nm |
| <b>Coating Type:</b><br>Metal                                       |
| <b>Length Tolerance (mm):</b><br>±0.1                               |
| <b>Substrate:</b> <input type="checkbox"/><br><a href="#">N-BK7</a> |
| <b>Surface Quality:</b><br>40-20                                    |
| <b>Total Length (mm):</b><br>15.0                                   |
| <b>Type:</b><br>Specialty Mirror                                    |
| <b>Wavelength Range (nm):</b><br>400 - 700                          |
| <b>Note:</b><br>Coating on Cone Surface                             |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 219:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |

---