


1200 Grooves, 12.7mm Square, 1000nm NIR Ruled Grating

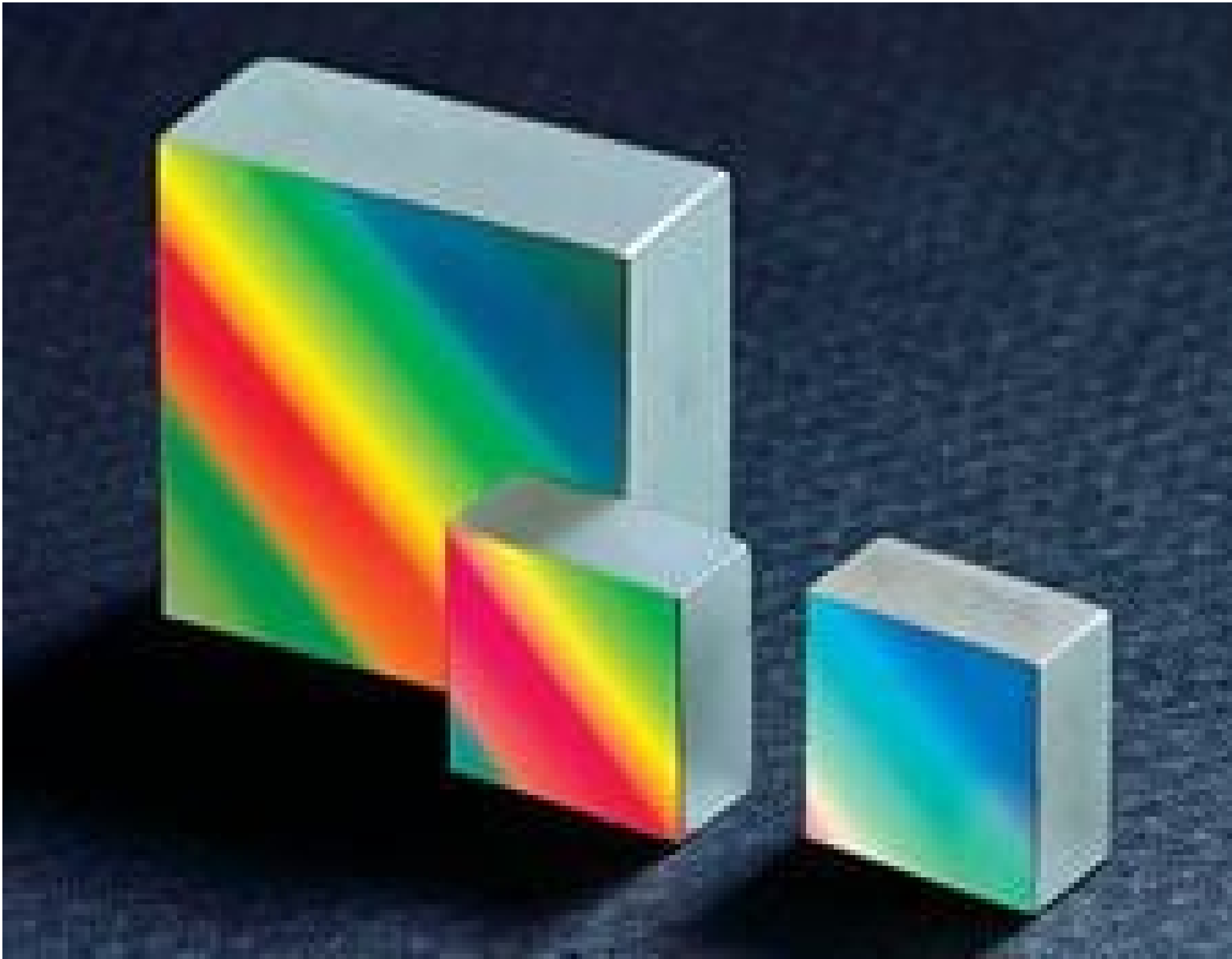

Stock #43-851 3-4 DAYS

- 1 + **€135,00**

ADD TO CART

Qty 1+
€135,00

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm): 1200
Wavelength Range (nm): 700 - 3000
Blaze Wavelength (nm): 1000
Blaze Angle (°): 36.87

Dimensions (mm): 12.7 x 12.7 ±0.5
Clear Aperture (%) : 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 12.70
Substrate: ☐ Float Glass
Thickness (mm): 6.00 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 12.70
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View