


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

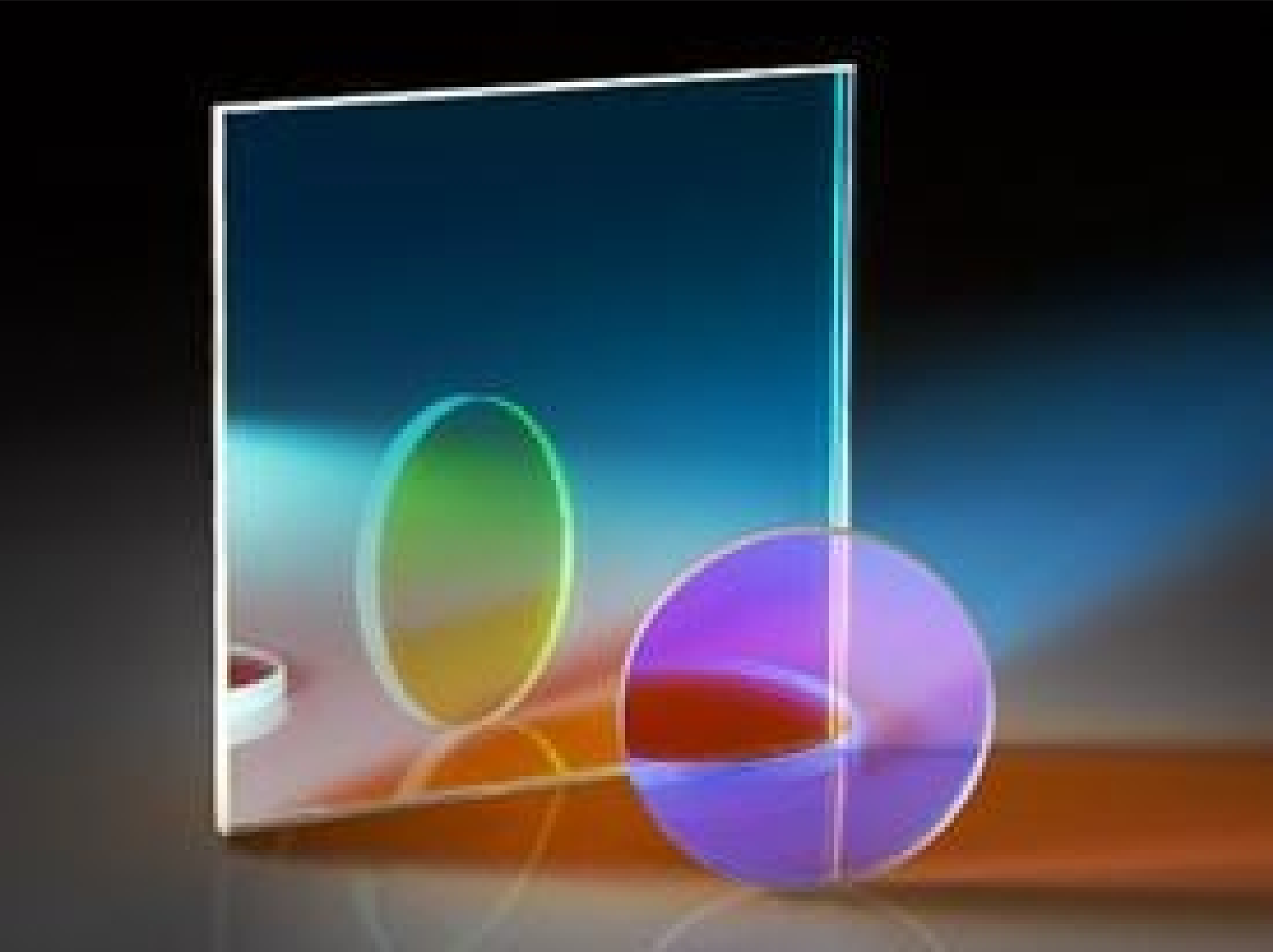

Additive and Subtractive Dichroic Color Filters

Stock #52-542 ■ In Stock



1



€22,00

ADD TO CART

Qty 1-24

€22,00

Qty 25+

€19,50

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.50

Angle of Incidence (°):
0

Cut-On Wavelength (nm):
520.00

Substrate:  BOROFLOAT®
Operating Temperature (°C): <100
Coating: Subtractive Color
Color: Yellow
Surface Quality: 80-50
Thickness (mm): 2.00 Nominal
Type: Dichroic Filter
Dimensional Tolerance (mm): ±0.25
Clear Aperture (%): ≥85
Cut-On Wavelength Tolerance (µm): 0.015
Coating Specification: T _{avg} <1.0% @ 400 - 475nm T _{avg} >80% @ 550 - 750nm

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant