


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

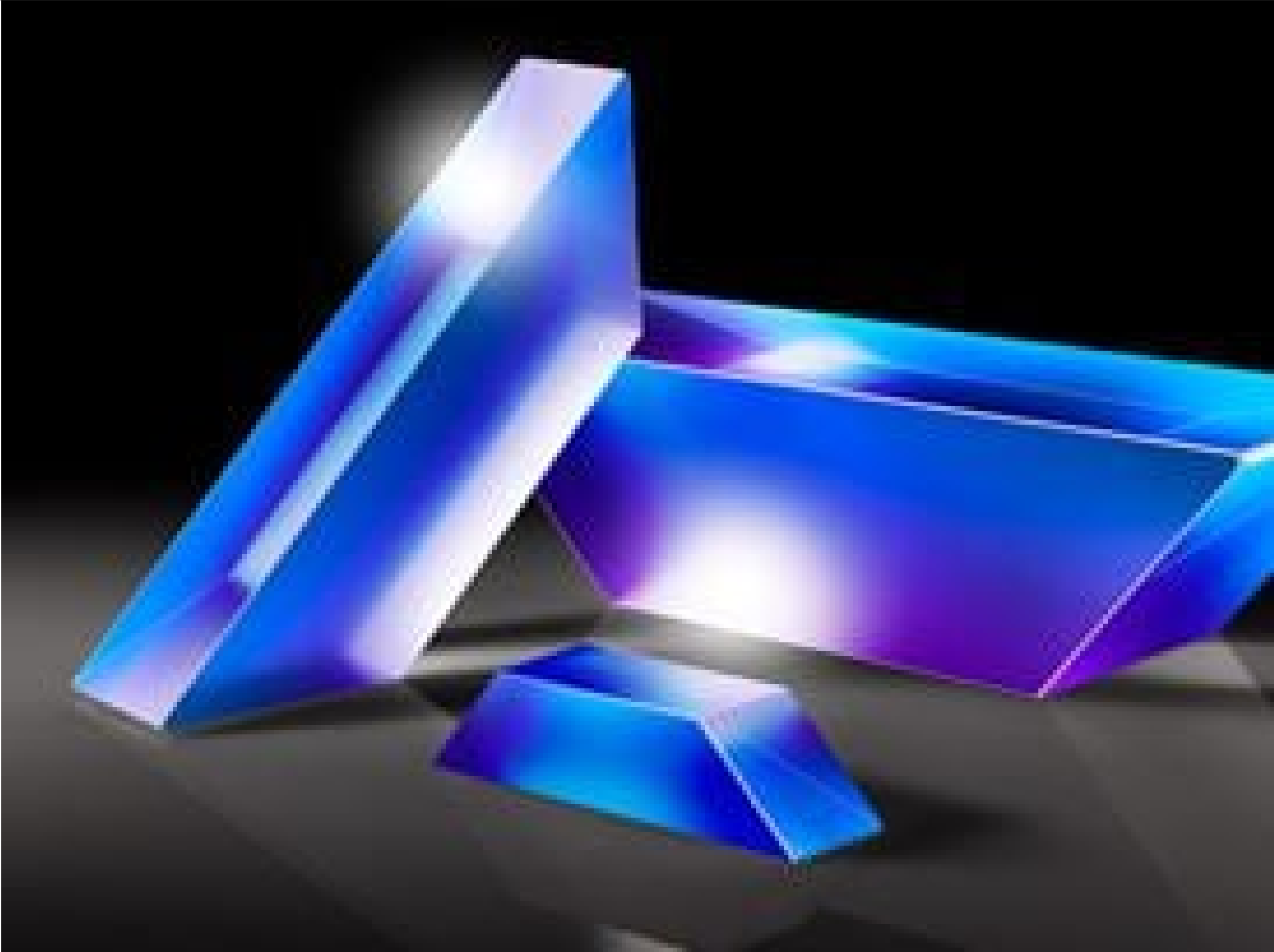

Stock #49-427 3-4 DAYS



1



€155,00

ADD TO CART

Qty 1-5

€155,00

Qty 6+

€139,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
VIS 0° (425-675nm)

Substrate:
[N-BK7](#)

Height (mm):
18.0

Length (mm): 74.60
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2.00
Bevel: Protective bevel as needed
Image Orientation: Left-Handed
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 0
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)
Damage Threshold, Reference: ☐ 5 J/cm² @ 532nm, 10ns
Power (fringes) @ 632.8nm: 0.50
Irregularity (fringes) @ 632.8nm: 0.25

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant