


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

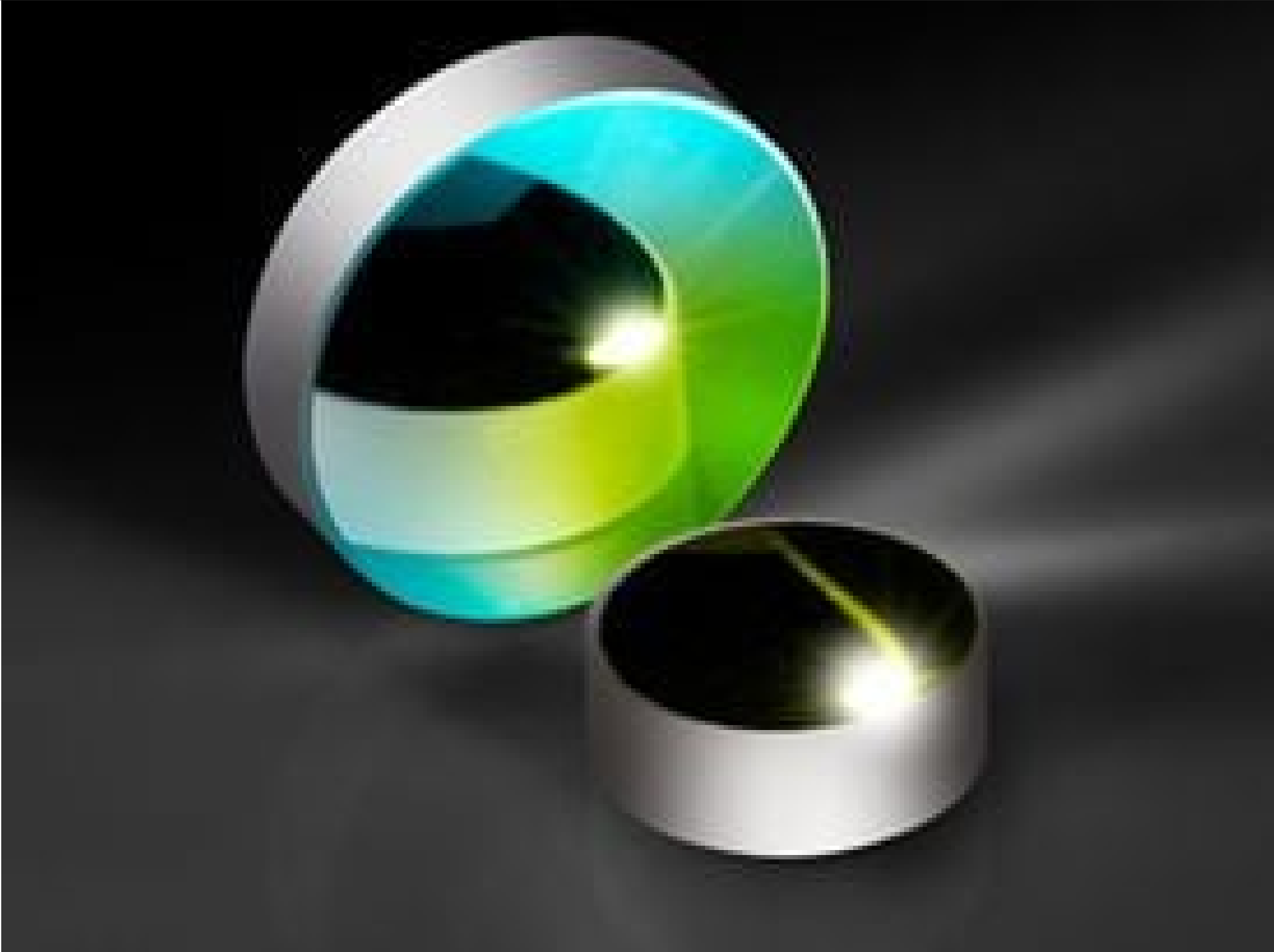

Stock #46-239 3-4 DAYS



1



€46,50

ADD TO CART

Qty 1-49

€46,50

Qty 50+

€42,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate: ☐

[N-BK7](#)

Focal Length Tolerance (%):

±2

Surface Quality:

60-40

Surface Accuracy:

N/4
Diameter (mm): 20.00 +0.00/-0.30
Effective Focal Length EFL (mm): 80.00
Radius of Curvature (mm): 160.00
Aperture (f/#): f/4
Coating: Protected Aluminum (400-2000nm)
Coating Specification: R _{avg} >85% @400 - 700nm R _{avg} >90% @400 - 2000nm
Coating Type: Metal
Back Surface: Ground
Center Thickness CT (mm): 3.00
Center Thickness Tolerance (mm): ±0.30
Edge Thickness ET (mm): 3.31
Edges: Ground
Radius R (mm): 160.0
Type: Spherical Mirror
Wavelength Range (nm): 400 - 2000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant