


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

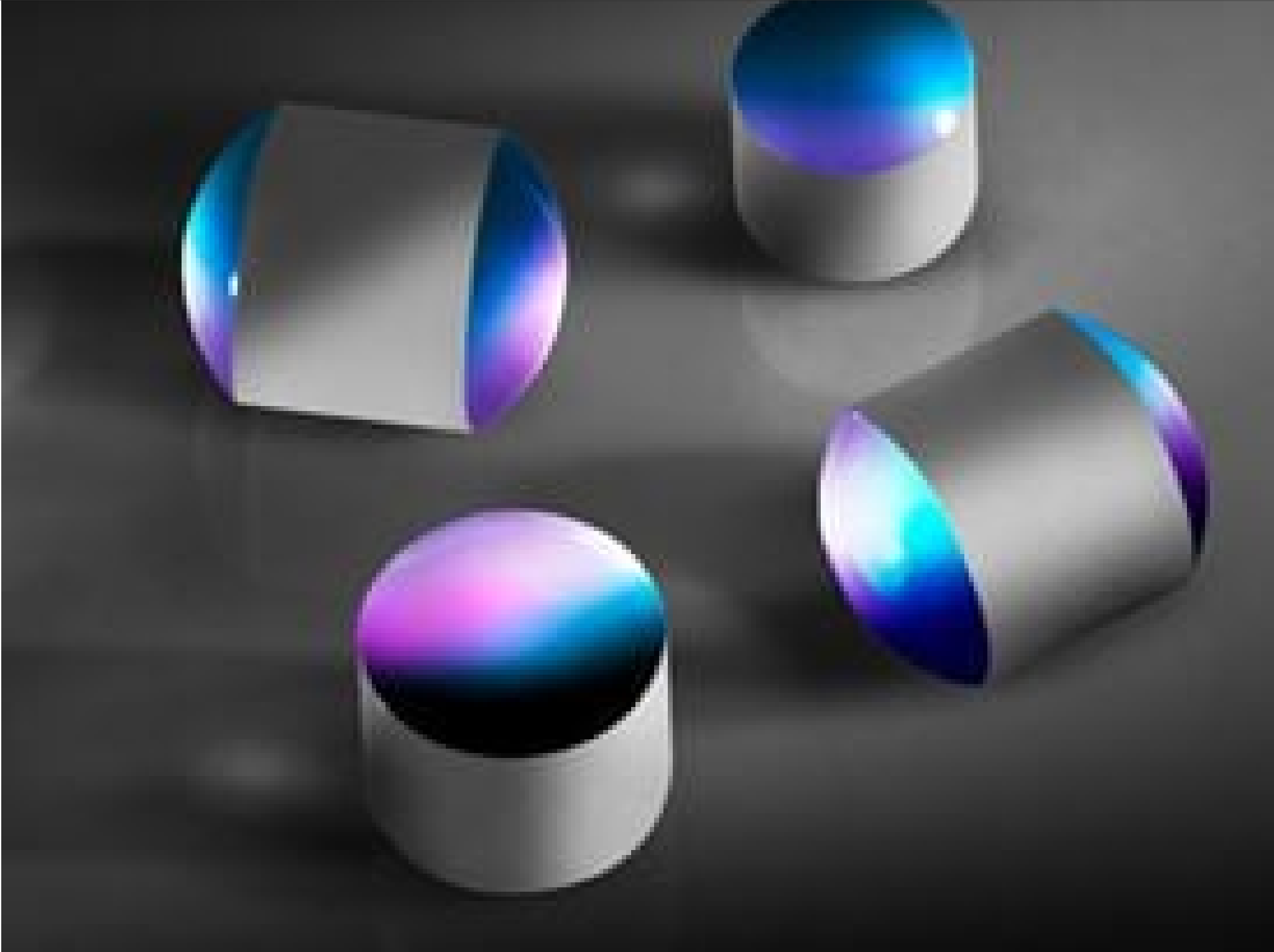

Stock #46-524 CLEARANCE 3-4 DAYS

- 1 +

€19,95

ADD TO CART

Qty 1+

€19,95

Volume Pricing

[Request Quote](#)

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
2.00

Substrate: ☐
[N-BK7](#)

Coating:
Uncoated

Type:
Half-Drum Lens

Wavelength Range (nm): 350 - 2200
Index of Refraction n_d: 1.517
Length (mm): 2.00
Length Tolerance (μm): ± 30
Radius R (mm): 1.25
Radius Tolerance (μm): $+0/-1.5$
Surface Quality: 40-20
Diameter Tolerance (μm): $+0/-50$

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View