


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

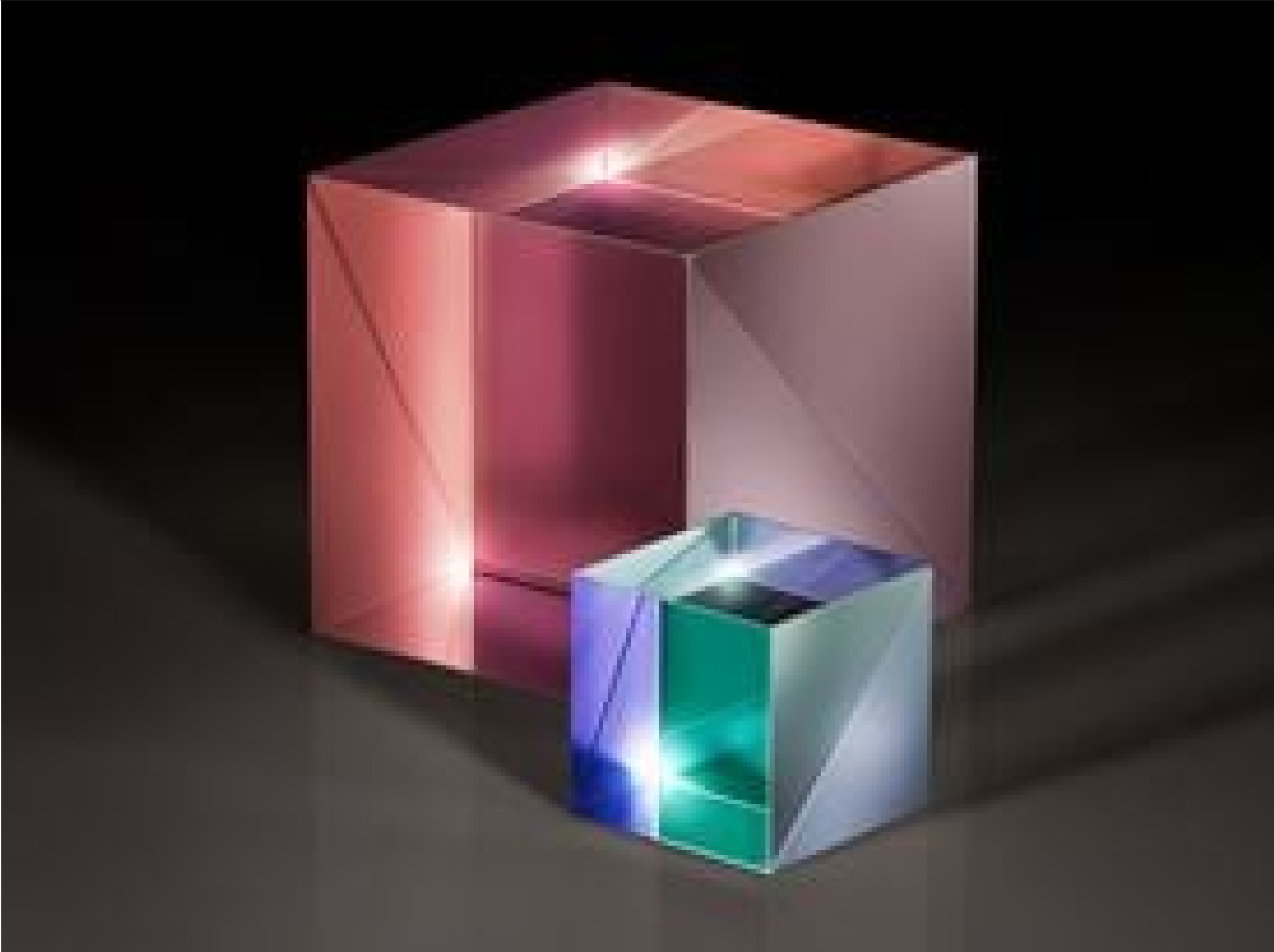

Laser Line Non-Polarizing Cube Beamsplitters



Stock **#35-960** ☐ In Stock



1



€276,00

ADD TO CART

Qty 1-5

€276,00

Qty 6+

€221,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Beam Deviation (arcmin):
±2

Bevel:
Protective as needed

Clear Aperture (%) : 90
Coating Specification : <0.25% Reflection on Entrance and Exit Faces
Construction : Cube
Design Wavelength DWL (nm) : 532
Dimensions (mm) : 25.0 x 25.0 x 25.0 ±0.1
Reflection/Transmission Tolerance (%) : ±5
Substrate : ☐ N-BK7
Surface Quality : 40-20
Transmission (%) : <45% ±5% @ DWL
Type : Non-Polarizing Beamsplitter
[Ts-Tp] : <3% @ DWL
Power (fringes) @ 632.8nm : 1.50
Irregularity (fringes) @ 632.8nm : 0.25

Regulatory Compliance

RoHS 2015 : Compliant
Reach 219 : Compliant
Certificate of Conformance : View