


TECHSPEC® 25mm Aluminum Coated Dove Prism

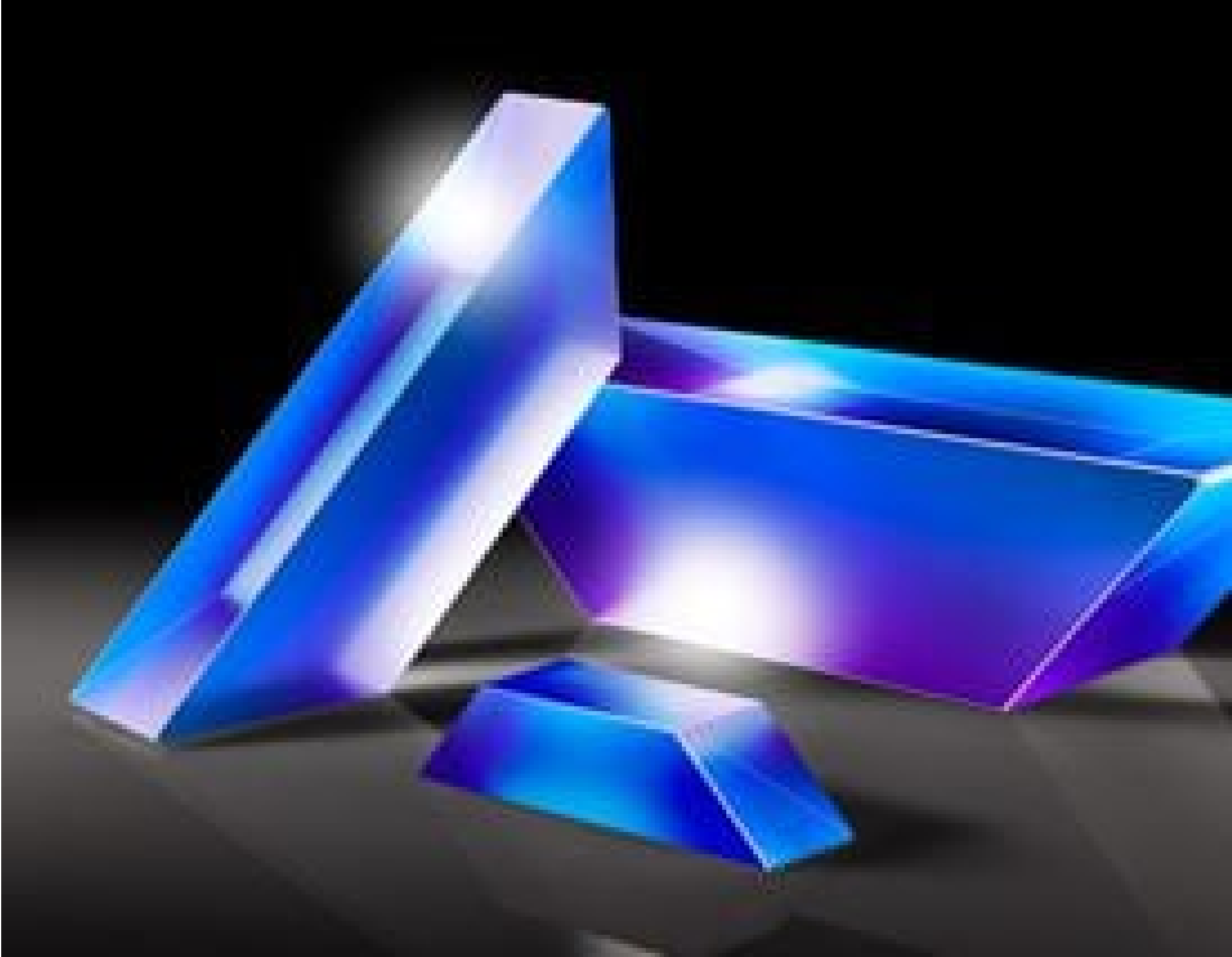

Stock **#45-816** ☐ In Stock

-

1

+

€200,00

ADD TO CART

Qty 1-5
€200,00
Qty 6+
€180,00
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Aluminum with protective overcoat

Substrate: ☐
[N-BK7](#)

Height (mm):
25.0

Length (mm): 103.18
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2
Bevel: Protective bevel as needed
Image Orientation: Right-Handed
Coating Specification: Reflective Surfaces: R _{avg} >85% FROM400-700nm, @ 45° AOI
Ray Deviation (°): 180
Wavelength Range (nm): 400 - 700
Damage Threshold, Reference: ☐ 0.3 J/cm² @ 532nm & 1064nm, 10ns
Power (fringes) @ 632.8nm: 0.50
Irregularity (fringes) @ 632.8nm: 0.25

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View