


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

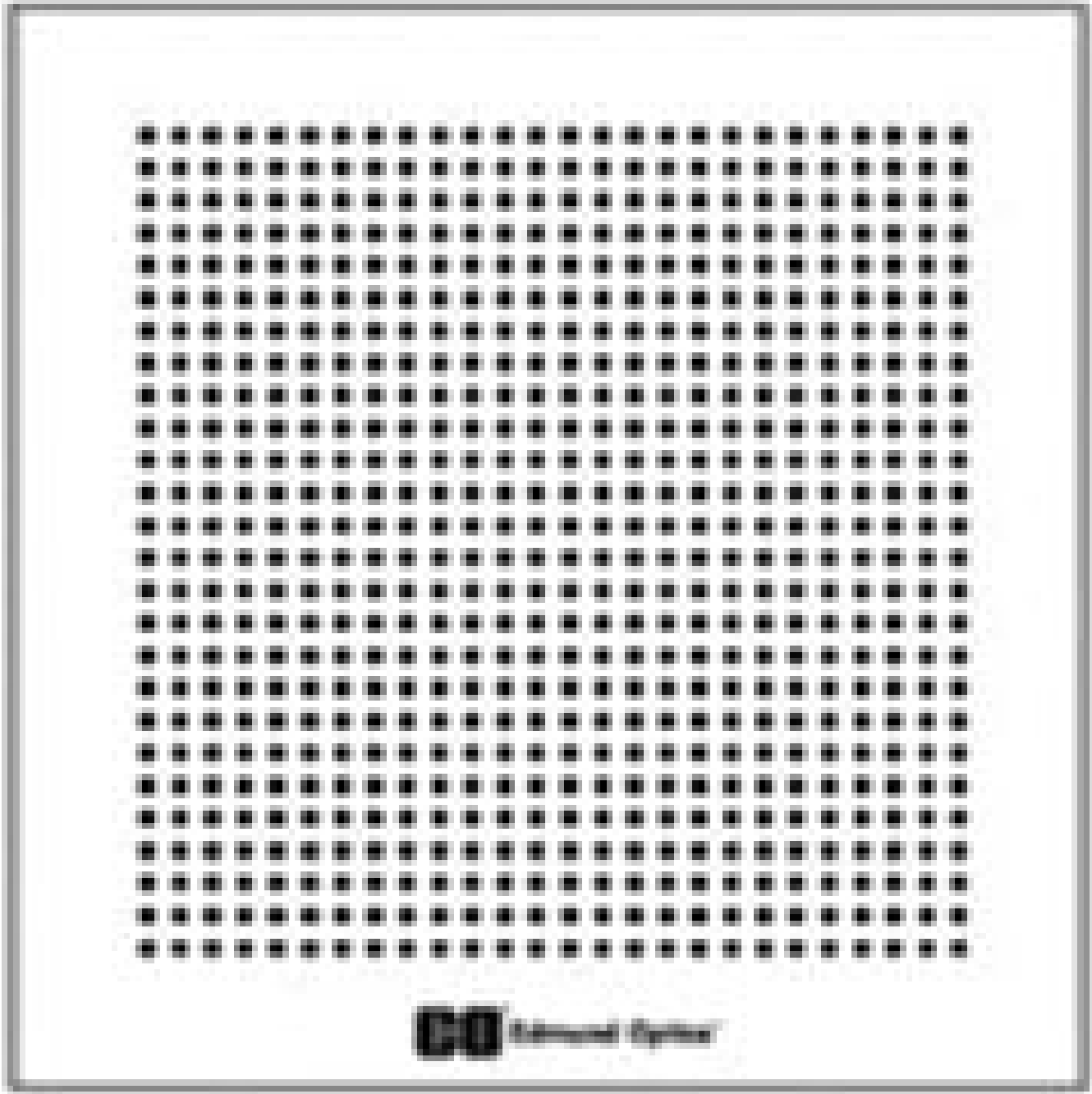

Stock #62-949 3-4 DAYS



1



€681,00

ADD TO CART

Qty 1-4

€681,00

Qty 5+

€647,40

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:  
Low Reflective Chrome

Dot Diameter (mm):  
0.0625

Dot Spacing (mm):  
0.125

Substrate:

|                                                        |
|--------------------------------------------------------|
| Float Glass                                            |
| <b>Pattern Size (mm):</b><br>25 x 25                   |
| <b>Dimensions (inches):</b><br>2 x 2 ±0.04             |
| <b>Thickness (mm):</b><br>2.00 ±0.2                    |
| <b>Center to Center Spacing Tolerance (µm):</b><br>± 1 |
| <b>Dot Diameter Tolerance (µm):</b><br>±3              |
| <b>NIST Certification:</b><br>No                       |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 223:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |