


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

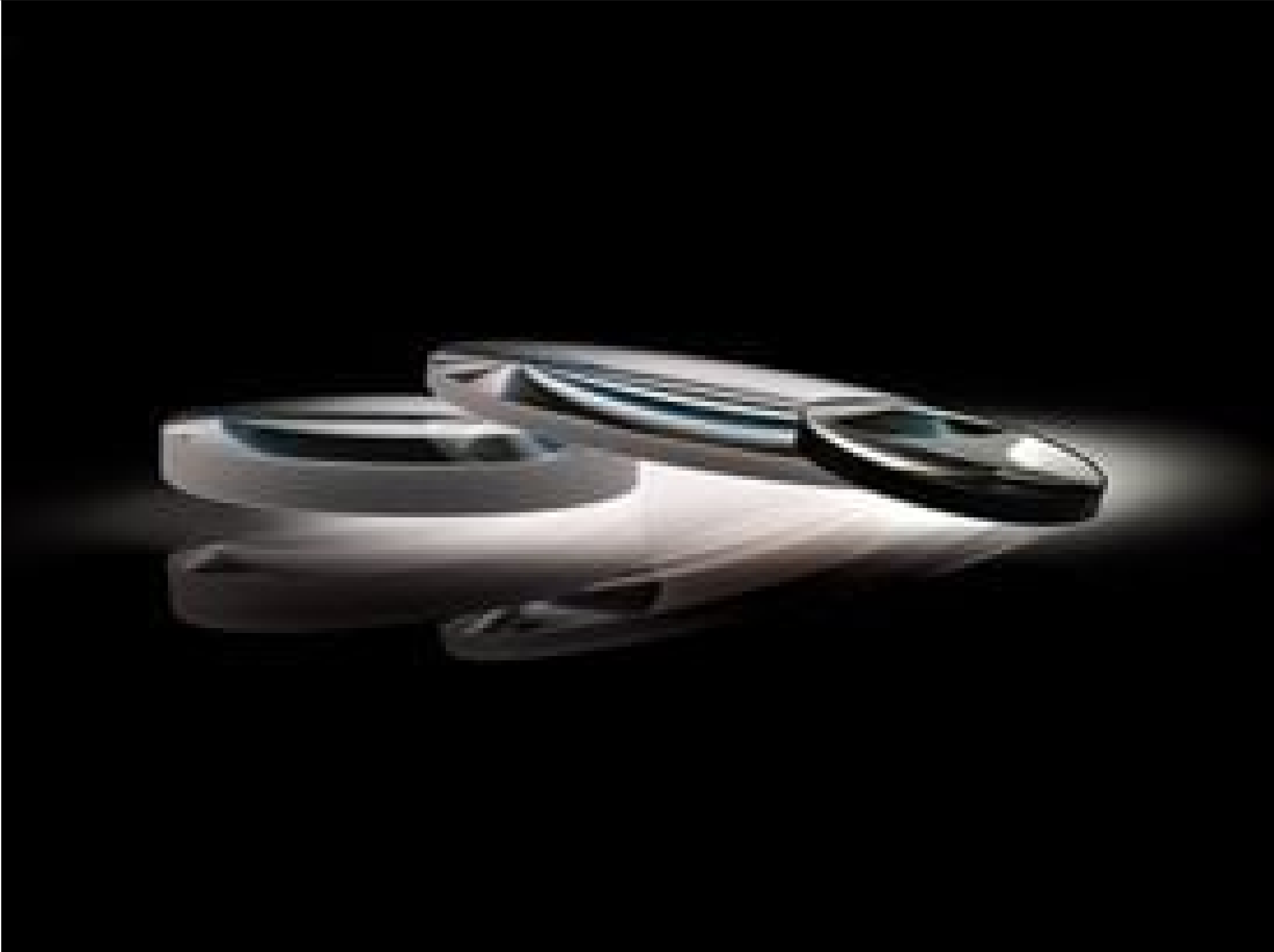

Stock **#45-131** ☐ In Stock

☐ [Other Coating Options](#)



1



€50,00

ADD TO CART

Qty 1-9

€50,00

Qty 10+

€45,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
3.00 +0.0/-0.025

Back Focal Length BFL (mm):

8.46
Effective Focal Length EFL (mm): 9.00
Coating: Uncoated
Substrate: ☐ N-BK7
Surface Quality: 20-10
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Centering (arcmin): <3
Bevel: Protective bevel as needed
Center Thickness CT (mm): 1.60
Center Thickness Tolerance (mm): ±0.05
Edge Thickness ET (mm): 1.35
Radius R ₁ =R ₂ (mm): 9.02
Clear Aperture CA (mm): 2.5
f/#: 3.00
Focal Length Specification Wavelength (nm): 587.6
Focal Length Tolerance (%): ±1
Numerical Aperture NA: 0.17
Type: Double-Convex Lens
Wavelength Range (nm): 350 - 2200

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant