


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 40mm Diameter 3-12µm AR, Zinc Sulfide Multispectral Window

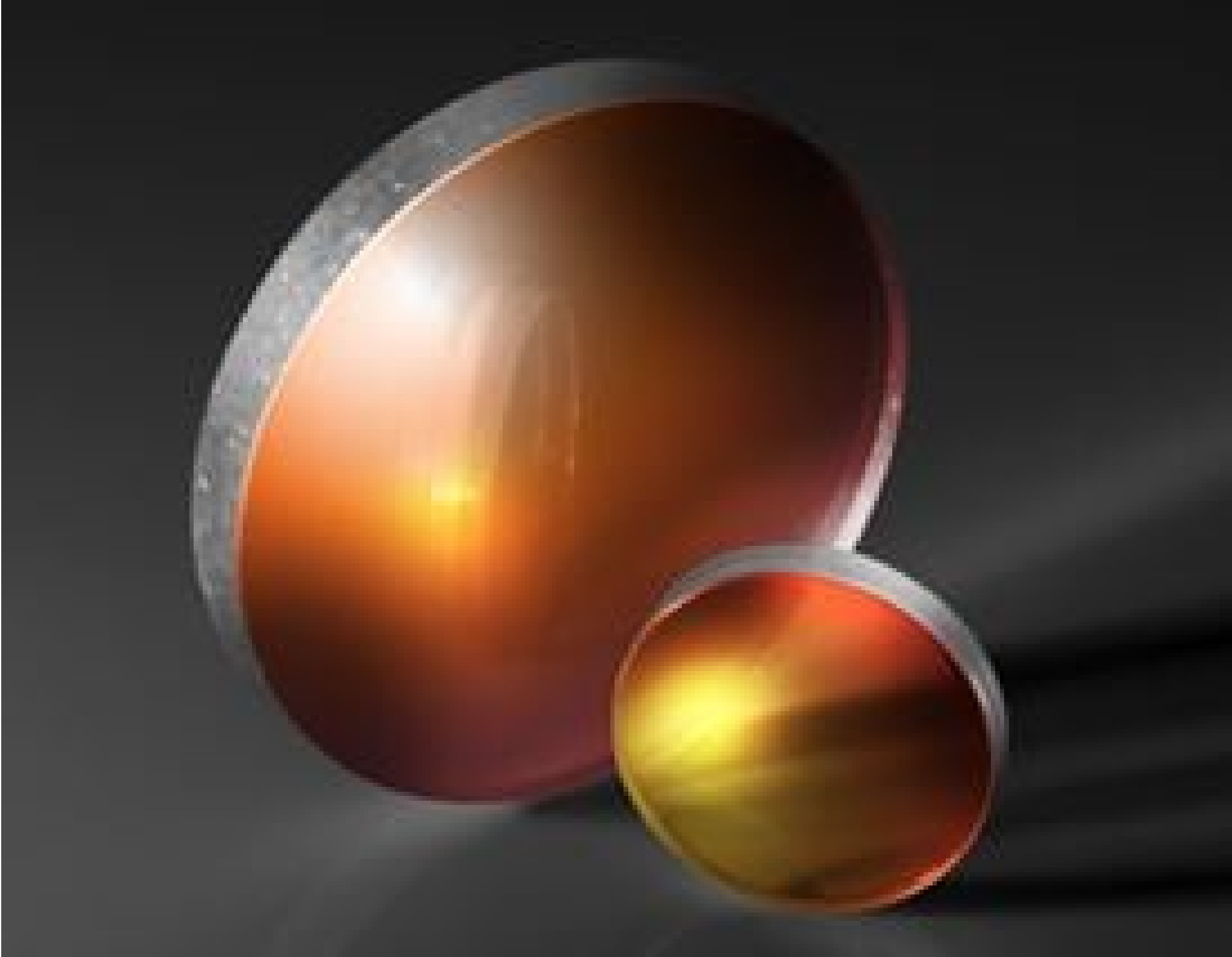

TECHSPEC® Zinc Sulfide Multispectral Windows

Stock #64-146 3-4 DAYS



1



€637,50

ADD TO CART

Qty 1-10

€637,50

Qty 11+

€574,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Bevel:
Protective as needed

Clear Aperture (%):
90.00

Clear Aperture CA (mm):

36.00
Diameter (mm): 40.00 +0.0/-0.1
Thickness (mm): 4.00 ±0.1
Coating: BBAR (3000-12000nm)
Coating Specification: R _{avg} <5.0% @ 3 - 12µm
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 6.8
Density (g/cm³): 4.08
Edges: Fine Ground
Index of Refraction n_d: 2.371
Knoop Hardness (kg/mm²): 210
Parallelism (arcmin): <1
Poisson's Ratio: 0.27
Substrate: Zinc Sulfide Multispectral
Surface Flatness (P-V): λ/10 @ 10.6µm
Surface Quality: 60-40
Type: Protective Window
Wavelength Range (nm): 3000 - 12000
Young's Modulus (GPa): 74.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View