


TECHSPEC® 5mm Aperture x 120mm L Low NA, Fused Silica Light Pipe

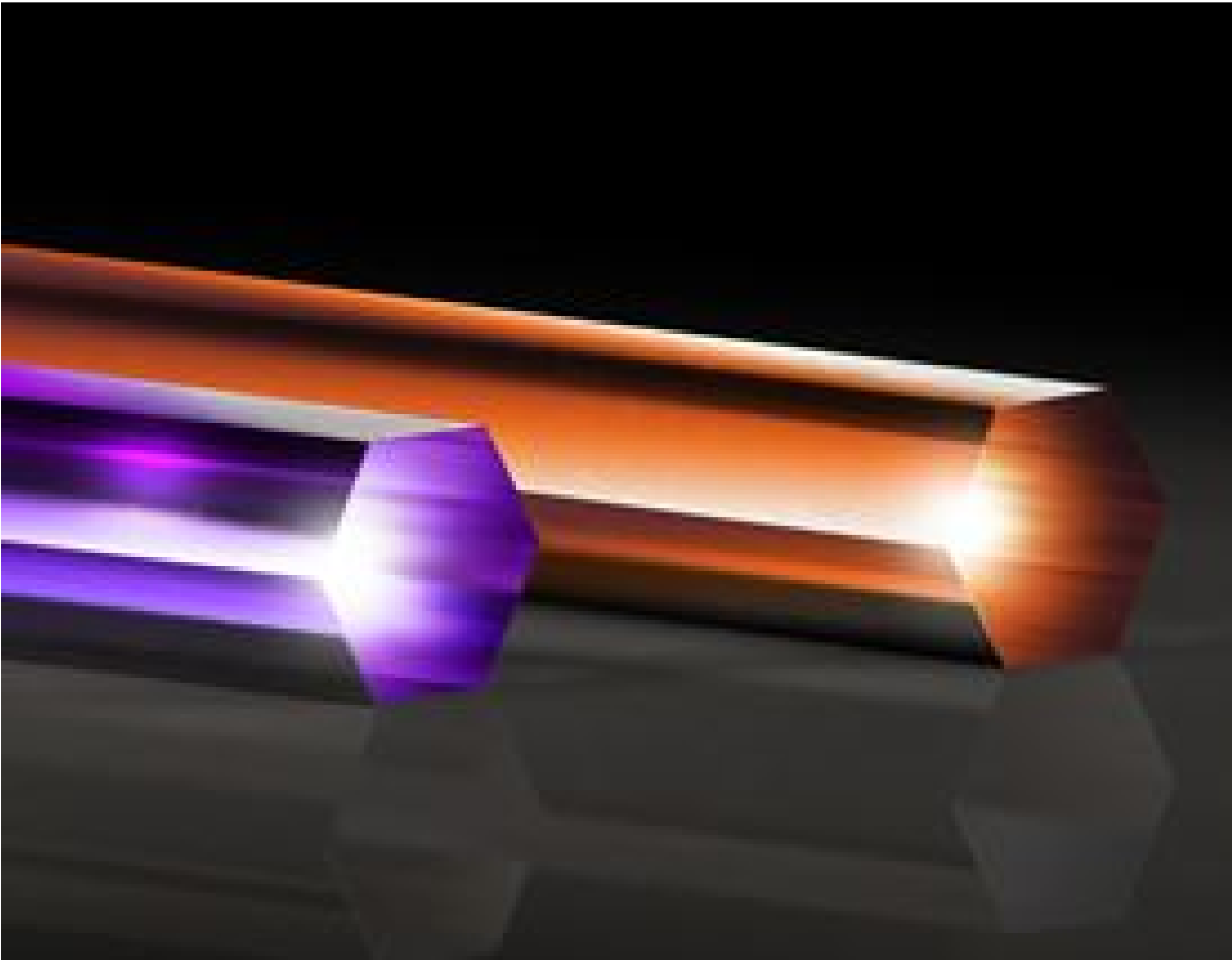

Fused Silica Light Pipe Homogenizing Rods



Stock **#65-833** 3-4 DAYS

- 1 +

€217,50

ADD TO CART

Qty 1-5
€217,50
Qty 6+
€174,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Uncoated

Substrate:

Fused Silica (Corning 7980)
Length (mm): 120.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 5.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 200 - 2200
Surface Flatness (P-V): 1λ
#Sorting: 34.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
