
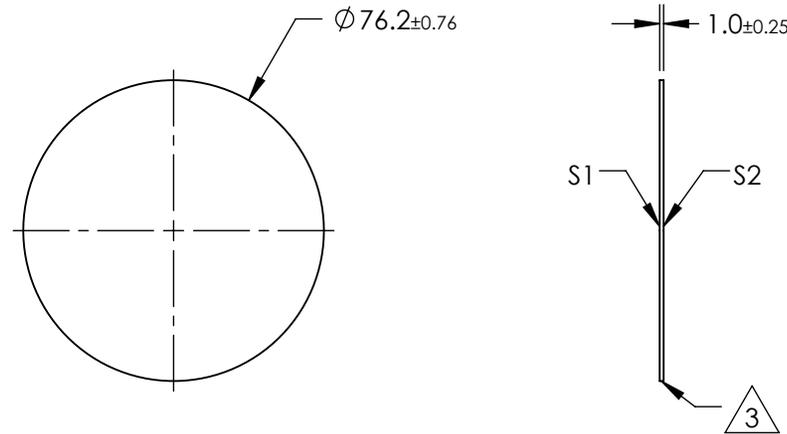


NOTES:

1. SUBSTRATE:
FLOAT GLASS
2. ANTI REFLECTION SURFACE TREATMENT (APPLY ACROSS CLEAR APERTURE)
AOI: 0°
S1 & S2: Ravg ≤0.5% @ 425 - 700nm

3. GROUND EDGES


4. ROHS COMPLIANT

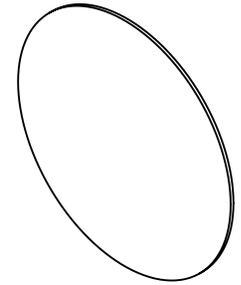

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

| | S1 | S2 |
|-----------------|----------------------|----------------------|
| SHAPE | PLANO | PLANO |
| SURFACE QUALITY | 80-50 | 80-50 |
| CLEAR APERTURE | ≥90% | ≥90% |
| BEVEL | PROTECTIVE AS NEEDED | PROTECTIVE AS NEEDED |

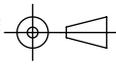THIRD ANGLE PROJECTION 

ALL DIMS IN mm

EO® Edmund Optics®

| | | |
|--------|--------------------------------------|--------------|
| TITLE | Ø76.2mm x 1mm HIGH EFFICIENCY WINDOW | |
| DWG NO | 48928 | SHEET 1 OF 1 |