
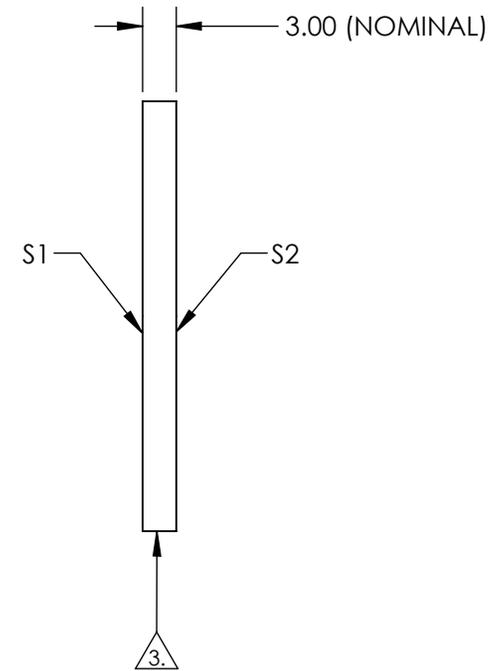


NOTES:

1. SUBSTRATE: Float Glass
2. COATING (APPLY ACROSS CLEAR APERTURE)
 - S1: Protected Gold (700-10000nm)
 - R(AVG) >96% @ 700 - 2000nm
 - R(AVG) >96% @ 2000 - 10,000nm
 - S2: NONE
3.  EDGES GROUND
4. RoHS COMPLIANT

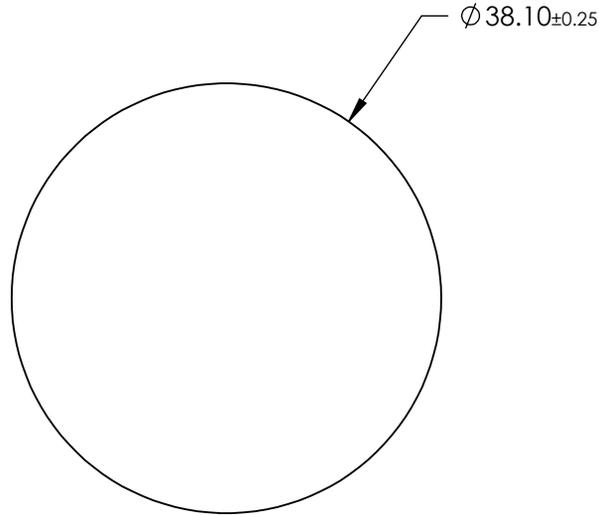

FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	S1	S2
SHAPE	PLANO	PLANO
SURFACE QUALITY	60-40	N/A
SURFACE FLATNESS	4 - 6λ	N/A
CLEAR APERTURE	Ø 36.20	N/A
BEVEL	PROTECTED AS NEEDED	PROTECTED AS NEEDED

THIRD ANGLE PROJECTION 

ALL DIMS IN mm



Edmund Optics®

TITLE	38.1mm Dia Protected Gold, 4-6λ Mirror
DWG NO	83497
SHEET	1 OF 1