
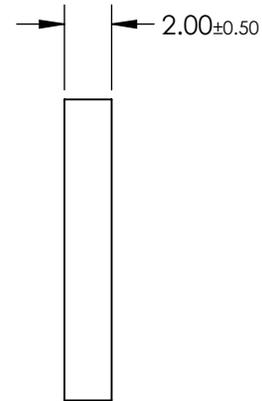
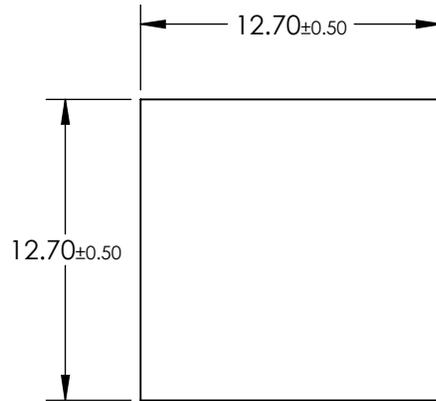


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

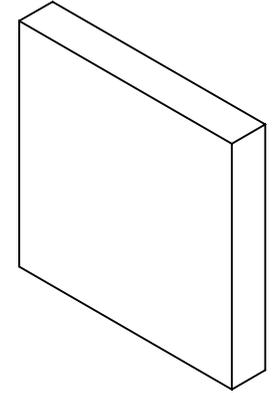

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	300
WAVELENGTH RANGE (nm)	250 - 500
BLAZE ANGLE	8.6°
RoHS	COMPLIANT

EO[®] Edmund Optics[®]

THIRD ANGLE PROJECTION 

ALL DIMS IN mm

TITLE	300 Grooves/mm, 12.7mm Sq, UV Transmission Grating Beamsplitter
DWG NO	85287
SHEET	1 OF 1