

[All Products](#) / [Optomechanics](#) / [Manual Translation Stages and Slides](#) / [Manual Stages and Slides](#)

Dovetail Optical Rail Systems



- Wide Range of Carrier Length and Mounting Hole Options Available
- Low Profile Design with Smooth Movement
- Increased Stability and <1mrad Straight Line Accuracy

Common Specifications

Physical & Mechanical Properties




Type of Movement:	Linear (X)	Guide System:	Dovetail
Construction:	Black Anodized Aluminum		

Hardware & Interface Connectivity


Type of Drive:	Manual
----------------	--------

Technical Information


Side Profile of Rail System

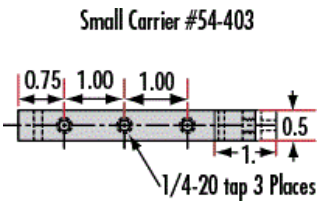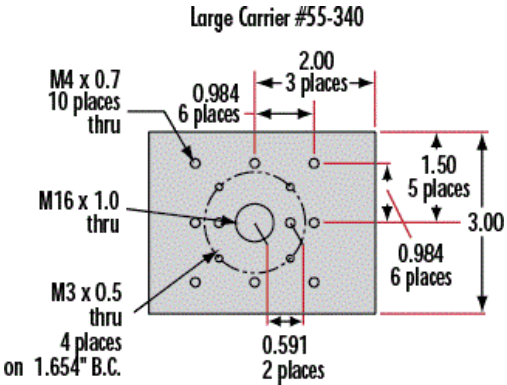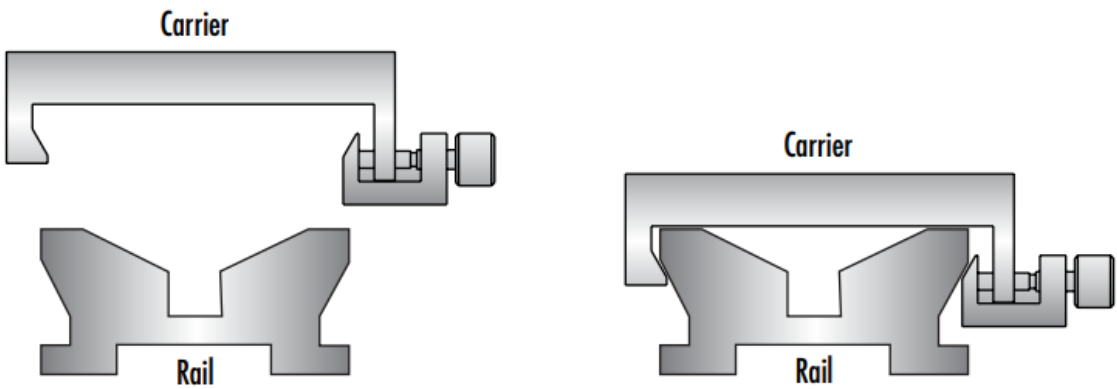



Medium Carrier #55-339

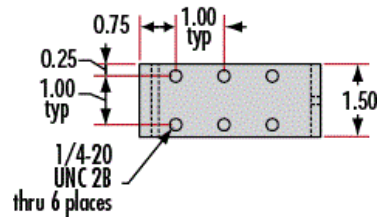


Large Carrier #55-404

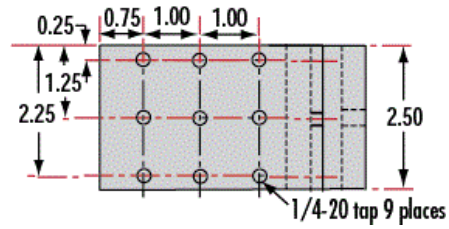

Medium Carrier #55-341

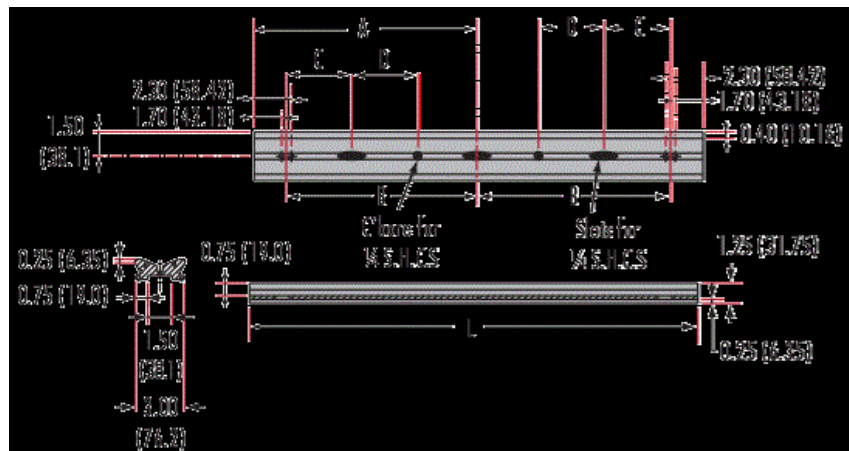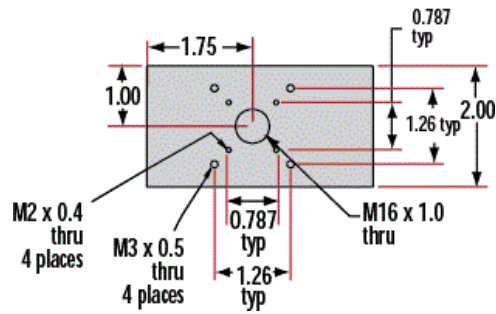

Common Side Profile

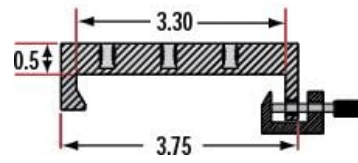

Products

Type of Drive	Type	Note	Length (inches)	Length (mm)	Mounting Threads	Stock Number	Price	Buy
Manual	Universal (Metric & English)	Rail	12	304.80	C'bore Holes and Slots only for ¼" (or M6) S.H.C.S	#54-401	€184,37 Volume Pricing	20+ In Stock
Manual	Universal (Metric & English)	Rail	24	609.60	C'bore Holes and Slots only for ¼" (or M6) S.H.C.S	#11-159	€258,00 Volume Pricing	20+ In Stock
Manual	Metric	Carrier	1.18	30.00	(8) M2 x 0.4, (1) M6 x 1.0	#12-507	€114,33 Volume Pricing	11 In Stock
Manual	English	Carrier	1.18	30.00	(8) 2-56, (1) 1/4-20	#12-508	€114,33 Volume Pricing	11 In Stock
Manual	Metric	Carrier	1.57	40.00	(4) M3 x 0.5, (8) M2 x 0.4, (1) M6 x 1.0	#12-509	€126,69 Volume Pricing	4 In Stock
Manual	English	Carrier	1.57	40.00	(4) 6-32, (8) 2-56, (1) 1/4-20	#12-510	€126,69 Volume Pricing	20+ In Stock
Manual	Metric	Carrier	2.76	70.00	(4) M3 x 0.5, (8) M2 x 0.4, (9) M6 x 1.0	#12-511	€146,26 Volume Pricing	20+ In Stock
Manual	English	Carrier	2.76	70.00	(4) 6-32, (8) 2-56, (9) 1/4-20	#12-512	€146,26 Volume Pricing	20+ In Stock
Manual	Universal (Metric & English)	Rail	36	914.40	C'bore Holes and Slots only for ¼" (or M6) S.H.C.S	#54-402	€345,05 Volume Pricing	20+ In Stock
Manual	English	Carrier	0.5	12.70	(3) ¼-20 on 1"	#54-403	€81,37 Volume Pricing	5 In Stock

Manual	Metric	Carrier	0.5	12.70	(3) M6 x 1.0 on 25mm	#11-160	€81,37 Volume Pricing	5 In Stock
Manual	English	Carrier	1.5	38.10	(6) ¼-20 on 1"	#55-339	€89,10 Volume Pricing	20+ In Stock
Manual	English	Carrier	2.5	63.50	(9) ¼-20 on 1"	#54-404	€122,57 Volume Pricing	20+ In Stock
Manual	Metric	Carrier	2.5	63.50	(9) M6 x 1.0 on 25mm	#11-161	€122,57 Volume Pricing	16 In Stock
Manual	Metric	Carrier	2	50.80	(1) M16 x 1.0, (4) M3 x 0.5, (4) M2 x 0.4	#55-341	€113,30 Volume Pricing	5 In Stock
Manual	Metric	Carrier	3	76.20	(1) M16 x 1.0, (10) M4 x 0.7, (4) M3 x 0.5	#55-340	€126,69 Volume Pricing	1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com