


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Broadband Dielectric Mirrors](#)

TECHSPEC® Broadband Dielectric $\lambda/10$ Mirrors

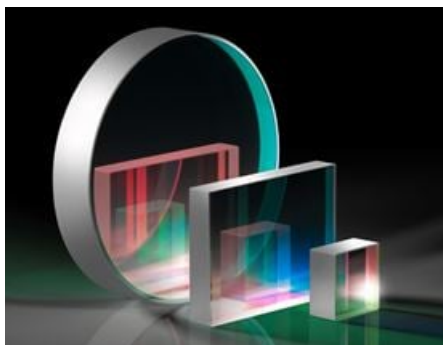

- Enhanced Reflectivity and LIDT over Metallic Coatings
- Average Reflectivity >99% Over Broad UV, Visible, and NIR Wavelengths
- Designed for all Polarization States from 0 – 45° AOI

Common Specifications

Physical & Mechanical Properties

Clear Aperture (%):	90
---------------------	----

Optical Properties

Surface Flatness (P-V):	$\lambda/10$
-------------------------	--------------




Substrate:	Fused Silica (Corning 7980)
------------	---


Surface Quality:	20-10
------------------	-------

Coating Type:	Dielectric
---------------	------------

Angle of Incidence (°):	0-45
-------------------------	------

Technical Information

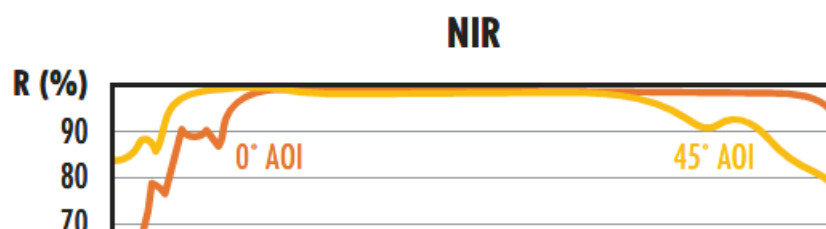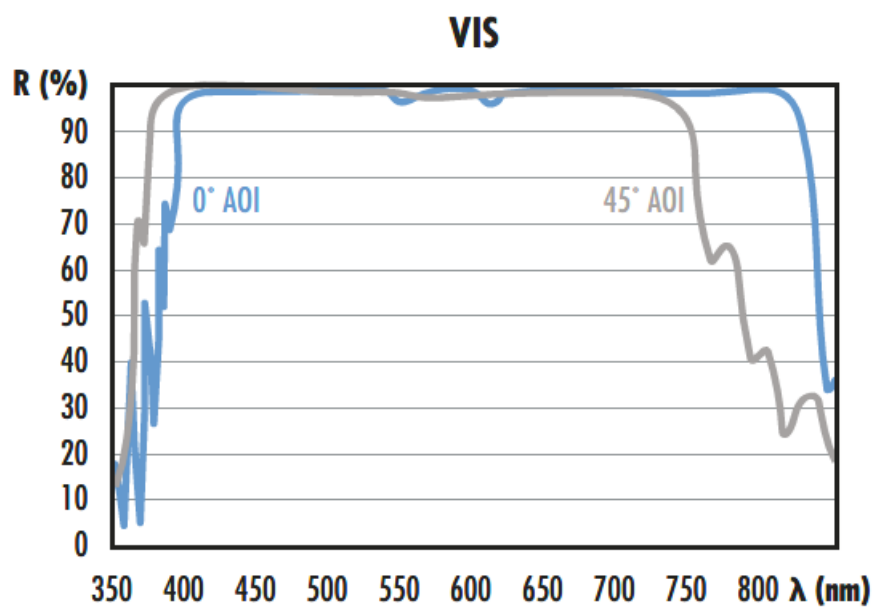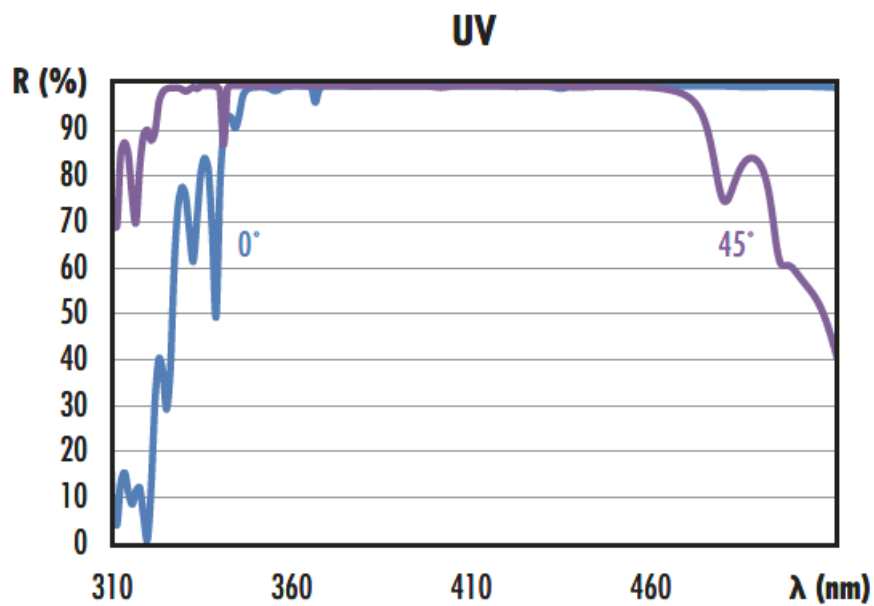

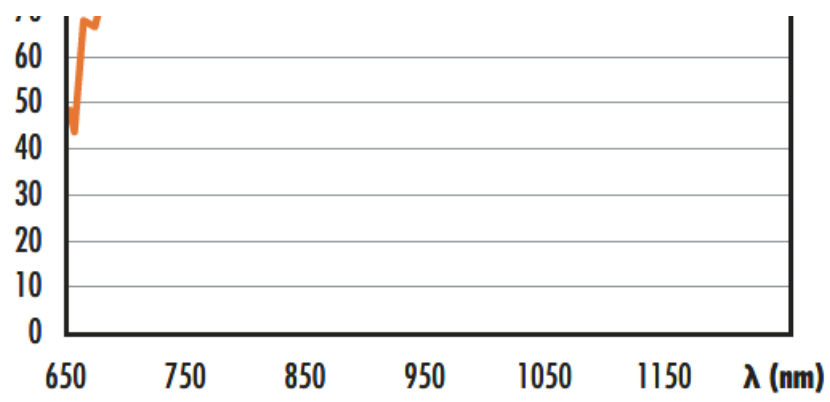

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Wavelength Range (nm)	Stock Number	Price	Buy
5.00	-	2.00	320 - 450	#37-558	€109,18 Volume Pricing	20+ In Stock
6.35	-	4.00	320 - 450	#39-190	€109,18 Volume Pricing	20+ In Stock
10.00	-	2.00	320 - 450	#37-559	€109,18 Volume Pricing	20+ In Stock
-	10.00 x 10.00	2.00	320 - 450	#29-901	€109,18 Volume Pricing	Contact Us
12.50	-	3.00	320 - 450	#37-560	€109,18 Volume Pricing	20+ In Stock
-	12.50 x 12.50	3.00	320 - 450	#29-902	€109,18 Volume Pricing	2 In Stock
12.70	-	6.35	320 - 450	#39-389	€109,18 Volume Pricing	20+ In Stock
15.00	-	3.00	320 - 450	#37-562	€128,75 Volume Pricing	2 In Stock
-	15.00 x 15.00	3.00	320 - 450	#29-903	€128,75 Volume Pricing	5 In Stock
19.10	-	6.35	320 - 450	#39-204	€128,75 Volume Pricing	14 In Stock
20.00	-	3.00	320 - 450	#37-563	€128,75 Volume Pricing	3 In Stock
-	20.00 x 20.00	3.00	320 - 450	#29-904	€128,75 Volume Pricing	Contact Us
25.00	-	4.00	320 - 450	#37-564	€133,90 Volume Pricing	20+ In Stock
-	25.00 x 25.00	4.00	320 - 450	#29-905	€133,90 Volume Pricing	12 In Stock
-	25.00 x 35.00	5.00	320 - 450	#29-345	€173,04 Volume Pricing	4 In Stock
25.40	-	6.35	320 - 450	#39-390	€133,90 Volume Pricing	17 In Stock
30.00	-	5.00	320 - 450	#37-568	€162,74 Volume Pricing	5 In Stock

35.00	-	5.00	320 - 450	#37-569	€190,55 Volume Pricing	13 In Stock
38.10	-	6.35	320 - 450	#39-218	€234,84 Volume Pricing	Contact Us
40.00	-	5.00	320 - 450	#37-570	€234,84 Volume Pricing	1 In Stock
50.00	-	10.00	320 - 450	#37-571	€262,65 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	320 - 450	#29-909	€262,65 Volume Pricing	9 In Stock
50.80	-	9.53	320 - 450	#39-225	€262,65 Volume Pricing	5 In Stock
75.00	-	7.50	320 - 450	#24-045	€664,35 Volume Pricing	2 In Stock
-	75.00 x 75.00	7.50	320 - 450	#29-910	€664,35 Volume Pricing	4 In Stock
100.00	-	10.00	320 - 450	#24-046	€1.189,65 Volume Pricing	1 In Stock
-	100.00 x 100.00	10.00	320 - 450	#29-911	€1.189,65 Volume Pricing	1 In Stock
5.00	-	2.00	400 - 750	#87-366	€81,37 Volume Pricing	Contact Us
6.35	-	4.00	400 - 750	#39-191	€81,37 Volume Pricing	9 In Stock
10.00	-	2.00	400 - 750	#87-367	€81,37 Volume Pricing	20+ In Stock
-	10.00 x 10.00	2.00	400 - 750	#29-913	€81,37 Volume Pricing	20+ In Stock
12.50	-	3.00	400 - 750	#87-368	€81,37 Volume Pricing	20+ In Stock
-	12.50 x 12.50	3.00	400 - 750	#29-914	€81,37 Volume Pricing	7 In Stock
12.70	-	6.35	400 - 750	#39-198	€81,37 Volume Pricing	20+ In Stock
15.00	-	3.00	400 - 750	#87-369	€100,43 Volume Pricing	10 In Stock
-	15.00 x 15.00	3.00	400 - 750	#29-915	€81,37 Volume Pricing	Contact Us
19.10	-	6.35	400 - 750	#39-205	€100,43 Volume Pricing	8 In Stock

20.00	-	3.00	400 - 750	#87-370	€100,43 Volume Pricing	20+ In Stock
-	20.00 x 20.00	3.00	400 - 750	#29-916	€100,43 Volume Pricing	Contact Us
25.00	-	4.00	400 - 750	#87-371	€106,09 Volume Pricing	Contact Us
-	25.00 x 25.00	4.00	400 - 750	#29-917	€106,09 Volume Pricing	3 In Stock
-	25.00 x 35.00	5.00	400 - 750	#29-346	€146,26 Volume Pricing	4 In Stock
25.40	-	6.35	400 - 750	#39-212	€106,09 Volume Pricing	20+ In Stock
30.00	-	5.00	400 - 750	#87-372	€131,84 Volume Pricing	2 In Stock
35.00	-	5.00	400 - 750	#87-373	€162,74 Volume Pricing	7 In Stock
38.10	-	6.35	400 - 750	#39-219	€197,76 Volume Pricing	20+ In Stock
40.00	-	5.00	400 - 750	#87-374	€197,76 Volume Pricing	5 In Stock
50.00	-	10.00	400 - 750	#33-188	€221,45 Volume Pricing	4 In Stock
-	50.00 x 50.00	5.00	400 - 750	#29-921	€221,45 Volume Pricing	7 In Stock
50.80	-	9.53	400 - 750	#39-226	€221,45 Volume Pricing	14 In Stock
75.00	-	7.50	400 - 750	#24-047	€597,40 Volume Pricing	Contact Us
-	75.00 x 75.00	7.50	400 - 750	#29-922	€597,40 Volume Pricing	Contact Us
100.00	-	10.00	400 - 750	#24-048	€1.107,25 Volume Pricing	2 In Stock
-	100.00 x 100.00	10.00	400 - 750	#29-923	€1.107,25 Volume Pricing	Contact Us
5.00	-	2.00	750 - 1100	#87-376	€81,37 Volume Pricing	9 In Stock
6.35	-	4.00	750 - 1100	#39-192	€81,37 Volume Pricing	4 In Stock
10.00	-	2.00	750 - 1100	#87-377	€81,37 Volume Pricing	20+ In Stock

-	10.00 x 10.00	2.00	750 - 1100	#29-925	€81,37 Volume Pricing	8 In Stock
12.50	-	3.00	750 - 1100	#87-378	€81,37 Volume Pricing	20+ In Stock
-	12.50 x 12.50	3.00	750 - 1100	#29-926	€81,37 Volume Pricing	6 In Stock
12.70	-	6.35	750 - 1100	#39-199	€81,37 Volume Pricing	20+ In Stock
15.00	-	3.00	750 - 1100	#87-379	€100,43 Volume Pricing	20+ In Stock
-	15.00 x 15.00	3.00	750 - 1100	#29-927	€100,43 Volume Pricing	12 In Stock
19.10	-	6.35	750 - 1100	#39-206	€100,43 Volume Pricing	20+ In Stock
20.00	-	3.00	750 - 1100	#87-380	€100,43 Volume Pricing	20+ In Stock
-	20.00 x 20.00	3.00	750 - 1100	#29-928	€100,43 Volume Pricing	4 In Stock
25.00	-	4.00	750 - 1100	#87-381	€106,09 Volume Pricing	20+ In Stock
-	25.00 x 25.00	4.00	750 - 1100	#29-929	€106,09 Volume Pricing	16 In Stock
-	25.00 x 35.00	5.00	750 - 1100	#29-347	€146,26 Volume Pricing	20+ In Stock
25.40	-	6.35	750 - 1100	#39-213	€106,09 Volume Pricing	20+ In Stock
30.00	-	5.00	750 - 1100	#87-382	€131,84 Volume Pricing	20+ In Stock
35.00	-	5.00	750 - 1100	#87-383	€162,74 Volume Pricing	3 In Stock
38.10	-	6.35	750 - 1100	#39-220	€197,76 Volume Pricing	3 In Stock
40.00	-	5.00	750 - 1100	#87-384	€197,76 Volume Pricing	10 In Stock
50.00	-	10.00	750 - 1100	#33-189	€221,45 Volume Pricing	10 In Stock
-	50.00 x 50.00	5.00	750 - 1100	#29-933	€221,45 Volume Pricing	20+ In Stock
50.80	-	9.53	750 - 1100	#39-227	€221,45 Volume Pricing	20+ In Stock

75.00	-	7.50	750 - 1100	#24-049	€618,00 Volume Pricing	5 In Stock
-	75.00 x 75.00	7.50	750 - 1100	#29-934	€618,00 Volume Pricing	Contact Us
100.00	-	10.00	750 - 1100	#24-050	€1.107,25 Volume Pricing	3 In Stock
-	100.00 x 100.00	10.00	750 - 1100	#29-935	€1.107,25 Volume Pricing	Contact Us



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com