

[All Products](#) / [Laser Optics](#) / [Laser Optical Assemblies](#) / [Beam Shapers](#)


AdlOptica π Shaper Flat Top Beam Shapers See More by [AdlOptica](#)



- Convert Gaussian Beam Profile to Flat Top Profile
- Near 100% Efficiency
- No Internal Focusing Enables High Power Laser Input
- [AdlOptica Focal- \$\pi\$ Shaper Q Flat Top Beam Shapers](#) Also Available

Technical Information

Example of beam shaping for TEM₀₀ Laser

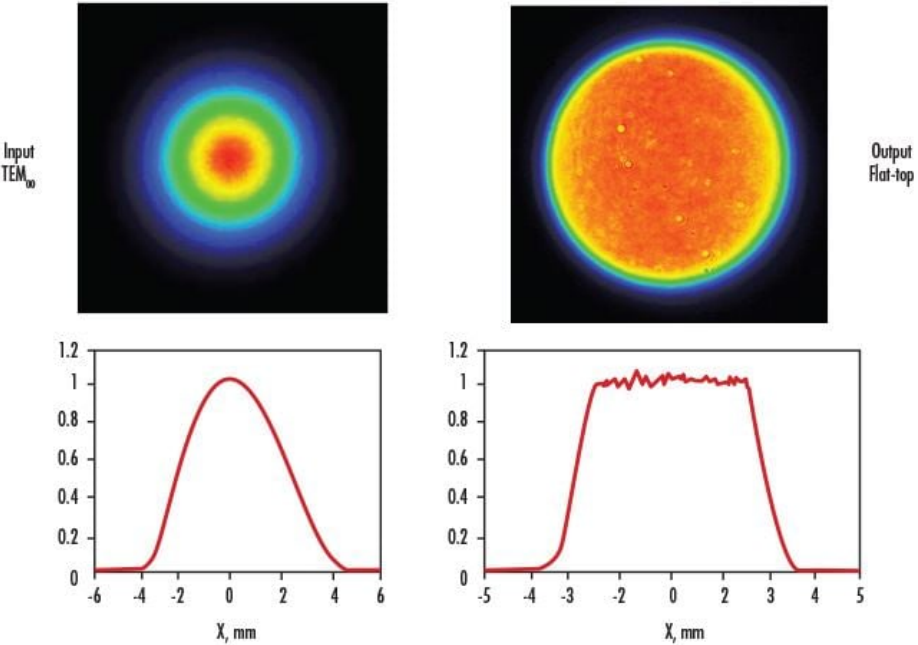

Products

DWL (nm)	Wavelength Range (nm)	Dia. (mm)	Length (mm)	Input Clear Aperture CA (mm)	Entrance Beam Diameter, 1/e ² (mm)	Stock Number	Price	Buy
266	250 - 275	39.00	143.00	-	6.3	#34-255	€6.808,30 Volume Pricing	1 In Stock
266	250 - 270	42.00	358.00	-	12.0 - 12.1	#15-498	€10.073,40 Volume Pricing	Contact Us
355	330 - 380	39.00	143.00	-	6.3	#34-256	€6.427,20 Volume Pricing	3 In Stock
355	330 - 380	42.00	358.00	-	12.0 - 12.1	#15-497	€10.073,40 Volume Pricing	Contact Us
355, 532	335 - 560	39.00	143.00	-	5.9 – 6.0	#21-102	€5.850,40 Volume Pricing	1 In Stock
442, 632.8	405 - 680	39.00	143.00	-	6.0	#12-644	€6.241,80 Volume Pricing	4 In Stock
532	510 - 550	39.00	143.00	-	6.3 - 6.4	#34-257	€6.241,80 Volume Pricing	3 In Stock
532	515 - 550	42.00	358.00	-	12.0 - 12.1	#15-496	€9.249,40 Volume Pricing	1 In Stock
800	700 - 900	39.00	143.00	-	6.4 - 6.5	#36-649	€6.241,80 Volume Pricing	1 In Stock
800	700 - 900	42.00	358.00	-	12.0 - 12.1	#14-279	€10.104,30 Volume Pricing	Contact Us
1064	1020 - 1100	39.00	143.00	-	6.4 - 6.5	#34-258	€5.675,30 Volume Pricing	3 In Stock
1064	1020 - 1100	42.00	358.00	-	12.0 - 12.1	#15-495	€8.837,40 Volume Pricing	1 In Stock
1064	1020 - 1100	49.00	360.00	-	12.0 – 12.1	#21-101	€10.217,60 Volume Pricing	1 In Stock
1319, 1650	1100 - 1700	39.00	143.00	-	5.9 - 6.0	#12-691	€5.675,30 Volume Pricing	Contact Us
1550	1500 - 1600	39.00	143.00	-	6.4-6.5	#37-700	€6.468,40 Volume Pricing	1 In Stock
1550	1500 - 1600	49.00	358.00	-	12	#25-841	€10.217,60 Volume Pricing	Contact Us
2050	1900 - 2160	39.00	143.00	-	6.4 - 6.5	#12-242	€6.581,70 Volume Pricing	Contact Us

[#25-840 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

5100	5000 - 5500	49.00	271.00	-	12		€8.847,70 Volume Pricing	1 In Stock
------	-------------	-------	--------	---	----	--	---	------------

9400	9000 - 10000	39.00	135.00	-	7	#25-838	€6.798,00 Volume Pricing	Contact Us
------	--------------	-------	--------	---	---	-------------------------	---	------------

9400	9000 - 10000	49.00	271.00	-	12	#25-839	€8.847,70 Volume Pricing	1 In Stock
------	--------------	-------	--------	---	----	-------------------------	---	------------

10600	10000 - 11000	39.00	143.00	-	7	#34-259	€6.808,30 Volume Pricing	Contact Us
-------	---------------	-------	--------	---	---	-------------------------	---	------------

10600	10000 - 11000	49.00	360.00	-	12	#34-260	€9.259,70 Volume Pricing	Contact Us
-------	---------------	-------	--------	---	----	-------------------------	---	------------

