


[All Products](#) / [Optics](#) / [Diffractive Optical Elements \(DOE\)](#)

HOLO/OR Diffractive Diffusers

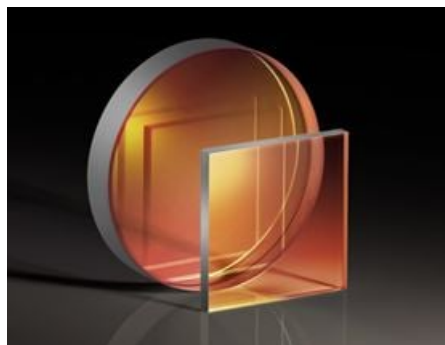

- Shape Laser Beams with Homogenized Distribution
- Circular or Square Output Shapes
- Designs for 532nm and 1064nm Nd:YAG Lasers
- Compatible with Single Mode or Multimode Beams

Common Specifications

Optical Properties

Substrate: Fused Silica (Corning 7980)	Input Beam Mode: SM or MM
Damage Threshold, Reference: See Link for More Details	

Technical Information

Products

Title	Stock Number	Price	Buy
1064nm, 20mm Dia., Square Output, High Homogeneity Diffractive Diffuser	#14-681	€1.726,00	5 In Stock
1064nm, 15mm Dia., Round Output, Diffractive Diffuser	#14-682	€1.193,00	1 In Stock
532nm, 15 x 15mm, Round Output, High Homogeneity Diffractive Diffuser	#14-683	€2.171,00	9 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com