


[All Products](#) / [Testing and Detection](#) / [Measurement Tools](#)

## Liquid Crystal Thermometers

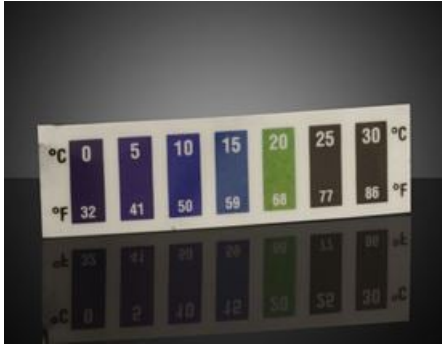

- Reversible Color Change Thermometers
- Instant Response and Continuous Readout
- 30 Celsius Degrees Ranges between 0 to 120°C

### Common Specifications

#### Physical & Mechanical Properties

Dimensions (mm):

12.5 x 45

## Technical Information

°C	0	5	10	15	20	25	30	°C
°F	32	41	50	59	68	77	86	°F

Liquid Crystal Thermometers are calibrated to turn green when the listed temperature is achieved. If green is not visible, the temperature will be midway between the elements that are blue and orange. Elements turn blue when they surpass their listed temperature and orange when they are just below their listed temperature.

## Products

Title	Stock Number	Price	Buy
0 - 30°C Temp Range, Liquid Crystal Thermometers (10/Pack)	<a href="#">#16-783</a>	€23,00 Qty 6+ €20,40	3-4 days
30 - 60°C Temp Range, Liquid Crystal Thermometers (10/Pack)	<a href="#">#16-784</a>	€23,00 Qty 6+ €20,40	Contact Us
60 - 90°C Temp Range, Liquid Crystal Thermometers (10/Pack)	<a href="#">#16-785</a>	€23,00 Qty 6+ €20,40	3-4 days
90 - 120°C Temp Range, Liquid Crystal Thermometers (10/Pack)	<a href="#">#16-786</a>	€23,00 Qty 6+ €20,40	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)