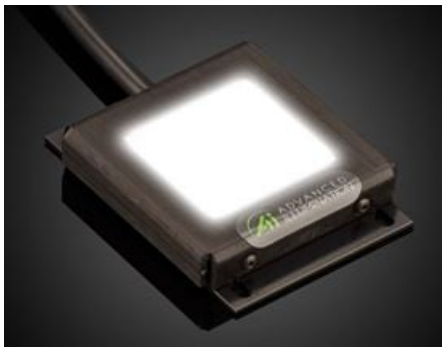


[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Backlights](#)

Advanced Illumination MicroBrite High Intensity Edge-Lit Backlights

 See More by [Advanced Illumination](#)


- High Intensity Machine Vision Illuminator
- Edge-to-Edge Uniform, Low Heat Illumination
- Thin, Compact Form Factor
- Optional Manual Intensity Adjustments ([#86-887](#) and [#89-555](#)) Recommended

Common Specifications

General

LED Lifetime (hours):	50,000	Type of Illumination:	LED Illuminator
Note:	Optional Manual Intensity Adjustment #86-887 and #89-555 are Available	Manufacturer:	Advanced Illumination
Geometry:	Backlight	Illumination Mode:	Constant

Hardware & Interface Connectivity

Connector:	Flying Leads	Input Voltage (V):	24V
-------------------	--------------	---------------------------	-----

Environmental & Durability Factors

Operating Temperature (°C):	0 - 60	Environmental Rating:	IP50
------------------------------------	--------	------------------------------	------

Technical Information

Products

Dimensions (mm)	Color	Wavelength (nm)	Stock Number	Price	Buy
70.3 x 54.71 x 11.33	White	-	#18-547	€870,00	1 In Stock
70.3 x 54.71 x 11.33	Blue	455.00	#18-549	€870,00	3 In Stock
70.3 x 54.71 x 11.33	Green	530.00	#18-550	€870,00	2 In Stock
70.3 x 54.71 x 11.33	Red	625.00	#18-548	€870,00	1 In Stock
70.3 x 54.71 x 11.33	IR	850.00	#18-551	€870,00	1 In Stock
120.02 x 104.60 x 11.25	White	-	#18-552	€980,00	2 In Stock
120.02 x 104.60 x 11.25	Blue	455.00	#18-554	€980,00	1 In Stock
120.02 x 104.60 x 11.25	Green	530.00	#18-555	€980,00	1 In Stock
120.02 x 104.60 x 11.25	Red	625.00	#18-553	€980,00	2 In Stock
120.02 x 104.60 x 11.25	IR	850.00	#18-556	€980,00	1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com