

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Precision Polished Metal Coatings](#)
TECHSPEC® $\lambda/20$ Fused Silica Right Angle Mirrors


- Precision Fused Silica Substrates for Increased Thermal Stability
- Ideal for System Alignment
- Enhanced Aluminum, Protected Gold, and Protected Silver Coatings Available

Common Specifications

Physical & Mechanical Properties

Dimensional Tolerance (mm):	+0.00/-0.10	Bevel:	Protective as needed
Optical Properties			
Surface Flatness (P-V):	$\lambda/20$	Substrate:	Fused Silica (Corning 7980)
Surface Quality:	20-10	Coating Type:	Metal
Angle Tolerance (arcsec):	± 15		

Technical Information


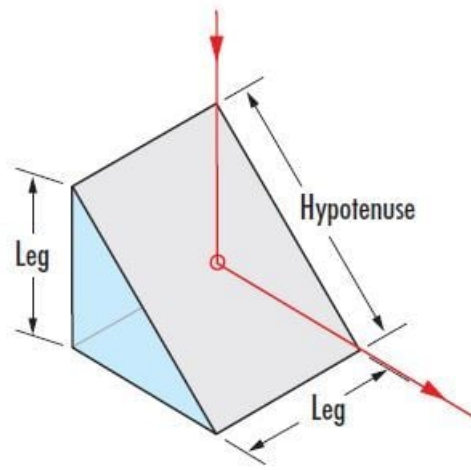


Image above shows light reflecting off the coated hypotenuse.

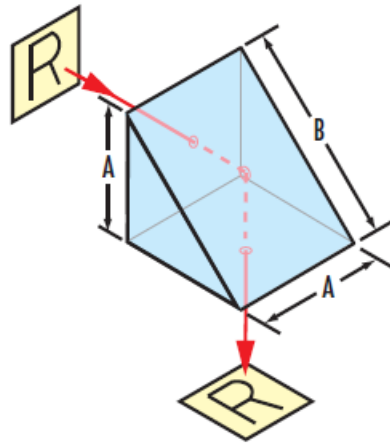

Products

Surface Flatness (P-V)	Length of Legs (mm)	Coating Specification	Coating	Stock Number	Price	Buy
$\lambda/20$	5.00	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	#22-545	€187,46 Volume Pricing	17 In Stock
$\lambda/20$	10.00	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	#22-546	€203,94 Volume Pricing	Contact Us
$\lambda/20$	12.50	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	#22-547	€209,09 Volume Pricing	3 In Stock
$\lambda/20$	15.00	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	#22-548	€224,54 Volume Pricing	6 In Stock
$\lambda/20$	20.00	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	#22-549	€241,02 Volume Pricing	4 In Stock
$\lambda/20$	25.00	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	#22-550	€251,32 Volume Pricing	Contact Us
$\lambda/20$	5.00	$R_{avg} > 98\% @ 450 - 800nm$ $R_{avg} > 98.5\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	#22-551	€197,76 Volume Pricing	9 In Stock
$\lambda/20$	10.00	$R_{avg} > 98\% @ 450 - 800nm$ $R_{avg} > 98.5\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	#22-552	€214,24 Volume Pricing	3 In Stock
$\lambda/20$	12.50	$R_{avg} > 98\% @ 450 - 800nm$ $R_{avg} > 98.5\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	#22-553	€219,39 Volume Pricing	Contact Us

$\lambda/20$	15.00	$R_{avg} > 98\% @$ 450 - 800nm $R_{avg} > 98.5\% @$ 2000 - 10,000nm	Protected Silver (450- 10000nm)	#22-554	€235,87 Volume Pricing	5 In Stock
$\lambda/20$	20.00	$R_{avg} > 98\% @$ 450 - 800nm $R_{avg} > 98.5\% @$ 2000 - 10,000nm	Protected Silver (450- 10000nm)	#22-555	€251,32 Volume Pricing	8 In Stock
$\lambda/20$	25.00	$R_{avg} > 98\% @$ 450 - 800nm $R_{avg} > 98.5\% @$ 2000 - 10,000nm	Protected Silver (450- 10000nm)	#22-556	€278,10 Volume Pricing	13 In Stock
$\lambda/20$	5.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	#22-557	€214,24 Volume Pricing	12 In Stock
$\lambda/20$	10.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	#22-558	€235,87 Volume Pricing	Contact Us
$\lambda/20$	12.50	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	#22-559	€241,02 Volume Pricing	Contact Us
$\lambda/20$	15.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	#22-560	€267,80 Volume Pricing	14 In Stock
$\lambda/20$	20.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	#22-561	€284,28 Volume Pricing	15 In Stock
$\lambda/20$	25.00	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	Protected Gold (700- 10000nm)	#22-562	€299,73 Volume Pricing	11 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com