


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

0.1 OD 50mm Dia, Absorptive ND Filter

See More by [Hoya](#)

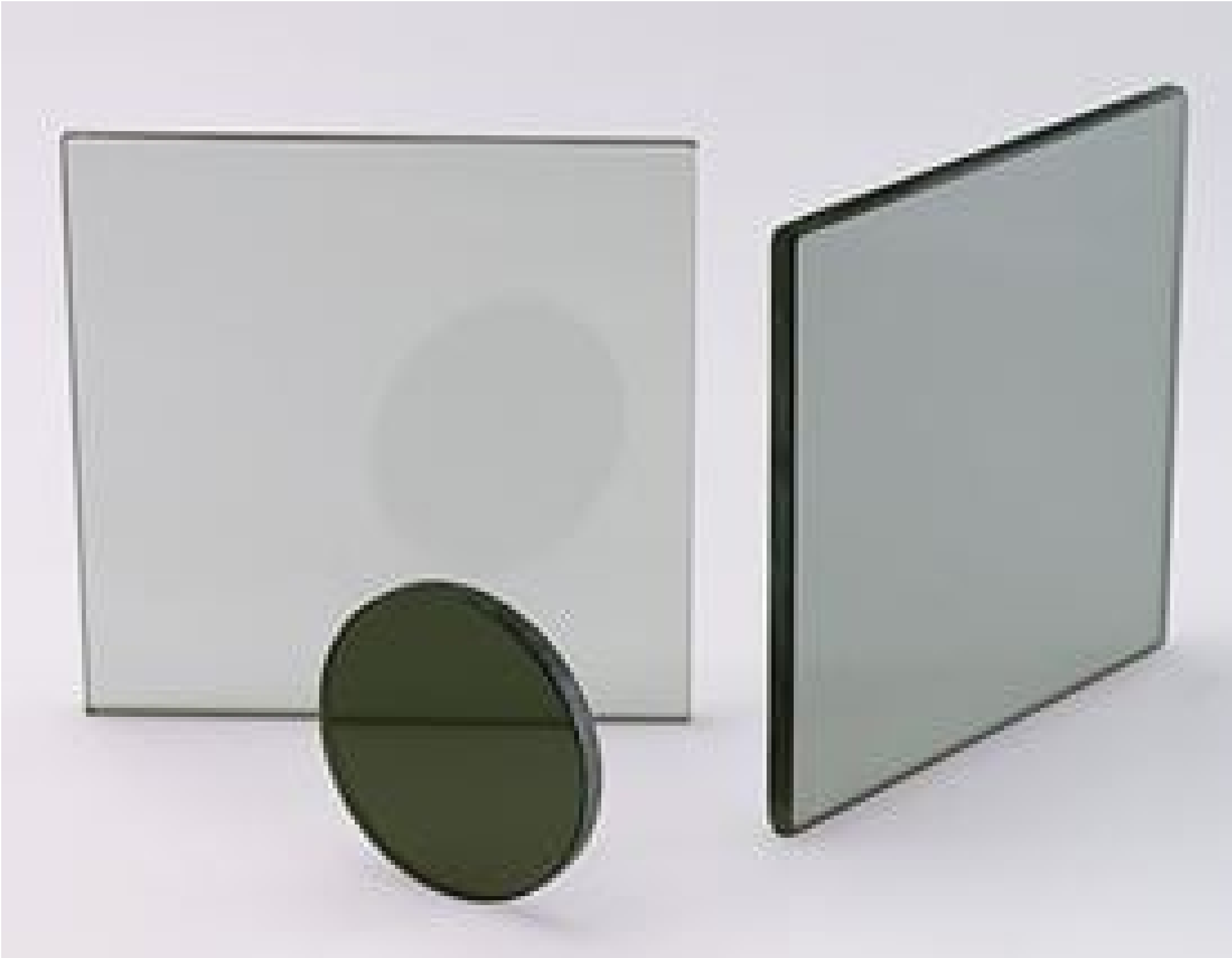

Stock #65-808 3-4 DAYS



1



€95,00

ADD TO CART

Qty 1-10

€95,00

Qty 11+

€84,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
50.00

Optical Density OD (Average):

0.1 ±0.03
Glass/Filter Number: Hoya ND-70
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.500
Surface Quality: 80-50
Transformation Temperature (°C): 470
Thickness (mm): 1.20
Thickness Tolerance (mm): ±0.5
Transmission (%): 79.0 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View