


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

0.2 X 40° Diffusing Angle 8" X 8" Unmounted

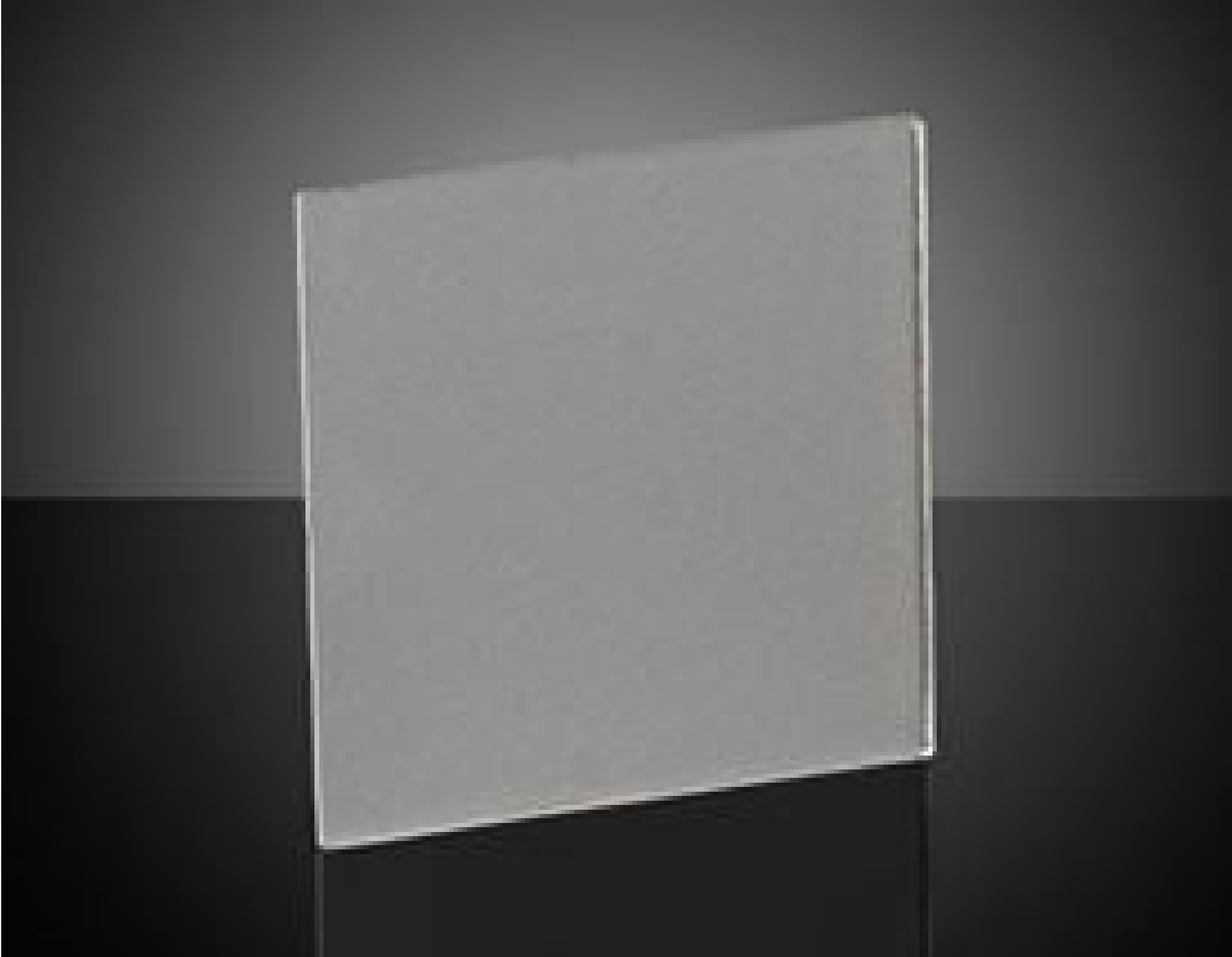

Stock #48-000 CLEARANCE 3-4 DAYS



1



€457,50

ADD TO CART

Qty 1+

€457,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Angle Tolerance (°):
±0.5 x ±4

Diffusing Angle (°):
0.2 x 40 (FWHM)

Dimensional Tolerance (mm):
±0.5

Dimensions (inches):
8 x 8

Dimensions (mm):
203.20 x 203.20

Operating Temperature (°C): -30 to +100 (Maximum of 240 Hours)
Substrate: ☐ Polycarbonate
Thickness (mm): 0.78
Transmission (%): >85
Type: Holographic Diffuser
Wavelength Range (nm): 400 - 700
Width (mm): 203.20
Construction: Unmounted
Damage Threshold, By Design: ☐ 0.22 J/cm² @ 1064nm, 10ns (typical)
Length (mm): 203.20

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant