


0.75" Travel, Fine Screw, Solid-Top Ball Bearing Stage

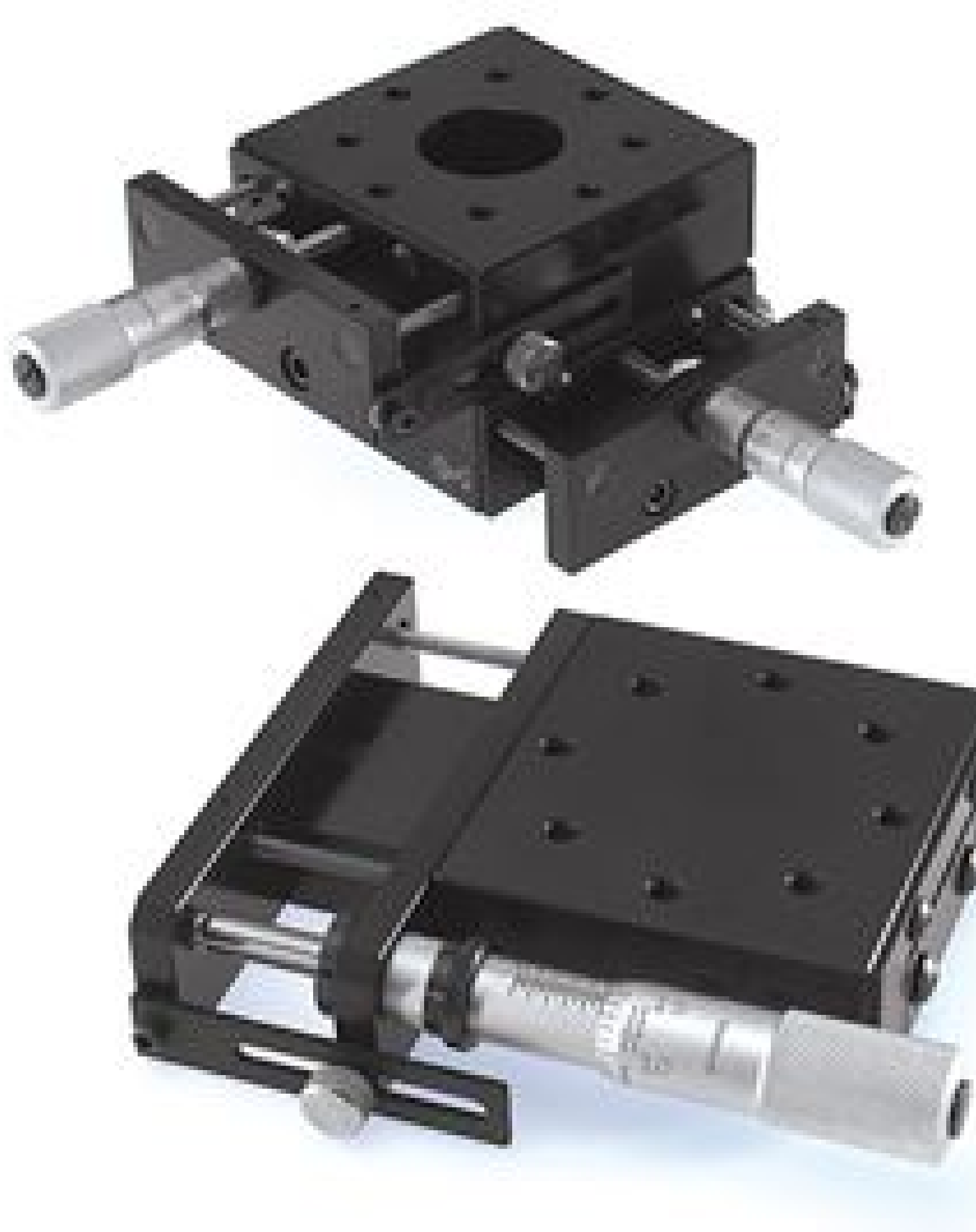

2.62" Center drive stage and its X-Y configuration

Stock **#37-978** [CONTACT US](#)



1



€535,00

ADD TO CART

Qty 1+

€535,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Type of Movement:
Linear (X)

Guide System:
Ball Bearing

Type of Drive:
Fine Screw (64 Pitch)

Drive Orientation:
Center Drive

Type:
English

Stage Size (mm):
66.5 x 66.5

Travel (inches):
0.75

Construction:
Aluminium Stage

Graduation (inches):
0.001

Height (inches):
1.00

Height (mm):
25.4

Load Capacity, Normal (lbs):
62

Note:
Solid Top

Stage Size (inches):
2.62 x 2.62

Straight Line Accuracy (inches):
0.00008/inch of travel

Weight (lbs):
0.72

Thrust Capacity, T_a (lbs):
10

Thrust Capacity, T_b (lbs):
2

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)