


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 0° AOI, 101 X 127mm, Cold Mirror

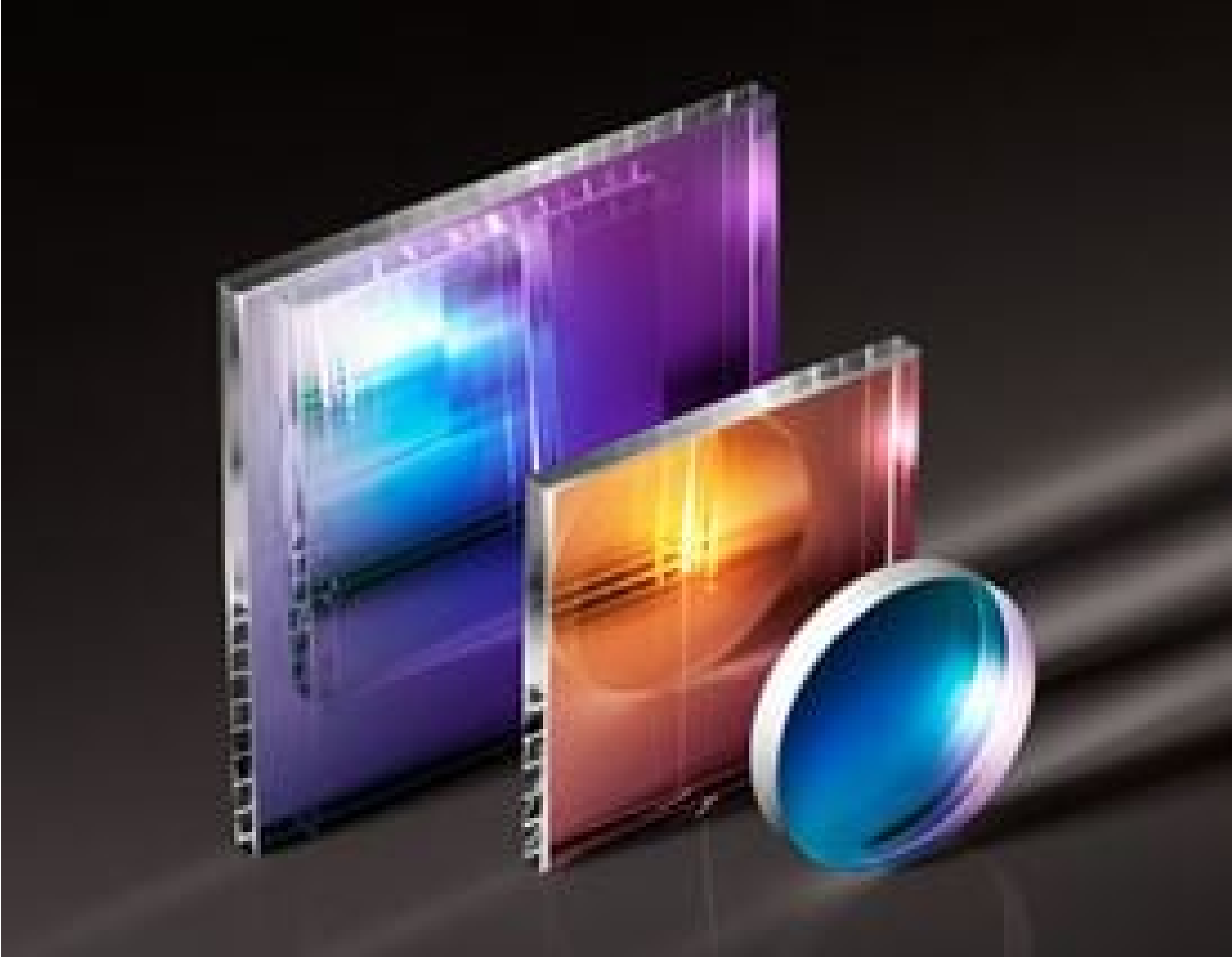

TECHSPEC High Performance Cold Mirrors

Stock #64-442 3-4 DAYS



1



€210,00

ADD TO CART

Qty 1-9

€210,00

Qty 10+

€185,60

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Angle of Incidence (°):
0

Coating:
Cold Mirror, 0°

Substrate: ☐
BOROFLOAT®

Dimensions (mm): 101.0 x 127.0
Surface Quality: 80-50
Thickness (mm): 3.30
Thickness Tolerance (mm): ±0.2
Transmission (%): Longpass Filter
Type: Cold Mirror
Dimensional Tolerance (mm): +0.0/-0.2
Coating Specification: R _{avg} ≥95% @ 400 - 690nm and T _{avg} ≥90% @ 750 - 1200nm AR Coating: R _{avg} <1% @ 700 - 1150nm
Wavelength Range (nm): 400 - 1150
Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant