


TECHSPEC® 0° AOI, 12.5mm Square, Cold Mirror

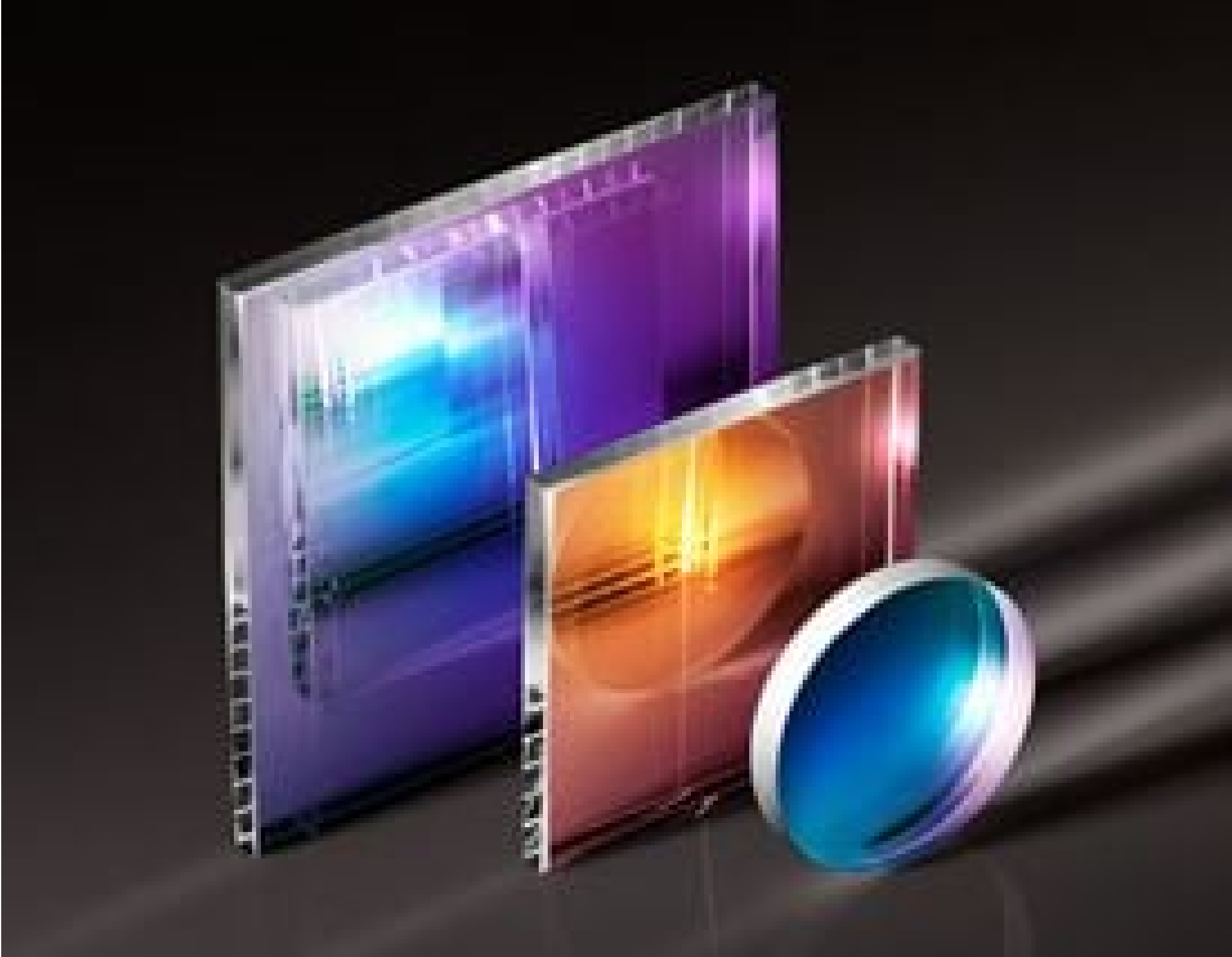

TECHSPEC High Performance Cold Mirrors

Stock #64-434 3-4 DAYS

⊖ 1 ⊕ **€44,50**

ADD TO CART

Qty 1-9
€44,50

Qty 10+
€38,80

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Angle of Incidence (°):
0

Coating:
Cold Mirror, 0°

Substrate: ☐
BOROFLOAT®

Dimensions (mm): 12.5 x 12.5
Surface Quality: 80-50
Thickness (mm): 1.10
Thickness Tolerance (mm): ±0.2
Transmission (%): Longpass Filter
Type: Cold Mirror
Dimensional Tolerance (mm): +0.0/-0.2
Coating Specification: R _{avg} ≥95% @ 400 - 690nm and T _{avg} ≥90% @ 750 - 1200nm AR Coating: R _{avg} <1% @ 700 - 1150nm
Wavelength Range (nm): 400 - 1150
Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant