


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 0° AOI, 50.0mm Diameter, Cold Mirror

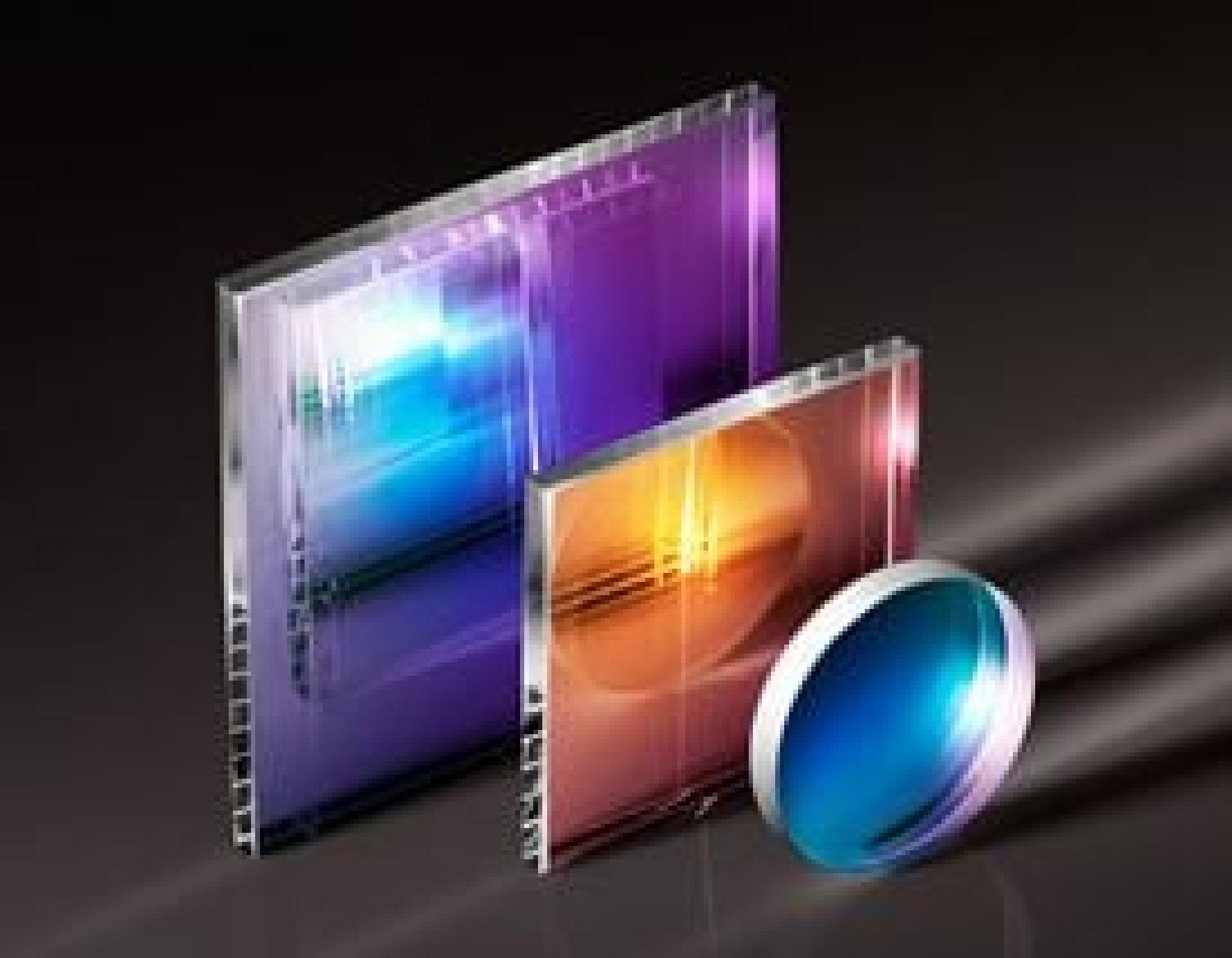

TECHSPEC High Performance Cold Mirrors

Stock #64-440 3-4 DAYS



1



€98,00

ADD TO CART

Qty 1-9

€98,00

Qty 10+

€86,20

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Angle of Incidence (°):
0

Coating:
Cold Mirror, 0°

Diameter (mm):
50.00

Substrate:  BOROFLOAT®
Surface Quality: 80-50
Thickness (mm): 3.30
Thickness Tolerance (mm): ±0.2
Transmission (%): Longpass Filter
Type: Cold Mirror
Dimensional Tolerance (mm): +0.0/-0.2
Coating Specification: R_{avg} ≥95% @400 - 690nm and T_{avg} ≥90% @ 750 - 1200nm AR Coating: R_{avg} <1% @ 700 - 1150nm
Wavelength Range (nm): 400 - 1150
Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant
