


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

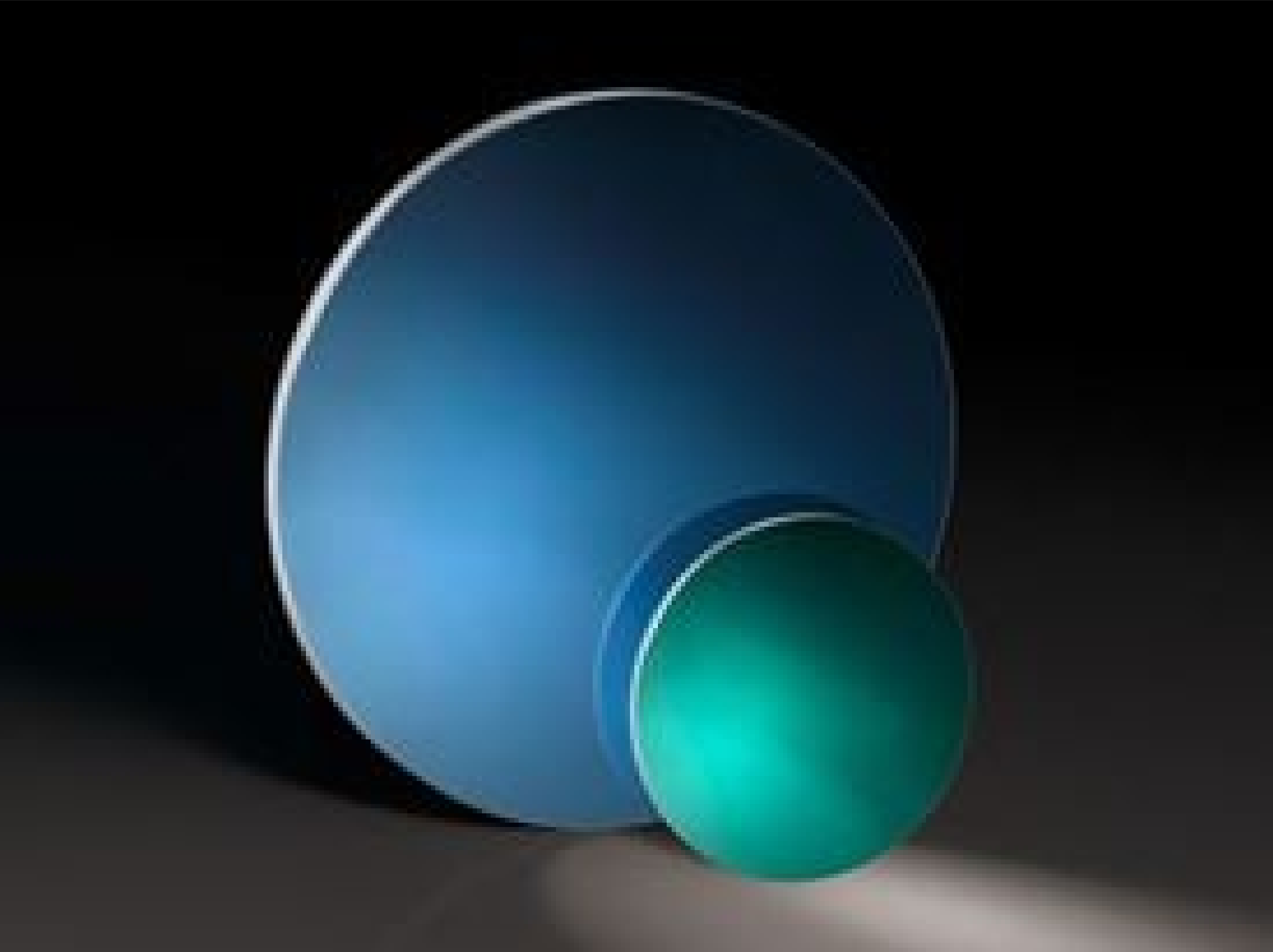

Colored Glass Replacement Longpass Filters

Stock #15-453 □ In Stock



1



€42,00

ADD TO CART

Qty 1-10

€42,00

Qty 11+

€37,80

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.70 ±0.127

Optical Density OD (Average):
≥5.0

Cut-On Wavelength (nm):
1,000.00 ±9

Substrate:  BOROFLOAT®
Operating Temperature (°C): -100 to +400
Coating: Dielectric
Index of Refraction n_d: 1.76
Rejection Wavelength (nm): 200 - 860
Surface Quality: 80-50
Thickness (mm): 1.10 ±0.10
Transmission (%): >90 (typical)
Transmission Wavelength (nm): 1035 - 2500
Type: Longpass Filter
Clear Aperture (%): 90
Environmental Durability: ML-STD-810, Method 507.3, Procedure III, Modified to 40 cycles
Physical Durability: ML-C-48497
Wavelength Range (nm): 200 - 2500

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View