


1064nm, 15mm Dia., Round Output, Diffractive Diffuser

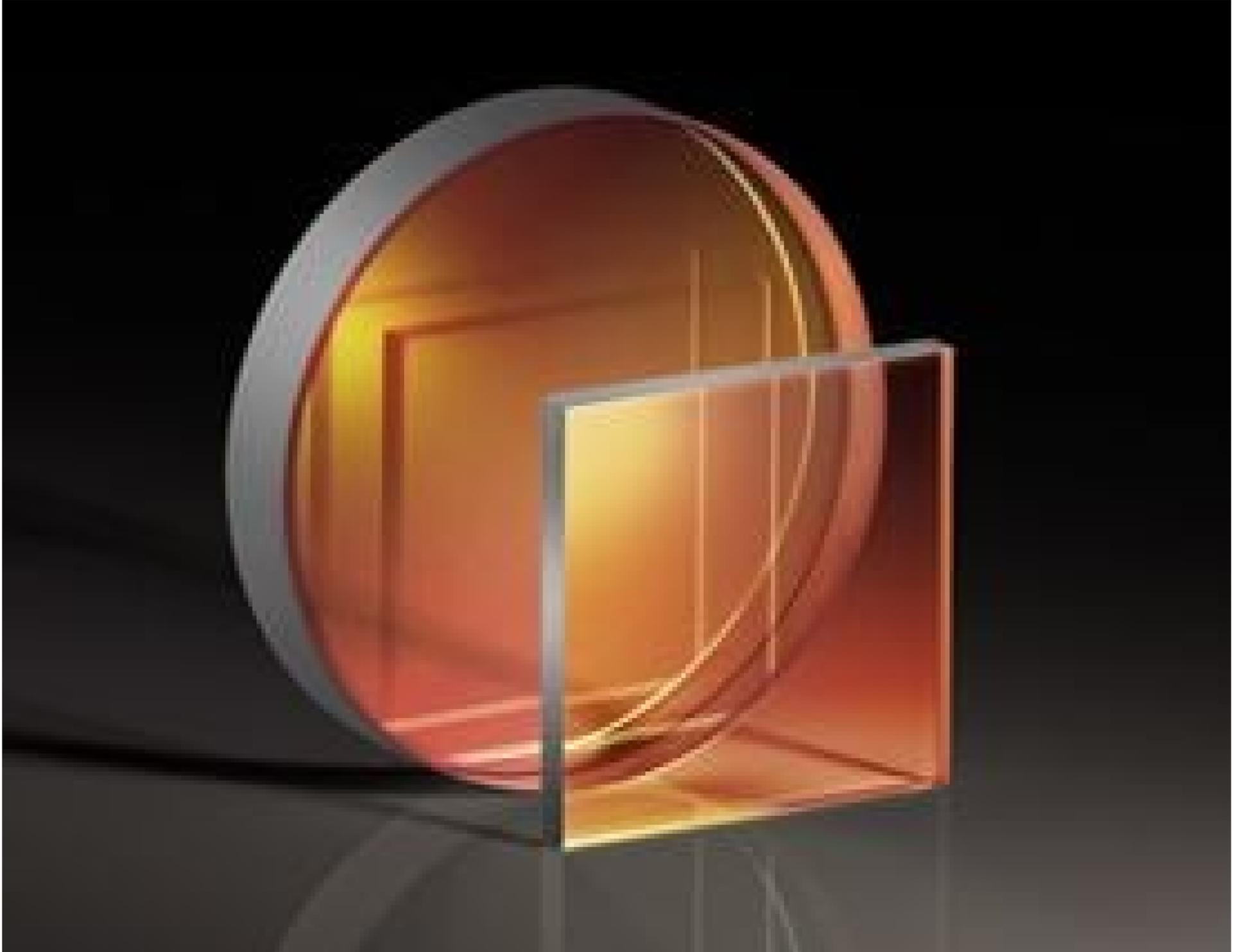

HOLO/OR Diffractive Diffusers

Stock #14-682 3-4 DAYS

1 **€1.170,00**

ADD TO CART

Qty 1+

€1.170,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Clear Aperture CA (mm):
13.00

Coating:
Laser V-Coat (1064nm)

Design Wavelength DWL (nm):
1064

Diameter (mm):
15.00 +0.05/-0.15

Substrate:
[Fused Silica](#) (Coming 7980)

Thickness (mm):
3.00 ±0.1

Input Beam Mode:
SMor MM

Minimum Beam Diameter (mm):
5

Output Shape:
Round

Overall Efficiency (%):
77

Full Angle (°) :
5.27

Damage Threshold, Reference:
[See Link for More Details](#)

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

Reach 233:
[Compliant](#)
