


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

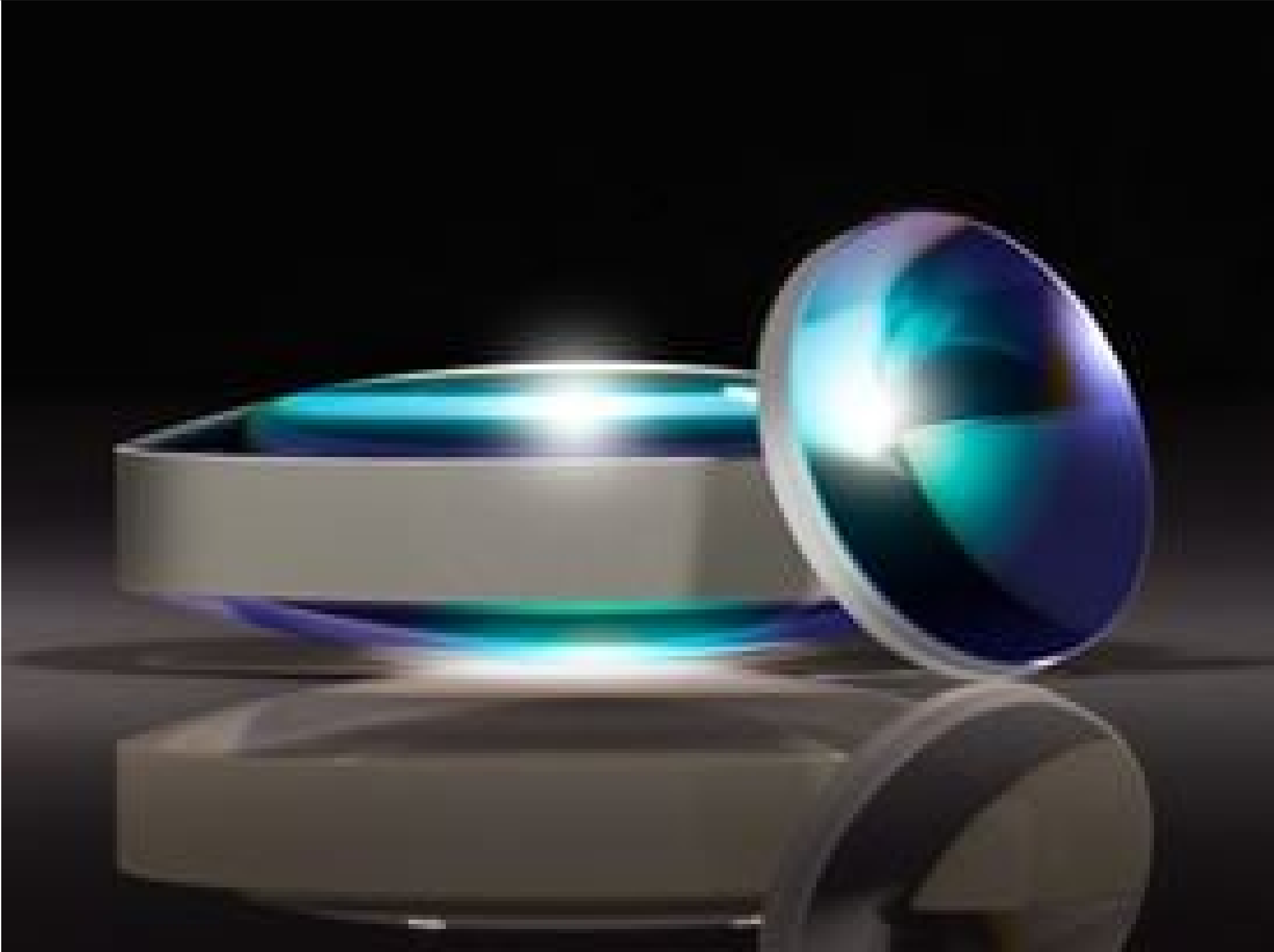

Stock #18-414 3-4 DAYS



1



€280,00

ADD TO CART

Qty 1-5

€280,00

Qty 6+

€224,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
10.00 +0.0/-0.025

Effective Focal Length EFL (mm):
10.00

Back Focal Length BFL (mm):
7.06

Substrate: N-BK7
Aspheric Design Wavelength (nm): 587.6
Asphere Figure Error, RMS @ 632.8nm: 0.4λ RMS and 2λ PV
Coating: Uncoated
Centering (arcmin): 3
Surface Quality: 40-20
Clear Aperture CA (mm): 9
Edge Thickness ET (mm): 5
Center Thickness CT (mm): 7.60 ±0.1
f#: 1.00
Bevel: None
Type: Aspheric Lens
Wavelength Range (nm): 330 - 2400
Radius R₁=R₂ (mm): 8.818
Power (diopters): 100.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View