


TECHSPEC®

10mm Protected Silver Coated, N-BK7 Right Angle Mirror

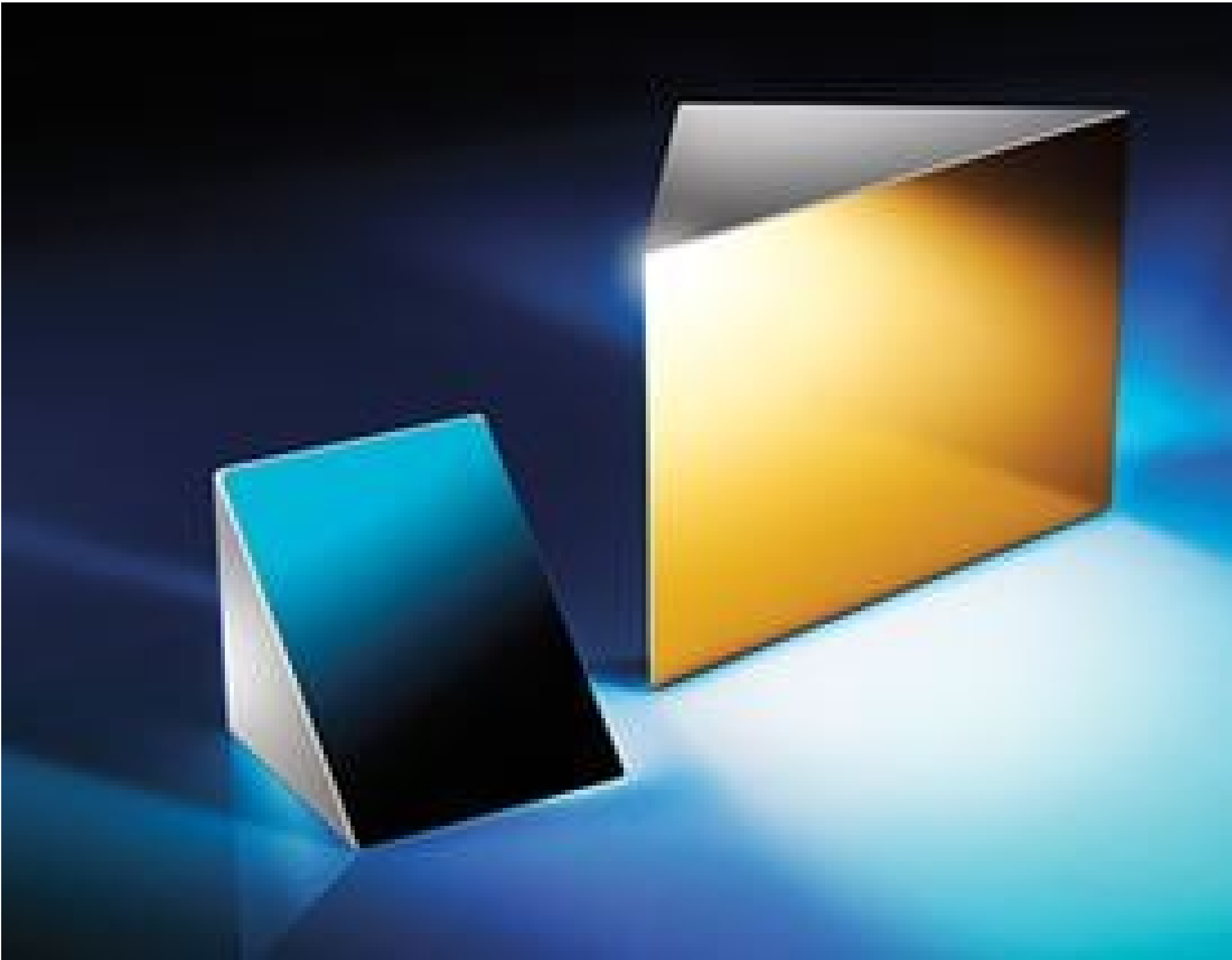

Stock #89-626 [CONTACT US](#)

-

1

+

€95,00

ADD TO CART

Qty 1-5
€95,00
Qty 6+
€76,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Substrate: ☐
N-BK7

Surface Quality:
40-20

Length of Legs (mm):
10.00

Dimensional Tolerance (mm): ±0.1
Coating Specification: R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 12.73 x 9.00
Length of Hypotenuse (mm): 14.10
Type: Right Angle Mirror
Wavelength Range (µm): 0.45 - 10
Wavelength Range (nm): 450 - 10000
Damage Threshold, Reference: ☐ 0.5 J/cm² @ 532nm & 1064nm, 10ns
Power (fringes) @ 632.8nm: 1.25
Irregularity (fringes) @ 632.8nm: 0.50

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant