

[See all 10 Products in Family](#)

1.0" Angle Mirror Mount with Mirror



1.0" Angle Mirror Mount with Mirror

Stock **#33-504** **7 In Stock**

-

1

+

€133⁰⁰

ADD TO CART

Volume Pricing	
Qty 1+	€133,00 each
Need More?	Request Quote

i Prices shown are exclusive of VAT/local taxes

Product Downloads

General	
Adjustable - Tip-Tilt	Type:
Square or Rectangular	Type of Optics:
Fixed mirror included	Note:
1.0" Angle	Type of Mount:


Physical & Mechanical Properties	
0.1	Weight (lbs):
Black Anodized Aluminum, Stainless Steel	Construction:
15	Fine Tilt Angle (°):
0.015	Resolution (inches):
15	Fine Tip Angle (°):
0.015	Adjustment Screw Pitch (inches):
0.75	Centerline Height (inches):
22 x 22	Pre-Mounted Mirror Size (mm):
Threading & Mounting	
3.0 - 25.4	Size of Compatible Optics (mm):
1/4-20	Compatible Post:
1.0 Sq.	Mounting Plate Size (inches):
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:

Product Details

- 1.0" or 1.5" Square Mounting Surface
- Two Fine Adjustment Screws (64-Pitch) Allow for Tilting
- Models with Pre-Mounted 1/4 Mirror Available
- Straight or Angle Configuration Options Available

Small Mirror Mounts are available with a 1.0" or 1.5" square mounting surface. These optical mirror mounts feature two stainless steel fine-resolution (64-pitch) mounting screws that provide precise tilting of the mounting surface in two directions. These optical mirror mounts are suitable for mounting to most post mounts. Small Mirror Mounts are constructed of black anodized aluminum and each type has an option for an included fixed mirror. These mounts feature mounting holes in various sizes, including 1/4-20 and 10-32.

Technical Information

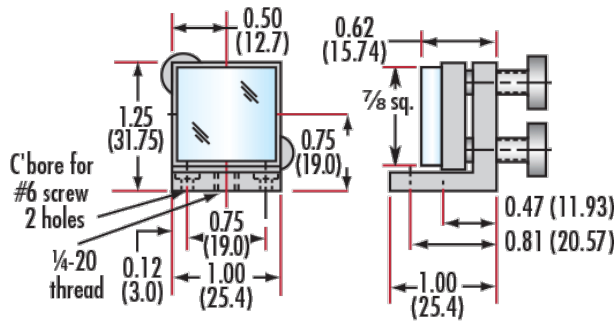

#33-504