


# 12.5mm Dia., 2mm Thick, Calcium Fluoride (CaF<sub>2</sub>) Diffuser

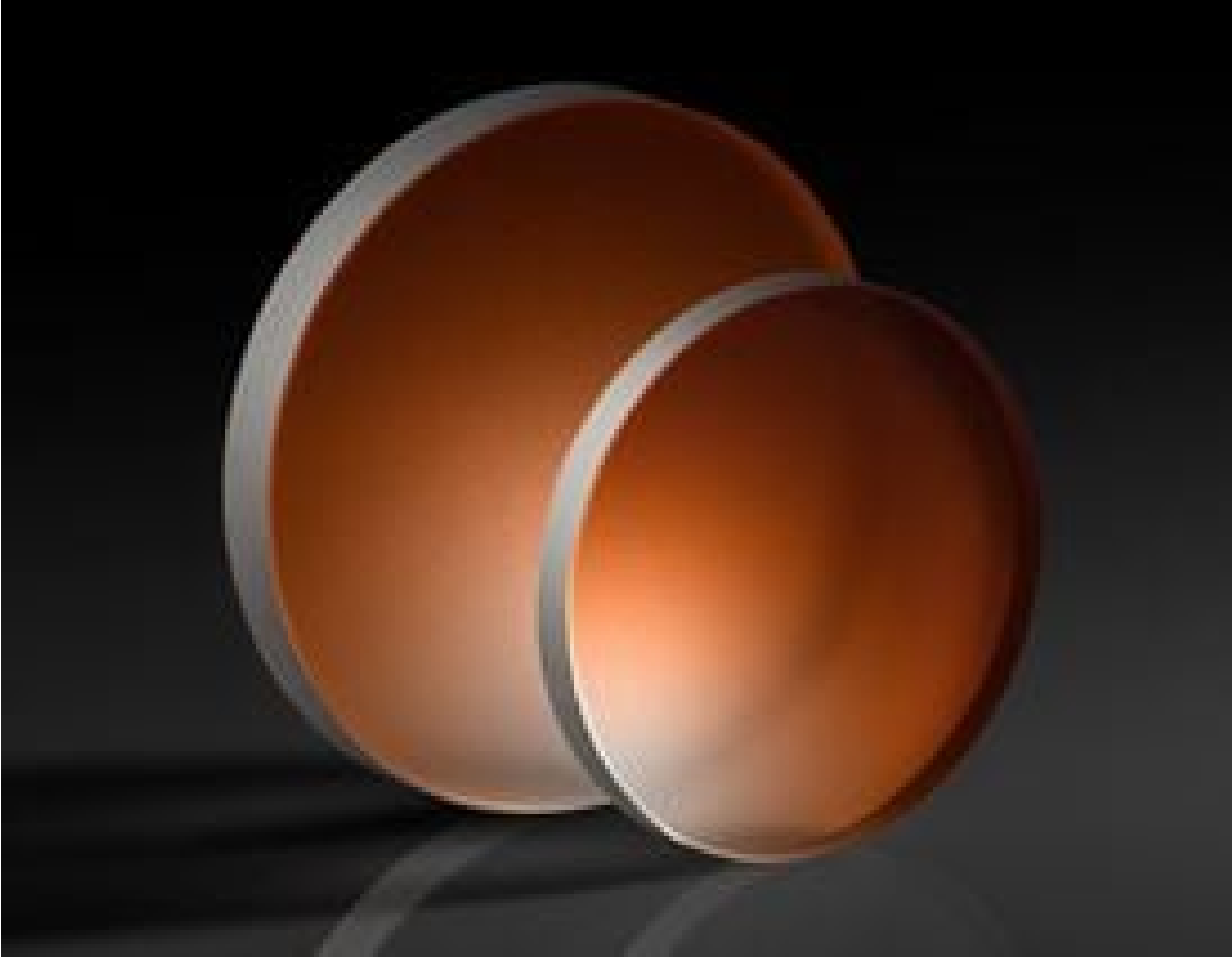

IR Calcium Fluoride (CaF<sub>2</sub>) Diffusers

Stock **#19-732** [CONTACT US](#)

-

1

+

**€135,00**

ADD TO CART

Qty 1-10

€135,00

Qty 11+

€121,50

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



**Diameter (mm):**  
12.50 +0.00/-0.10

**Coating:**  
Uncoated

**Edges:**

|                                                                                                         |
|---------------------------------------------------------------------------------------------------------|
| Fine Grind                                                                                              |
| <b>Substrate:</b> <input type="checkbox"/><br>Calcium Fluoride (CaF <sub>2</sub> )                      |
| <b>Thickness (mm):</b><br>2.00 ±0.10                                                                    |
| <b>Type:</b><br>IR Diffuser                                                                             |
| <b>Wavelength Range (nm):</b><br>300 - 7000                                                             |
| <b>Note:</b><br>Fine Grind first surface with a roughness (Ra) of <input type="checkbox"/> 0.75 microns |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |