


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 12.5mm Dia X 12.5mm FL Acylinder Lens, Uncoated

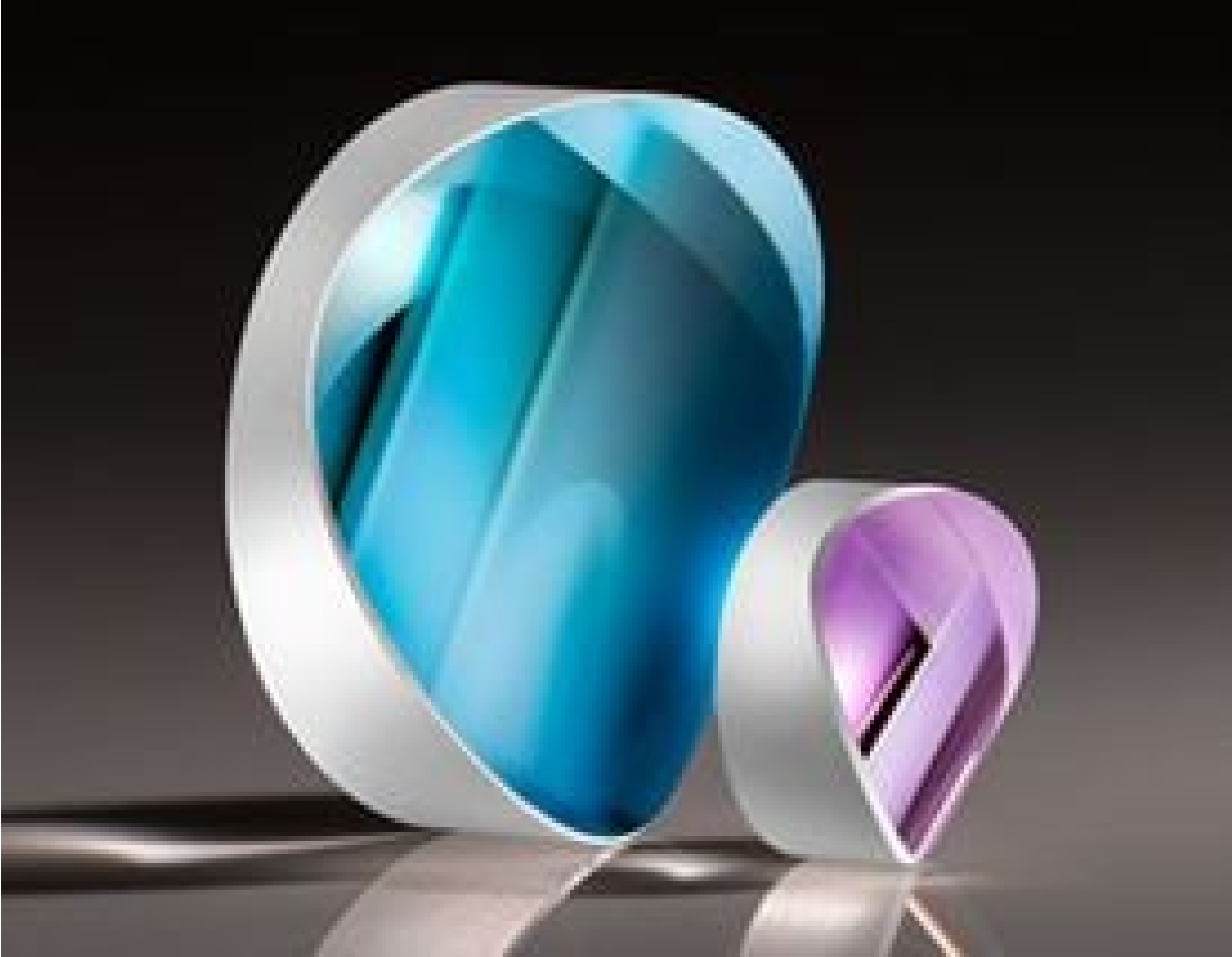

TECHSPEC Acylinder Lenses

Stock #86-031 3-4 DAYS



1



€600,00

ADD TO CART

Qty 1-5

€600,00

Qty 6+

€480,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50 +0.0/-0.1

Effective Focal Length EFL (mm):
12.50

Substrate: ☐
[N-SF5](#)

f/#: 1.00
Numerical Aperture NA: 0.50
Coating: Uncoated
Type: Acyliner Lens
Wavelength Range (nm): 380 - 2500
Back Focal Length BFL (mm): 9.2
Center Thickness CT (mm): 5.50
Center Thickness Tolerance (mm): ±0.1
Clear Aperture (%): 90.00
Edge Thickness ET (mm): 3.0
Focal Length Specification Wavelength (nm): 587.6
Surface Accuracy, RMS (µm): 1.0
Surface Quality: 60-40

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View