


TECHSPEC®

# 12.5mm Enhanced Aluminum Coated, N-BK7 Right Angle Mirror

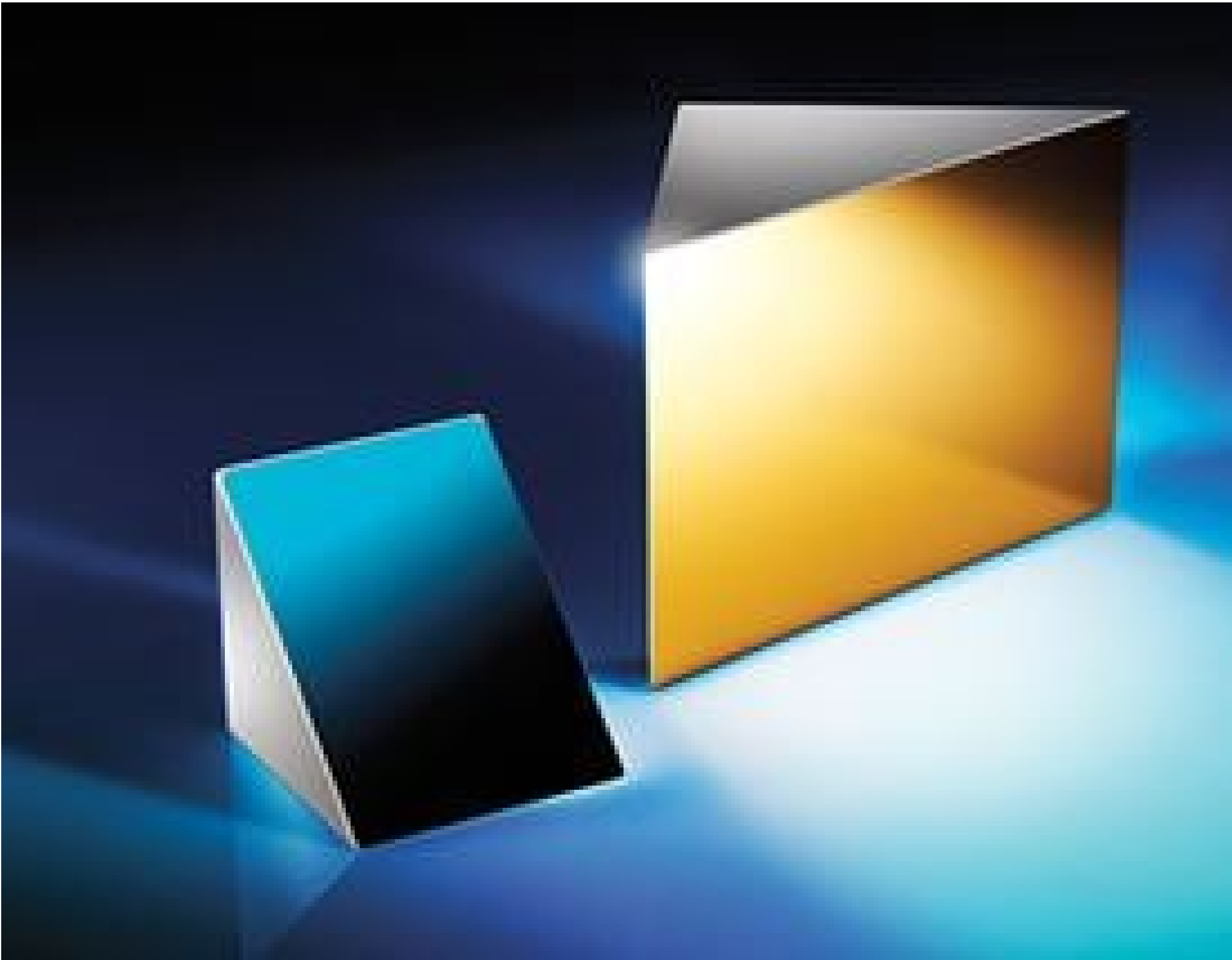

Stock #48-384 ☐ In Stock

-

1

+

€82,50

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-5                       |
| €82,50                        |
| Qty 6+                        |
| €66,00                        |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):  
λ/8

Substrate: ☐  
[N-BK7](#)

Surface Quality:  
40-20

|                                                                                                                                                                    |
|--------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <div>Length of Legs (mm):<br/>12.50</div>                                                                                                                          |
| <div>Dimensional Tolerance (mm):<br/>±0.1</div>                                                                                                                    |
| <div>Coating Specification:<br/>R<sub>avg</sub> &gt;95% @ 450 - 650nm</div>                                                                                        |
| <div>Coating:<br/>Enhanced Aluminum (450-650nm)</div>                                                                                                              |
| <div>Coating Type:<br/>Metal</div>                                                                                                                                 |
| <div>Angle Tolerance (arcmin):<br/>±2</div>                                                                                                                        |
| <div>Bevel:<br/>Protective bevel as needed</div>                                                                                                                   |
| <div>Clear Aperture CA (mm):<br/>15.91 x 11.25</div>                                                                                                               |
| <div>Length of Hypotenuse (mm):<br/>17.70</div>                                                                                                                    |
| <div>Type:<br/>Right Angle Mirror</div>                                                                                                                            |
| <div>Wavelength Range (µm):<br/>0.45 - 0.65</div>                                                                                                                  |
| <div>Wavelength Range (nm):<br/>450 - 650</div>                                                                                                                    |
| <div>Damage Threshold, Reference: <br/>0.2 J/cm<sup>2</sup> @ 532nm, 10ns</div> |

## Regulatory Compliance

|                                                                 |
|-----------------------------------------------------------------|
| <div>RoHS 2015:<br/><a href="#">Compliant</a></div>             |
| <div>Reach 219:<br/><a href="#">Compliant</a></div>             |
| <div>Certificate of Conformance:<br/><a href="#">View</a></div> |