


TECHSPEC® 12.5mm Minor Axis Uncoated, Fused Silica Brewster Window

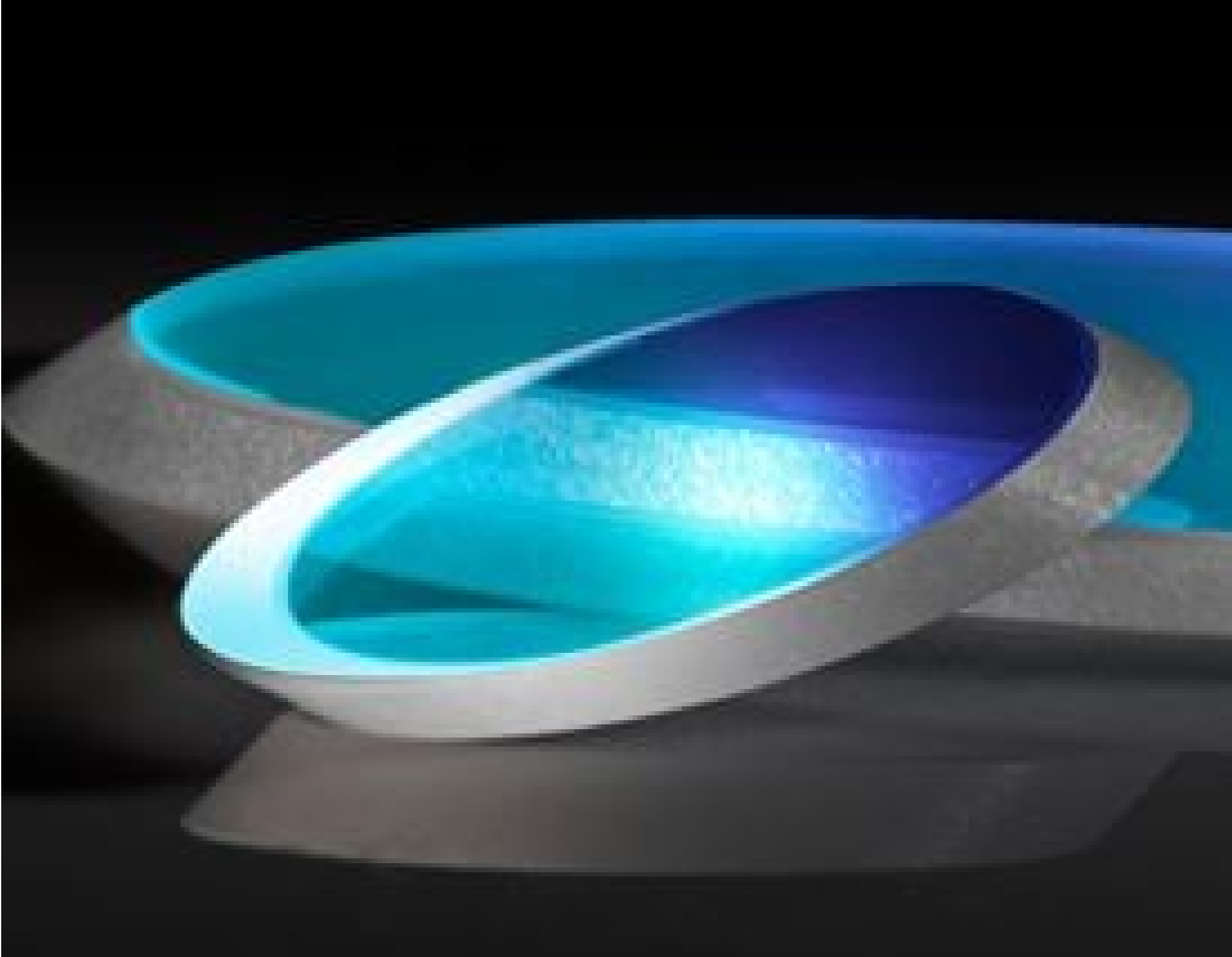

Stock **#65-824** 3-4 DAYS

- 1 + **€90,00**

ADD TO CART

Qty 1-10
€90,00
Qty 11+
€81,00
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Clear Aperture CA (mm):
11.25 x 19.90

Thickness (mm):
2.00 ±0.20

Coating:
Uncoated

Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.52 (+5 to +35°C) 0.57 (0 to +200°C) 0.48 (-100 to +200°C)
Design Wavelength DWL (nm): 632.8
Edges: Fine Ground
Index of Refraction n_d: 1.458
Major Axis (mm): 22.11
Minor Axis (mm): 12.50 +0.00/-0.25
Parallelism (arcsec): ≤10
Substrate: ☐ Fused Silica (Corning 7980)
Surface Quality: 10-5
Transmitted Wavefront, P-V: λ/10
Type: Linear Polarizer
Wavelength Range (nm): 200 - 2200
Young's Modulus (GPa): 73
Construction: Brewster Window

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View