

[See all 60 Products in Family](#)

**TECHSPEC® 125mm, Side Drive, Standard Top, English Stage**



TECHSPEC® Crossed-Roller Bearing Linear Translation Stages (Standard-Top Model)



Stock #66-453 **1 In Stock**

⊖ 1 ⊕ €665.<sup>00</sup>

**ADD TO CART**

Volume Pricing	
Qty 1-2	€665,00 each
Qty 3+	€580,50 each
Need More?	<a href="#">Request Quote</a>

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

**General**


English **Type:**

**Physical & Mechanical Properties**


Linear (X) **Type of Movement:**




**30mm Standard-Top Stages - Center Drive**

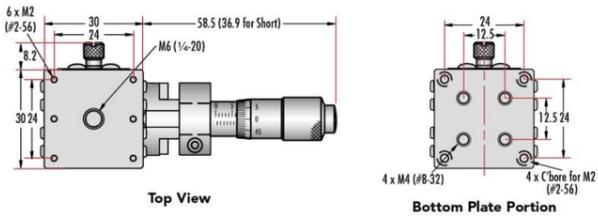


**30mm Standard-Top Stages - Side Drive**

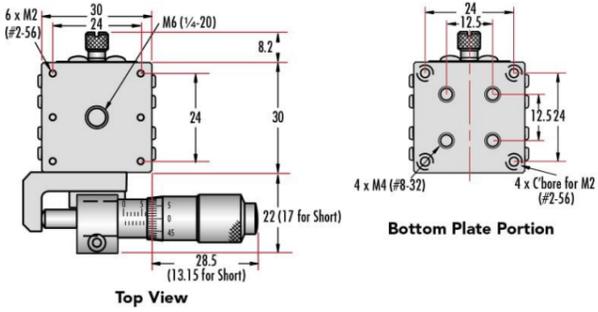


**40mm Standard-Top Stages - Center Drive**

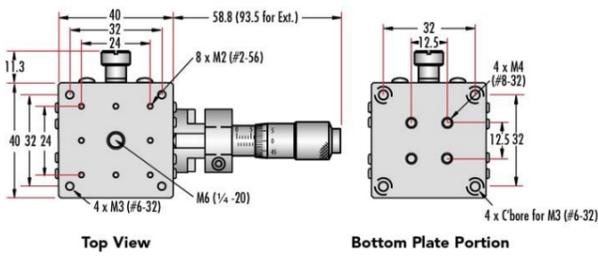


**40mm Standard-Top Stages - Side Drive**

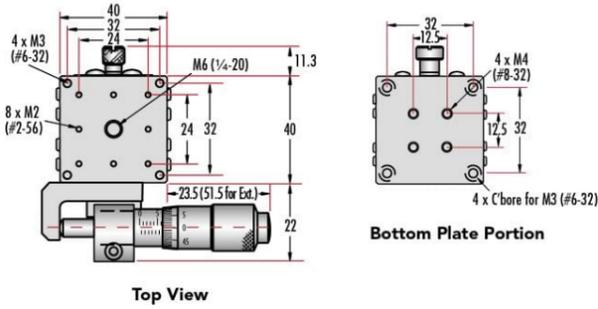


**70mm Standard-Top Stages - Center Drive**

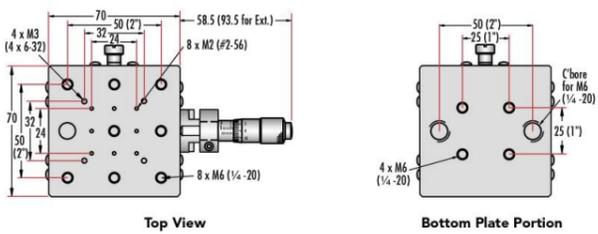

**70mm Standard-Top Stages - Side Drive**

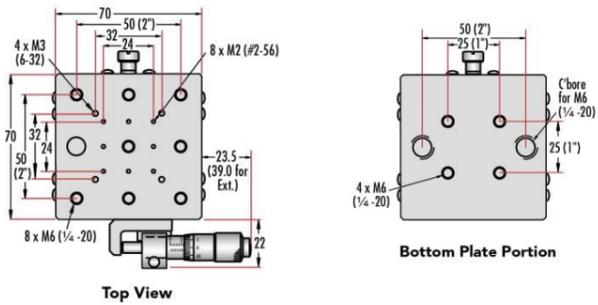

**125mm Standard-Top Stages - Center Drive**

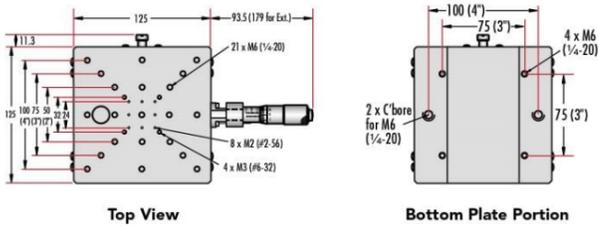

**125mm Standard-Top Stages - Side Drive**

