


TECHSPEC® 125mm, Side Drive, Thru-Hole, English Micrometer Stage

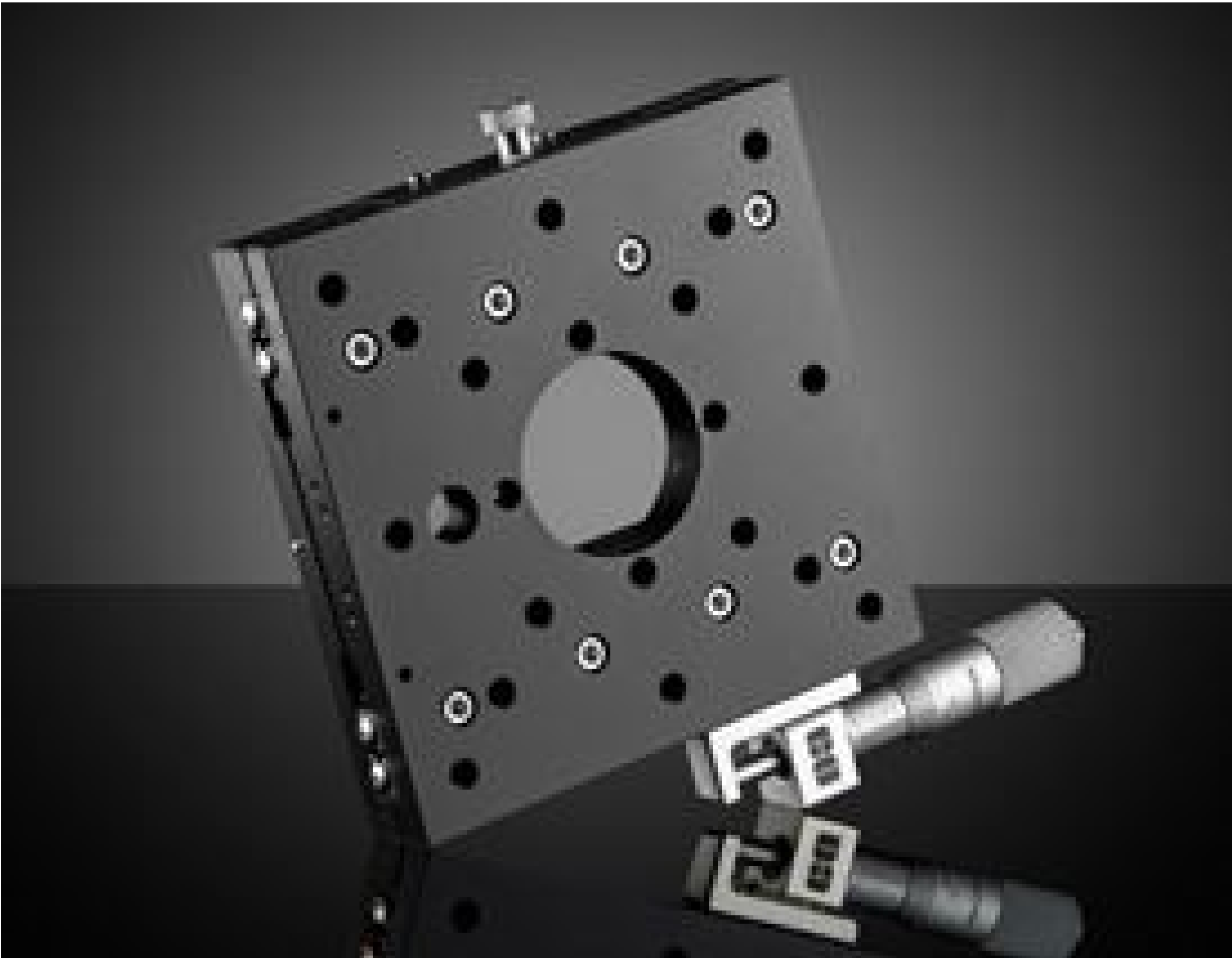

Stock #66-466 3-4 DAYS

⊖ 1 ⊕ **€620,00**

ADD TO CART

Qty 1-2
€620,00

Qty 3+
€543,40

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
English Micrometer

Drive Orientation:

Side Drive
Type: English
Stage Size (mm): 125 x 125
Travel (inches): 1
Center Hole: M42 x 0.75
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.635
Load Capacity (kg): 20
Mounting Threads: (1) M42 x 0.75, (20) 1/4-20
Stage Size (inches): 4.92 x 4.92
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)