


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

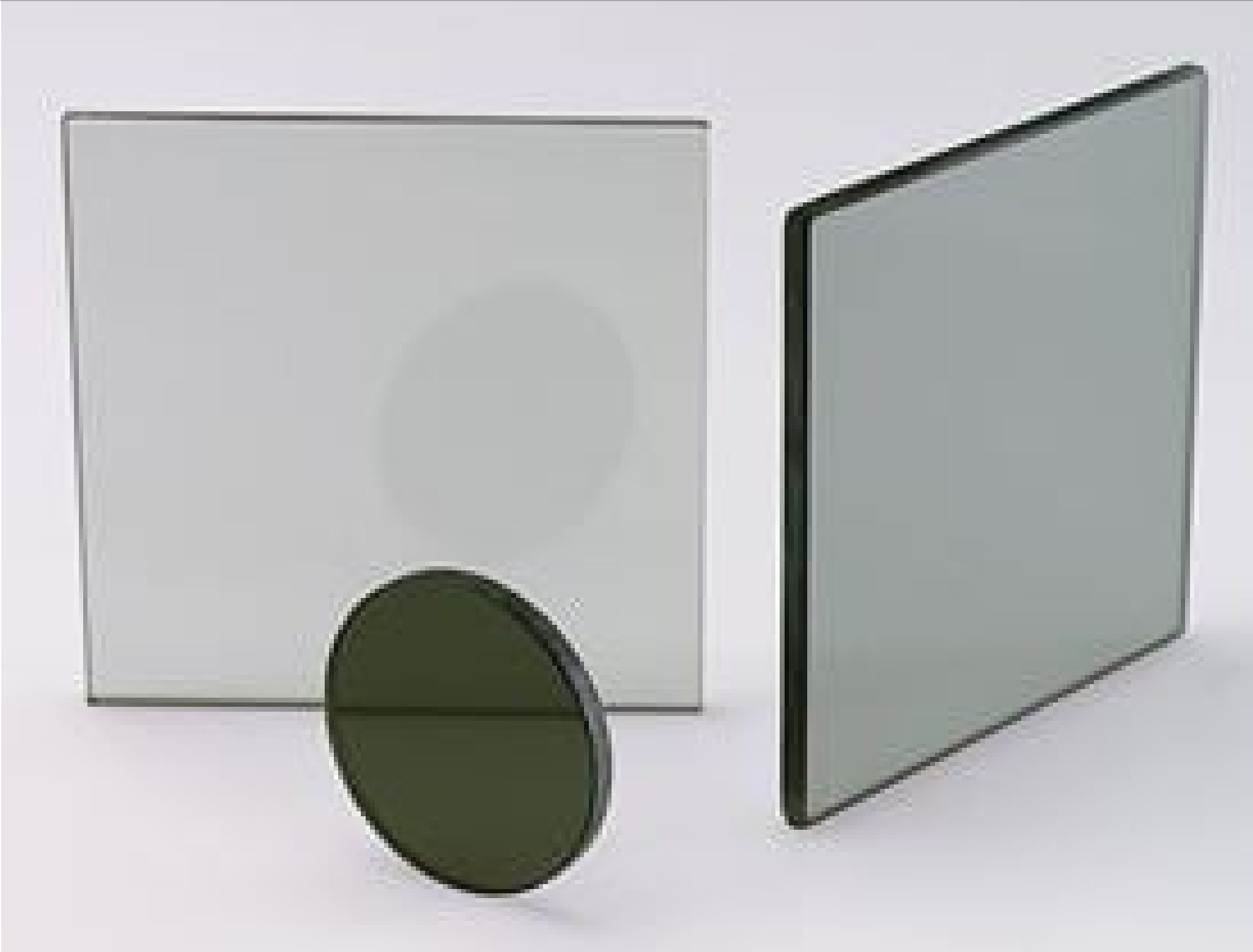

Stock #48-091 3-4 DAYS



1



€44,00

ADD TO CART

Qty 1-10

€44,00

Qty 11+

€39,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):  
25.00

Optical Density OD (Average):

|                                                               |
|---------------------------------------------------------------|
| 1.5 ±0.05                                                     |
| <b>Glass/Filter Number:</b><br><a href="#">Hoya ND-0.3</a>    |
| <b>Substrate:</b> <input type="checkbox"/><br>ND Filter Glass |
| <b>Coating:</b><br>Uncoated                                   |
| <b>Index of Refraction <math>n_d</math>:</b><br>1.51          |
| <b>Surface Quality:</b><br>80-50                              |
| <b>Transformation Temperature (°C):</b><br>490                |
| <b>Thickness (mm):</b><br>1.50                                |
| <b>Thickness Tolerance (mm):</b><br>±0.5                      |
| <b>Transmission (%):</b><br>3.0 (average)                     |
| <b>Type:</b><br>Neutral Density Filter                        |
| <b>Blocking Wavelength Range (nm):</b><br>400 - 700           |
| <b>Dimensional Tolerance (mm):</b><br>±0.1                    |
| <b>Parallelism (mm):</b><br><0.02                             |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 224:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |