


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 15mm Aluminum Coated Dove Prism

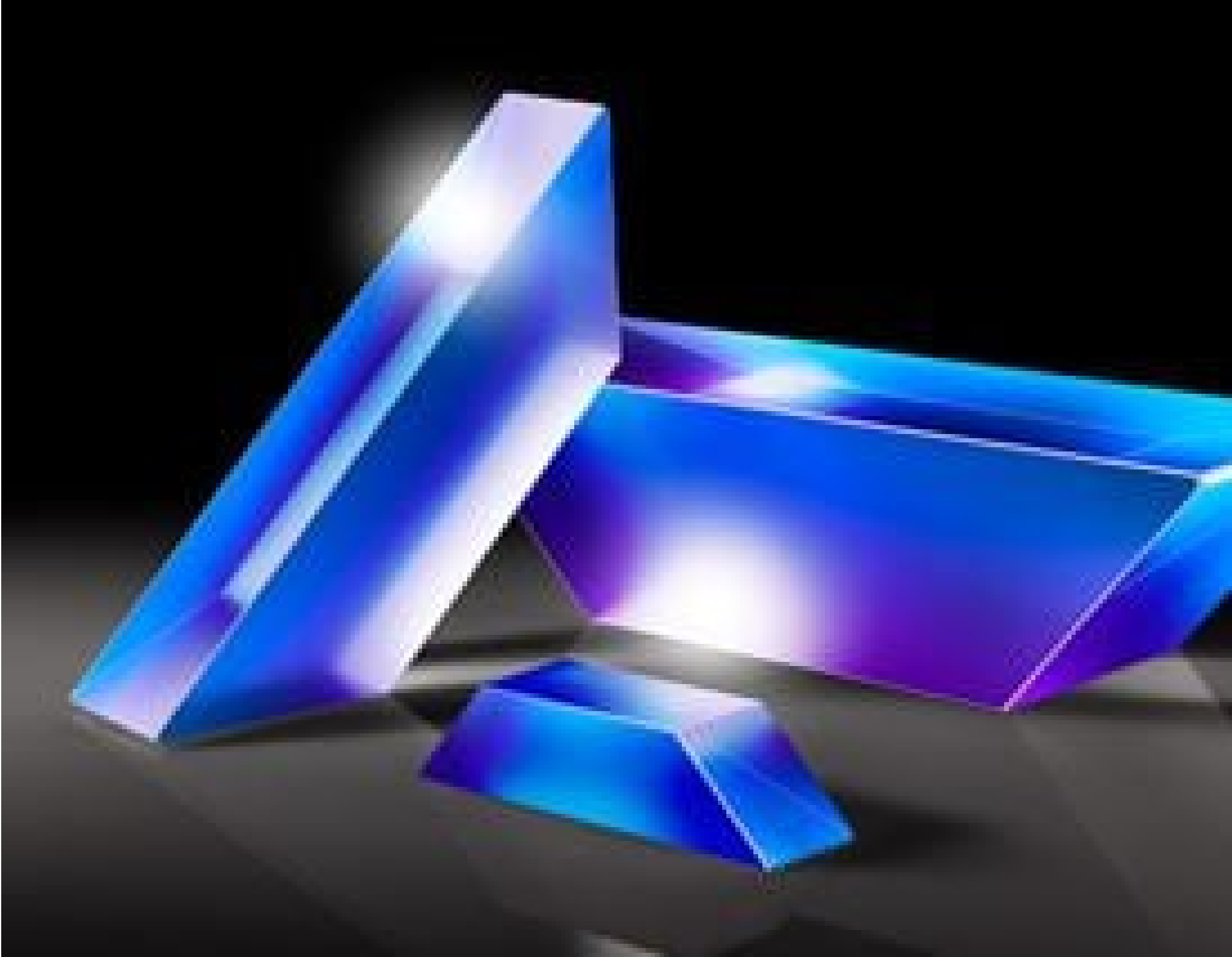

Stock #45-815 3-4 DAYS



1



€128,00

ADD TO CART

Qty 1-5

€128,00

Qty 6+

€115,20

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Aluminum with protective overcoat

Substrate: ☐
[N-BK7](#)

Height (mm):
15.0

Length (mm): 62.50
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2
Bevel: Protective bevel as needed
Image Orientation: Right-Handed
Coating Specification: Reflective Surfaces: R _{avg} >85% FROM400-700nm, @ 45° AOI
Ray Deviation (°): 180
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)
Damage Threshold, Reference: ☐ 0.3 J/cm² @ 532nm & 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View