

[All Products](#) / [Optics](#) / [Optical Filter](#)
/ [Hard Coated OD 4.0 50nm Bandpass](#)

[See all 159 Products in Family](#)

TECHSPEC®

1600nm CWL, 12.5mm Bandpass Filter

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region: European Union

Submit



Stock #87-859 [CONTACT US](#)

1

€240^{,00}

ADD TO CART

Volume Pricing	
Qty 1-5	€240,00 each
Qty 6-25	€192,00 each
Qty 26-49	€180,00 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

- STEP:step
- Curve:pdf
- PDF Drawing:pdf
- IGES:igs
- eDrawing:eprt
- EO Spec Sheet
- [Download All](#)

General

Type: Bandpass Filter

Physical & Mechanical Properties

Diameter (mm): 12.50 +0.0/-0.1

Clear Aperture CA (mm): 8.5

Construction: Mounted in Black Anodized Ring

Physical Durability: Adhesion per MIL-PRF-13830B, Section C.4.5.12
Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11
Cleaning per MIL-C-48497A Section 4.5.4.2

Substrate Thickness (mm): 3.5 ±0.5

Optical Properties

Angle of Incidence (°): 0

Bandwidth (nm): 45

Optical Density OD (Average): ≥4.0

Center Wavelength CWL (nm): 1,600.00

Full Width-Half Max FWHM (nm): 50.00

Substrate: [i](#) Optical Glass

Minimum Transmission: >90

Coating: Hard Coated

(%):

Surface Quality: 80-50

Blocking Wavelength Range (nm): 200 - 1800

Threading & Mounting

Mount Thickness (mm): 5.0 ±0.1

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

Environmental & Durability Factors

Environmental Durability: Humidity per MIL-STD-810H, Section 507.6
Temperature per MIL-STD-810H, Section 501.7 and 502.7

Regulatory Compliance

RoHS 2015: **Compliant**

Certificate of Conformance: **View**

Reach 247: **Compliant**

Need different specs or modifications?

Edmund Optics offers comprehensive custom manufacturing services for optical and imaging components tailored to your specific application requirements. Whether in the prototyping phase or preparing for full-scale production, we provide flexible solutions to meet your needs. Our experienced engineers are here to assist—from concept to completion.

Our capabilities include:

- Custom dimensions, materials, coatings, and more
- High-precision surface quality and flatness
- Tight tolerances and complex geometries
- Scalable production—from prototype to volume

Learn more about our [custom manufacturing capabilities](#) or submit an inquiry [here](#).

Product Details

- High Transmission, Deep Blocking
- Broad Bandwidths Ideal for Imaging Applications
- Available in VIS and IR Center Wavelengths
- **Hard Coated OD 4.0 10nm** and **25nm** Bandpass Filters Also Available

TECHSPEC® Hard Coated OD 4.0 50nm Bandpass Filters are ideal for imaging applications, including machine vision inspection, fluorescence microscopy, and a variety of biotech instrumentation. These bandpass filters eliminate unwanted background noise and enhance the signal-to-noise ratio within imaging applications. Unlike traditional filters, these hard coated filters are fabricated using only a single substrate. TECHSPEC® Hard Coated OD 4.0 50nm Bandpass Filters offer deeper blocking, higher transmission, and steeper slopes than traditional coated filters. Hard Coated OD 4.0 **10nm** and **25nm** are also available.

Note: These filters are optimized for high spectral performance rather than high Laser Induced Damage Thresholds (LIDT). A typical LIDT for these filters is 1 J/cm² @ 532nm, 10ns. Please [contact us](#) if you require a filter with a higher LIDT value.

Technical Information

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.

Related Products



Manual Cage Filter Wheel




Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:




Hard Coated OD 4.0 25nm Bandpass Filters

Frequently Purchased Together

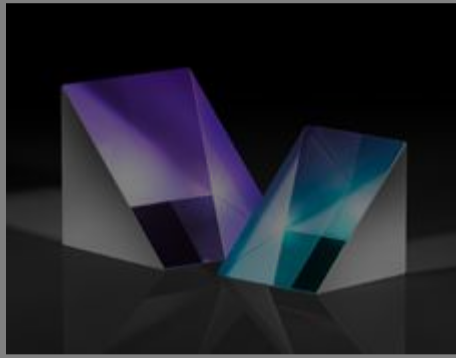

#32-336 - 25mm, Uncoated, N-BK7 Right Angle Prism
€79,50

Qty

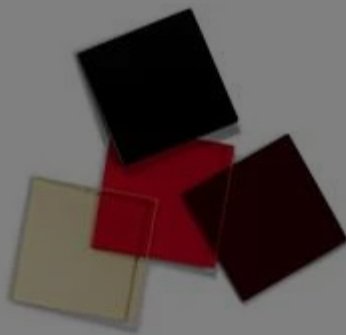

#32-760 - SCHOTT RG-1000, 25.4mm Dia., 3mm Thick, Colored Glass Longpass Filter
€46,00

Qty



#45-760 - 45mm Focal Length f/4, Relay Lens
€394,00

Qty







 















 



 
 
 
 
 



#45-762 - 30mm Focal Length f/8, Relay Lens
€230,00

Qty







Compatible Mounts

	Title	Type	Compare	Stock Number	Price	Buy
		Fixed		#13-789	€19,50 Request Quote	10 In Stock <input type="text" value="1"/>
		Fixed		#13-790	€19,50 Request Quote	17 In Stock <input type="text" value="1"/>
		Adjustable - Tip-Tilt		#15-865	€43,50 Request Quote	CONTACT US <input type="text" value="1"/>
		Fixed		#36-416	€59,00 Request Quote	17 In Stock <input type="text" value="1"/>
		Fixed		#36-418	€59,00 Request Quote	10 In Stock <input type="text" value="1"/>
		Fixed		#03-668	€63,00 Request Quote	20+ In Stock <input type="text" value="1"/>
		Fixed		#36-605	€83,00 Request Quote	20+ In Stock <input type="text" value="1"/>
		Adjustable - Tip-Tilt		#58-850	€93,00 Request Quote	20+ In Stock <input type="text" value="1"/>

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 12.5/12.7mm Optic Dia., Kinematic Mount and Rotation				€96,50	20+ In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Compact Kinematic Mount, 2-Screws					20+ In Stock <input type="text" value="1"/> 
MORE+	 5.0 - 25.0mm Optic Height, Metric Bar-Type Optic Holder	Fixed		#55-529	€102,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Kinematic Mount, 3-Screws	Adjustable - Tip-Tilt		#58-853	€104,00 Request Quote	15 In Stock <input type="text" value="1"/> 
MORE+	 7.0 - 40.0 Optic Height, English Bar-Type Optic Holder	Fixed		#03-676	€106,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 10.0 - 60.0mm Optic Height, Metric Bar-Type Optic Holder	Fixed		#55-530	€108,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 7.0 - 67.0 Optic Height, English Bar-Type Optic Holder	Fixed		#03-669	€116,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Compact Kinematic Mount, 3-Screws	Adjustable - Tip-Tilt		#34-721	€117,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 8.0 - 118.0 Optic Height, English Bar-Type Optic Holder	Fixed		#03-666	€120,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 4.0 - 36.0mm Optic Dia., Self-Centering Jaw Clamp	Fixed		#16-077	€157,00 Request Quote	5 In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Stainless Steel Kinematic Mount, 2-Screws	Adjustable - Tip-Tilt		#26-814	€161,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Stainless Steel Kinematic Mount, 3-Screws	Adjustable - Tip-Tilt		#26-817	€182,00 Request Quote	20+ In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., X-Y Translating Optic Mount	Adjustable - Linear (XY)		#62-955	€261,00 Request Quote	5 In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Top Adjust Kinematic Mount, Lead Screw	Adjustable - Tip-Tilt		#13-768	€270,00 Request Quote	6 In Stock <input type="text" value="1"/> 
MORE+	 12.5/12.7mm Optic Dia., Top Adjust Kinematic Mount, Micrometer	Adjustable - Tip-Tilt		#13-769	€289,00 Request Quote	5 In Stock <input type="text" value="1"/> 
MORE+	 5.0 - 100.0mm Optic Dia., Self-Centering Jaw Clamp	Fixed		#16-078	€410,00 Request Quote	CONTACT US <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
 	12.5/12.7mm Optic Dia., Precision Gi Mount				€421,00	7 In Stock <input type="text" value="1"/> 
 	12.5/12.7mm Optic Dia., Translating Mount					5 In Stock <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

Check out our full selection of mounts [here](#).