

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#) / [HPi Series Fixed Focal Length Lenses](#)

[See all 28 Products in Family](#)

TECHSPEC® 16mm



16mm HPI Series Fixed Focal Length Lens

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region: European Union

Submit

1

€710⁰⁰

ADD TO CART

Volume Pricing

Qty 1+ €710,00 each

Need More? [Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Product Downloads

- STEP:step
- PDF Drawing:pdf
- IGES:igs
- Zemax
- eDrawing:eprt
- EO Spec Sheet

General

Product Family: HPi Series

Type: Fixed Focal Length Lens

Physical & Mechanical Properties

Iris Option: Fixed

Length (mm): 64.20

Maximum Diameter (mm): 48

Outer Diameter (mm): 48

Weight (g): 117

Maximum Rear Protrusion (mm): 0

Optical Properties

Horizontal Field of View @ Max Sensor Format: 127mm - 53°

Field of View at Max Sensor Format: Horizontal: 112.4mm - 47.2°
Vertical: 82.7mm - 35.9°
Diagonal: 144.7mm - 58°

Horizontal Field of View, 1.1" Sensor: 113.4mm - 47.6°

Horizontal Field of View, 1" Sensor: 101.3mm - 43.2°

Horizontal Field of View, 2/3" Sensor: 68.4mm - 30.1°

Horizontal Field of View, 1/1.8" Sensor: 55.7mm - 24.8°

Horizontal Field of View, 1/2" Sensor: 49.4mm - 22.1°

Horizontal Field of View, 1/2.5" Sensor: 44.7mm - 20.0°

Horizontal Field of View, 1/3" Sensor: 36.9mm - 16.6°

Horizontal Field of View, 1/4" Sensor: 27.6mm - 12.5°

Maximum Image Circle (mm): 17.60

Numerical Aperture NA, Object Side: 0.0058

Number of Elements (Groups):	9 (7)	Focal Length FL (mm):	16.00		
Working Distance (mm):	100 - ∞	Aperture:	f/11		
Coating:	λ/4 MgF ₂	<div style="border: 1px solid black; padding: 10px; text-align: center;"> <p>Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.</p> <p>Select Your Country/Region:</p> </div>			
Entrance Pupil Position (mm):	27.28			Principal Plane (mm):	
Image Space Principal Plane (mm):	4.08			Maximum Distortion (%):	-3.76
Exit Pupil Position (mm):	-58.81	Optimized Working Distance (mm):	400 - 2000		
Lens Wavelength Range:	VIS				

Sensor

Optimized Sensor Format:	1"	Maximum Sensor Format:	1.1"
Pixel Size (μm):	1.85		

Threading & Mounting

Filter Thread:	M46.0 x 0.75 (Female)	Mount:	C-Mount
-----------------------	-----------------------	---------------	---------

Environmental & Durability Factors

Storage Temperature (°C):	-20 to +60	Type of Ruggedization:	Industrial (Fixed Aperture with Simplified Mechanics)
----------------------------------	-------------------	-------------------------------	-------------------------------------------------------

Regulatory Compliance

Certificate of Conformance:	View		
------------------------------------	----------------------	--	--

Product Details

- 1.1", C-Mount Lens
- Up to 20 MegaPixels, 1.85μm Pixel Size Sensors
- Instrumentation (HPi) versions of our HP Series Lenses with Streamlined Mechanical Designs and Fixed Apertures
- 16mm to 50mm Focal Length
- **Ruggedized (HPr) Designs** Also Available

TECHSPEC® HPi Series Fixed Focal Length Lenses offer the same high resolution performance as the TECHSPEC HP Series Lenses with a streamlined design. The simplified mechanical design enables a more compact size with a reduction in cost and weight, making them ideal for OEM volume applications. Featuring a wide range of fixed aperture versions and an adjustable focus, TECHSPEC HPi Series Fixed Focal Length Lenses offer the ideal combination of simplicity and flexibility required for industrial applications. Call for OEM Quantity Pricing.

Edmund Optics has created a family of high performance optical designs (the HP Series family) and developed three customized optomechanical solutions targeted for specific applications. These lens sub-families utilize the same optics as the HP Series lenses providing the same optical performance in a variety of optomechanical solutions to meet your application requirements:

- **HP Series:** Features locking cam focus and iris adjustment. This is the most adjustable version of these optical designs and is the typical high quality machine vision lens.
- **HPi Series:** Simplified mechanics featuring fixed apertures with compact housing. **Industrial Ruggedization** for reduced size, cost, and locked focus.
- **HPr Series:** All optics glued in place and a locking C-clamp focus ring. **Stabilized Ruggedization** for reduced pixel shift and improved focus stability.

Technical Information

#33-819, 16mm f/11, HPi Series Fixed Focal Length Lens, Working Distance versus Field of View Plot

#33-819, 16mm f/11, HPi Series Fixed Focal Length Lens, Modulated Transfer Function (MTF) Plot, 500mm Working Distance, f11

#33-819, 16mm f/11, HPi Series Fixed Focal Length Lens, Modulated Transfer Function (MTF) Plot, 500mm Working Distance, f11

#33-819, 16mm f/11, HPi Series Fixed Focal Length Lens, Modulated Transfer Function (MTF) Plot, 500mm Working Distance, f11

#33-819, 16mm f/11, HPi Series Fixed Focal Length Lens, Modulated Transfer Function (MTF) Plot, 1000mm Working Distance, f11

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

Accessories

Note: Compatible accessories for individual stock numbers may vary. If unsure about which accessories work with your products, please contact us [here](#).

	Title	Compare	Stock Number	Price	Buy
MORE+	Filter Adapter M34 x 0.5 from M27.5 x 0.5 (Female)		#11-610	€54,50 Request Quote	7 In Stock <input type="text" value="1"/>

Related Products



#89-820 - Light Red M46.0 x 0.75 High Performance Machine Vision Filter
€302,00

Qty



#89-790 - Green M46.0 x 0.75 High Performance Machine Vision Filter
€302,00

Qty



#89-770 - Blue M46.0 x 0.75 High Performance Machine Vision Filter
€302,00

Qty

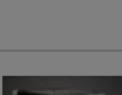
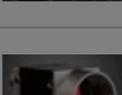
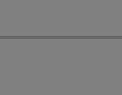
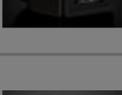


#89-800 - VIS (UV/IR Cut) M46.0 x 0.75 High Performance Machine Vision Filter
€302,00

Qty

Compatible Cameras

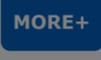
	Title	Type	Compare	Stock Number	Price	Buy
MORE+	LUCID Vision Labs Triton™ TRI120S-MC, Sony IMX304, 12.3MP, Monochrome Camera (Recertified 05-P)	Monochrome Camera		#12-759-RCD-05P RECERTIFIED	€868,00 Request Quote	1 In Stock <input type="text" value="1"/>
MORE+	LUCID Vision Labs Phoenix™ PHX089S-CC, Sony IMX267, 8.9 MP, Color Camera	Color Camera		#11-469	€915,00 Request Quote	CONTACT US <input type="text" value="1"/>
MORE+	LUCID Vision Labs Phoenix™ PHX089S-MC, Sony IMX267, 8.9 MP, Monochrome Camera	Monochrome Camera		#11-468	€915,00 Request Quote	1 In Stock <input type="text" value="1"/>

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 LUCID Vision Labs Triton™ TRI080-CC, Sony IMX304, 8.9MP, Color Camera					4 In Stock <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Triton™ TRI080-MC, Sony IMX304, 8.9MP, Monochrome Camera	Camera			Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Basler ace acA2500-20gm Monochrome GigE Camera	Monochrome Camera		#35-919	€1.050,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Basler ace acA2500-60um Monochrome USB 3.0 Camera	Monochrome Camera		#35-929	€1.050,00 Request Quote	5 In Stock <input type="text" value="1"/> 
MORE+	 M2590, 1" Monochrome, DALSA Genie Nano GigE PoE Camera	Monochrome Camera		#34-964	€1.060,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Phoenix™ PHX120S-CC, Sony IMX304, 12.3 MP, Color Camera	Color Camera		#11-473	€1.070,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Phoenix™ PHX120S-MC, Sony IMX304, 12.3 MP, Monochrome Camera	Monochrome Camera		#11-472	€1.070,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 Basler ace acA2500-20gc Color GigE Camera	Color Camera		#35-920	€1.080,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Basler ace acA2500-60uc Color USB 3.0 Camera	Color Camera		#35-930	€1.080,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Triton™ TRI120S-CC, Sony IMX304, 12.3MP, Color Camera	Color Camera		#12-760	€1.085,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Triton™ TRI120S-MC, Sony IMX304, 12.3MP, Monochrome Camera	Monochrome Camera		#12-759	€1.085,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 C2590-IR, 1" Color, DALSA Genie Nano GigE PoE Camera	Color Camera		#34-965	€1.100,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 IDS U3-3180CP-C-HQ, USB 3.0, 1" Color Camera	Color Camera		#24-083	€1.140,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 IDS U3-3180CP-M-GL, USB 3.0, 1" Monochrome Camera	Monochrome Camera		#24-084	€1.140,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 M2590, 1" NIR, Teledyne DALSA Genie Nano GigE PoE Camera	NIR Camera		#14-677	€1.140,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Triton™ TRI071S-CC, Sony IMX428,	Color Camera		#17-100	€1.265,00 Request Quote	1 In Stock <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

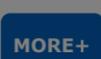
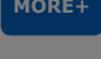
	Title	Type	Compare	Stock Number	Price	Buy
	7.1MP, Color Camera					
MORE+	 LUCID Vision Labs Triton™ TRI0700 MC, Sony IMX542, 7.1MP, Monochrome Camera					1 In Stock <input type="text" value="1"/> 
<div style="border: 1px solid black; padding: 5px; background-color: white;"> <p>Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.</p> <p>Select Your Country/Region:</p> </div>						
MORE+	 LUCID Vision Labs Triton™ TRI0162S-CC, Sony IMX542, 16.2MP, Color Camera	Color Camera		#17-103	€1.325,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Triton™ TRI0162S-MC, Sony IMX542, 16.2MP, Monochrome Camera	Monochrome Camera		#17-102	€1.325,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 Allied Vision Alvim 1800 U-1620m, 1.1" 16.2MP C-Mount, USB 3.0 Monochrome Camera (Recertified 05-P)	Monochrome Camera		#19-599-RCD-05P RECERTIFIED	€1.376,80 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 GS3-U3-41C6C-C 1" FLIR Grasshopper®3 High Performance USB 3.0 Color Camera	Color Camera		#88-514	€1.540,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 GS3-U3-41C6M-C 1" FLIR Grasshopper®3 High Performance USB 3.0 Monochrome Camera	Monochrome Camera		#88-513	€1.540,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 GS3-U3-41C6NIR-C 1" FLIR Grasshopper®3 High Performance USB 3.0 NIR Camera	NIR Camera		#89-526	€1.540,00 Request Quote	3 In Stock <input type="text" value="1"/> 
MORE+	 IDS U3-3290SE-C-HQ, USB 3.0, 1" Color Camera (Recertified 05-P)	Color Camera		#24-134-RCD-05P RECERTIFIED	€1.556,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Allied Vision Alvim 1800 U-1620m, 1.1" 16.2MP C-Mount, Right Angle USB 3.1 Monochrome Camera (Partial Housing)	Monochrome Camera		#19-602	€1.560,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Allied Vision Alvim 1800 U-1620m, 1.1" 16.2MP C-Mount, USB 3.0 Monochrome Camera (Partial Housing)	Monochrome Camera		#19-601	€1.560,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Allied Vision Alvim 1800 U-1620c, 1.1" 16.2MP C-Mount, Right Angle USB 3.1 Color Camera (Partial Housing)	Color Camera		#19-606	€1.570,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Allied Vision Alvim 1800 U-1620c, 1.1" 16.2MP C-Mount, USB 3.0 Color	Color Camera		#19-605	€1.570,00 Request Quote	CONTACT US <input type="text" value="1"/> 

	Title	Type	Compare	Stock Number	Price	Buy
	Camera (Partial Housing)					
	 Allied Vision Alvium 1800 U-1620m, 1.1" 16.2MP C-Mount, Right Angle USB 3.1 Monochrome Camera					CONTACT US 1 
<p>Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.</p> <p>Select Your Country/Region:</p>						
	 Allied Vision Alvium 1800 U-1620m, 1.1" 16.2MP C-Mount, USB 3.0 Monochrome Camera	Monochrome Camera		#19-599	€1.570,00 Request Quote	3 In Stock 1 
	 Allied Vision Alvium 1800 U-1620c, 1.1" 16.2MP C-Mount, Right Angle USB 3.1 Color Camera	Color Camera		#19-604	€1.580,00 Request Quote	1 In Stock 1 
	 Allied Vision Alvium 1800 U-1620c, 1.1" 16.2MP C-Mount, USB 3.0 Color Camera	Color Camera		#19-603	€1.580,00 Request Quote	4 In Stock 1 
	 Allied Vision Alvium G1-1620m, 1.1" 16.2MP C-Mount, GigE PoE Monochrome Camera	Monochrome Camera		#23-567	€1.590,00 Request Quote	CONTACT US 1 
	 Allied Vision Alvium G1-1620c, 1.1" 16.2MP C-Mount, GigE PoE Color Camera	Color Camera		#23-568	€1.600,00 Request Quote	CONTACT US 1 
	 Allied Vision Alvium G1-1236m, 1.1" 12.4MP C-Mount, GigE PoE Monochrome Camera	Monochrome Camera		#23-563	€1.600,00 Request Quote	2 In Stock 1 
	 Allied Vision Alvium G1-1236c, 1.1" 12.4MP C-Mount, GigE PoE Color Camera	Color Camera		#23-564	€1.610,00 Request Quote	2 In Stock 1 
	 BFS-U3-88S6C-C USB 3.1 Blackfly® S, Color Camera	Color Camera		#11-512	€1.635,00 Request Quote	1 In Stock 1 
	 BFS-PGE-88S6C-C PoE GigE Blackfly® S, Color Camera	Color Camera		#11-530	€1.635,00 Request Quote	2 In Stock 1 
	 BFS-U3-88S6M-C USB 3.1 Blackfly® S, Monochrome Camera	Monochrome Camera		#11-511	€1.635,00 Request Quote	1 In Stock 1 
	 BFS-PGE-88S6M-C PoE GigE Blackfly® S, Monochrome Camera	Monochrome Camera		#11-529	€1.635,00 Request Quote	1 In Stock 1 
	 Basler AceacA4096-30um USB 3.0 Monochrome Camera	Monochrome Camera		#37-217	€1.680,00 Request Quote	2 In Stock 1 
	 Basler ace acA4096-11gm Monochrome GigE Camera	Monochrome Camera		#37-209	€1.680,00 Request Quote	CONTACT US 1 

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 LUCID Vision Labs Triton™ TRI020-CC, Sony IMX20.4MP, Color Camera					CONTACT US 1 
MORE+	 LUCID Vision Labs Triton™ TRI020-MC, Sony IMX20.4MP, Monochrome Camera	Camera		#17-104	Request Quote	CONTACT US 1 
MORE+	 Basler Ace acA4096-30uc USB 3.0 Color Camera	Color Camera		#37-218	€1.700,00 Request Quote	CONTACT US 1 
MORE+	 Basler ace acA4096-11gc Color GigE Camera	Color Camera		#37-210	€1.700,00 Request Quote	1 In Stock 1 
MORE+	 Pixelink PL-D726MU-BL, 1" 6.6MP, Board Level USB 3.0 Monochrome Camera	Monochrome Camera		#89-402 CLEARANCE	€1.725,00 Request Quote	CONTACT US 1 
MORE+	 Basler ace2 a2A5320-23umBAS Monochrome USB3 Basic Camera	Monochrome Camera		#16-625	€1.725,00 Request Quote	1 In Stock 1 
MORE+	 Basler ace2 a2A5320-7gmBAS Monochrome GigE Basic Camera	Monochrome Camera		#16-601	€1.725,00 Request Quote	1 In Stock 1 
MORE+	 Basler ace2 a2A5320-23ucBAS Color USB3 Basic Camera	Color Camera		#16-626	€1.745,00 Request Quote	1 In Stock 1 
MORE+	 Basler ace2 a2A5320-7gcBAS Color GigE Basic Camera	Color Camera		#16-602	€1.745,00 Request Quote	CONTACT US 1 
MORE+	 Pixelink PL-D734MU-T, 1" 4.2MP, C-Mount USB 3.0 Monochrome Camera (Recertified 05-P)	Monochrome Camera		#33-342-RCD-05P RECERTIFIED	€1.760,00 Request Quote	2 In Stock 1 
MORE+	 Basler ace acA2040-90um Monochrome USB 3.0 Camera	Monochrome Camera		#89-989	€1.790,00 Request Quote	2 In Stock 1 
MORE+	 Basler ace acA2040-90uc Color USB 3.0 Camera	Color Camera		#89-990	€1.830,00 Request Quote	CONTACT US 1 
MORE+	 LUCID Vision Labs Atlas™ ATL071S-CC, Sony IMX420, 7.1MP, Color Camera (Recertified 05-P)	Color Camera		#17-111-RCD-05P RECERTIFIED	€1.836,00 Request Quote	1 In Stock 1 
MORE+	 Allied Vision Mako G-419B 1" Monochrome CMOS Camera (Recertified 05-P)	Monochrome Camera		#88-472-RCD-05P RECERTIFIED	€1.870,00 Request Quote	1 In Stock 1 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
	 Allied Vision Alvium 1800 U-1236m 1.1\" data-bbox="201 44 311 108"/> 1.1\" 12.4MP C-Mount, USB 3.0 Monochrome Camera					2 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium G5-1620c, 1.1\" data-bbox="201 121 311 185"/> 16.2MP C-Mount, 5GigE PoE Color Camera (Recertified 05-P)	Color Camera		#23-636-RCD-05P RECERTIFIED	€1.888,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-1236c, 1.1\" data-bbox="201 198 311 252"/> 12.4MP C-Mount, USB 3.0 Color Camera	Color Camera		#14-890	€1.890,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-1236c, 1.1\" data-bbox="201 265 311 319"/> 12.4MP C-Mount, Right Angle USB 3.1 Color Camera	Color Camera		#14-892	€1.890,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Basler ace2 a2A5320-23umPRO Monochrome USB3 Pro Camera	Monochrome Camera		#16-637	€1.890,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Basler ace2 a2A5320-7gmPRO Monochrome GigE Pro Camera	Monochrome Camera		#16-613	€1.890,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Pixelink M-Series M4C-CYL Microscopy Color Camera	Color Microscopy Camera		#17-819	€1.895,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Basler ace2 a2A5320-23ucPRO Color USB3 Pro Camera	Color Camera		#16-638	€1.925,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Basler ace2 a2A5320-7gcPRO Color GigE Pro Camera	Color Camera		#16-614	€1.925,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 IDS U3-3290SE-C-HQ, USB 3.0, 1\" data-bbox="201 615 311 649"/> Color Camera	Color Camera		#24-134	€1.945,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 IDS U3-3290SE-M-GL, USB 3.0, 1\" data-bbox="201 668 311 702"/> Monochrome Camera	Monochrome Camera		#24-135	€1.945,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-1236C Color CMOS PoE Camera	Color Camera		#37-515 CLEARANCE	€1.953,95 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Manta G-895 1\" data-bbox="201 774 311 808"/> Color CMOS Camera	Color Camera		#36-179	€1.960,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-895 1\" data-bbox="201 827 311 861"/> Monochrome CMOS Camera	Monochrome Camera		#36-178	€1.960,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium G1-2040m, 1.1\" data-bbox="201 880 311 934"/> 20.4MP C-Mount, GigE PoE Monochrome Camera	Monochrome Camera		#23-571	€1.960,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-1236m, 1.1\" data-bbox="201 953 311 997"/> 12.4MP C-Mount, Right Angle	Monochrome Camera		#14-891	€1.965,00 Request Quote	CONTACT US <input type="text" value="1"/> 

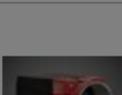
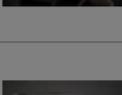
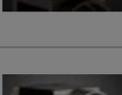
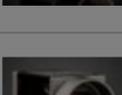
Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
	USB 3.1 Monochrome Camera					
	 Allied Vision A G1-2040c, 1.1" 20.4MP C-Mount, Right Angle USB 3.1 GigE PoE Color Camera					CONTACT US <input type="text" value="1"/> 
	 Allied Vision Mako G-419B 1" Monochrome CMOS Camera	Monochrome Camera		#88-472	€1.980,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040m, 1.1" 20.4MP C-Mount, Right Angle USB 3.1 Monochrome Camera (Partial Housing)	Monochrome Camera		#19-610	€1.990,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040m, 1.1" 20.4MP C-Mount, USB 3.0 Monochrome Camera (Partial Housing)	Monochrome Camera		#19-609	€1.990,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Mako G-419C 1" Color CMOS Camera	Color Camera		#88-473	€2.000,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040c, 1.1" 20.4MP C-Mount, Right Angle USB 3.1 Color Camera (Partial Housing)	Color Camera		#19-614	€2.000,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040c, 1.1" 20.4MP C-Mount, USB 3.0 Color Camera (Partial Housing)	Color Camera		#19-613	€2.000,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040m, 1.1" 20.4MP C-Mount, Right Angle USB 3.1 Monochrome Camera	Monochrome Camera		#19-608	€2.000,00 Request Quote	2 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040m, 1.1" 20.4MP C-Mount, USB 3.0 Monochrome Camera	Monochrome Camera		#19-607	€2.000,00 Request Quote	9 In Stock <input type="text" value="1"/> 
	 BFS-U3-122S6C-C USB 3.1 Blackfly® S, Color Camera	Color Camera		#11-518	€2.020,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-895C Color CMOS PoE Camera	Color Camera		#35-899	€2.020,00 Request Quote	2 In Stock <input type="text" value="1"/> 
	 BFS-PGE-122S6C-C PoE GigE Blackfly® S, Color Camera	Color Camera		#11-532	€2.020,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium 1800 U-2040c, 1.1" 20.4MP C-Mount, USB 3.0 Color Camera	Color Camera		#19-611	€2.020,00 Request Quote	5 In Stock <input type="text" value="1"/> 

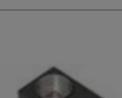
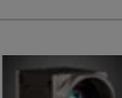
Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
	 Allied Vision Alvium 1800 U-2040c 20.4MP C-Mount, Right Angle USB 3.1 Color Camera					2 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-419 1" Monochrome CMOS Camera				Quote	CONTACT US <input type="text" value="1"/> 
	 BFS-U3-122S6M-C USB 3.1 Blackfly® S, Monochrome Camera	Monochrome Camera		#11-517	€2.020,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-895B Monochrome CMOS PoE Camera	Monochrome Camera		#35-898	€2.020,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 BFS-PGE-122S6M-C PoE GigE Blackfly® S, Monochrome Camera	Monochrome Camera		#11-531	€2.020,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-1620C Color CMOS PoE Camera	Color Camera		#17-092	€2.030,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-1620B Monochrome CMOS PoE Camera	Monochrome Camera		#17-091	€2.030,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Allied Vision Alvium G5-1620m, 1.1" 16.2MP C-Mount, 5GigE PoE Monochrome Camera	Monochrome Camera		#23-635	€2.040,00 Request Quote	5 In Stock <input type="text" value="1"/> 
	 Allied Vision Alvium G5-1620c, 1.1" 16.2MP C-Mount, 5GigE PoE Color Camera	Color Camera		#23-636	€2.050,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Basler Ace acA4112-20um USB 3.0 Monochrome Camera	Monochrome Camera		#37-221	€2.060,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Basler ace acA4112-8gm Monochrome GigE Camera	Monochrome Camera		#37-211	€2.060,00 Request Quote	CONTACT US <input type="text" value="1"/> 
	 Basler Ace acA4112-20uc USB 3.0 Color Camera	Color Camera		#37-222	€2.080,00 Request Quote	8 In Stock <input type="text" value="1"/> 
	 Basler ace acA4112-8gc Color GigE Camera	Color Camera		#37-212	€2.080,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-419C Color CMOS PoE Camera	Color Camera		#13-941	€2.080,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Manta G-419B Monochrome CMOS PoE Camera	Monochrome Camera		#13-940	€2.080,00 Request Quote	1 In Stock <input type="text" value="1"/> 
	 Allied Vision Mako G-419B 1" NIR CMOS Camera	NIR Camera		#88-474	€2.090,00 Request Quote	2 In Stock <input type="text" value="1"/> 
	 Basler ace acA2040-90um NIR USB 3.0 Camera	NIR Camera		#34-176	€2.120,00 Request Quote	CONTACT US <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 BFS-U3-70S7C-C USB 3.1 Blackfly® S, Color Camera (Recertified 0				€2.125,00	1 In Stock <input type="text" value="1"/> 
MORE+	 Allied Vision M G-419 1" NIR Camera					CONTACT US <input type="text" value="1"/> 
MORE+	 BFS-U3-70S7C-C USB 3.1 Blackfly® S, Color Camera	Color Camera		#13-927	€2.150,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 BFS-PGE-70S7C-C PoE GigE Blackfly® S, Color Camera	Color Camera		#13-923	€2.150,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 BFS-U3-70S7M-C USB 3.1 Blackfly® S, Monochrome Camera	Monochrome Camera		#13-926	€2.150,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 BFS-PGE-70S7M-C PoE GigE Blackfly® S, Monochrome Camera	Monochrome Camera		#13-922	€2.150,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Pixelink PL- D734CU-T, 1" 4.2MP, C-Mount USB 3.0 Color Camera	Color Camera		#33-343	€2.160,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL- D797CU-BL, 1.1" 7.1MP, Board Level USB 3.0 Color Camera	Color Camera		#14-170	€2.160,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Pixelink PL- D734MU-T, 1" 4.2MP, C-Mount USB 3.0 Monochrome Camera	Monochrome Camera		#33-342	€2.160,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL- D797MU-BL, 1.1" 7.1MP, Board Level USB 3.0 Monochrome Camera	Monochrome Camera		#14-169	€2.160,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Basler ace2 a2A4504-18umBAS Monochrome USB3 Basic Camera	Monochrome Camera		#16-623	€2.170,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 Basler ace2 a2A4504-5gmBAS Monochrome GigE Basic Camera	Monochrome Camera		#16-599	€2.170,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Basler ace2 a2A4504-18ucBAS Color USB3 Basic Camera	Color Camera		#16-624	€2.205,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Basler ace2 a2A4504-5gcBAS Color GigE Basic Camera	Color Camera		#16-600	€2.205,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Basler ace acA2040-25gm Monochrome GigE Camera	Monochrome Camera		#87-104	€2.230,00 Request Quote	4 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL- D797CU-T, 1.1" 7.1MP, C-Mount USB 3.0 Color Camera	Color Camera		#14-168	€2.265,00 Request Quote	CONTACT US <input type="text" value="1"/> 

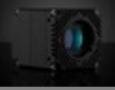
Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 LUCID Vision Labs Atlas™ ATLO71S-CC, Sony IMX420, 7.1MP, Color Camera					CONTACT US 1 
MORE+	 Pixelink PL-D797MU-T, 1.1" 7.1MP, C-Mount USB 3.0 Monochrome Camera	Camera		#14-167	Request Quote	CONTACT US 1 
MORE+	 LUCID Vision Labs Atlas™ ATLO71S-MC, Sony IMX420, 7.1MP, Monochrome Camera	Monochrome Camera		#17-110	€2.265,00 Request Quote	1 In Stock 1 
MORE+	 Basler ace acA2040-25gc Color GigE Camera	Color Camera		#87-105	€2.270,00 Request Quote	1 In Stock 1 
MORE+	 Pixelink M-Series M4M-CYL Microscopy Monochrome Camera	Monochrome Microscopy Camera		#17-820	€2.375,00 Request Quote	CONTACT US 1 
MORE+	 Basler ace2 a2A4504-18umPRO Monochrome USB3 Pro Camera	Monochrome Camera		#16-635	€2.405,00 Request Quote	1 In Stock 1 
MORE+	 Basler ace2 a2A4504-5gmPRO Monochrome GigE Pro Camera	Monochrome Camera		#16-611	€2.405,00 Request Quote	CONTACT US 1 
MORE+	 IDS U3-3200SE-C-HQ, USB 3.0, 1.1" Color Camera	Color Camera		#24-132	€2.415,00 Request Quote	1 In Stock 1 
MORE+	 IDS U3-3200SE-M-GL, USB 3.0, 1.1" Monochrome Camera	Monochrome Camera		#24-133	€2.415,00 Request Quote	1 In Stock 1 
MORE+	 Basler ace2 a2A4504-18ucPRO Color USB3 Pro Camera	Color Camera		#16-636	€2.430,00 Request Quote	CONTACT US 1 
MORE+	 Basler ace2 a2A4504-5gcPRO Color GigE Pro Camera	Color Camera		#16-612	€2.430,00 Request Quote	CONTACT US 1 
MORE+	 M4020, 1.1" Monochrome, DALSA Genie Nano GigE PoE Camera	Monochrome Camera		#35-911	€2.435,00 Request Quote	CONTACT US 1 
MORE+	 C4020-IR, 1.1" Color, DALSA Genie Nano GigE PoE Camera	Color Camera		#35-912	€2.455,00 Request Quote	3 In Stock 1 
MORE+	 Allied Vision Manta G-2040B Monochrome CMOS PoE Camera	Monochrome Camera		#17-093	€2.470,00 Request Quote	CONTACT US 1 
MORE+	 Pixelink PL-D799CU-T, 1" 9.0MP, C-Mount USB 3.0 Color Camera	Color Camera		#38-008	€2.480,00 Request Quote	1 In Stock 1 
MORE+	 Pixelink PL-D799MU-T, 1" 9.0MP, C-Mount USB 3.0	Monochrome Camera		#38-007	€2.480,00 Request Quote	1 In Stock 1 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
	Monochrome Camera					
	 Allied Vision Manta G-1236 1.1" CMOS Camera					CONTACT US 1 
<p>Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.</p> <p>Select Your Country/Region:</p>						
	 Allied Vision Manta G-1236 1.1" Monochrome CMOS Camera	Camera		#36-180	Request Quote	1 In Stock 1 
	 IDS U3-3990SE-C-HQ, USB 3.0, 1.1" Color Camera	Color Camera		#24-140	€2.505,00 Request Quote	3 In Stock 1 
	 IDS U3-3990SE-M-GL, USB 3.0, 1.1" Monochrome Camera	Monochrome Camera		#24-141	€2.505,00 Request Quote	2 In Stock 1 
	 Basler ace acA2040-25gm-NIR GigE Camera	NIR Camera		#87-106	€2.530,00 Request Quote	CONTACT US 1 
	 Allied Vision Manta G-1236B Monochrome CMOS PoE Camera	Monochrome Camera		#37-514	€2.560,00 Request Quote	5 In Stock 1 
	 LUCID Vision Labs Atlas™ ATL089S-CC, Sony IMX255, 8.9MP, Color Camera	Color Camera		#13-736	€2.570,00 Request Quote	CONTACT US 1 
	 LUCID Vision Labs Atlas™ ATL089S-MC, Sony IMX255, 8.9MP, Monochrome Camera	Monochrome Camera		#13-735	€2.570,00 Request Quote	CONTACT US 1 
	 Pixelink PL-D757CU-BL, 1.1" 7.1MP, Board Level USB 3.0 Color Camera	Color Camera		#14-166	€2.700,00 Request Quote	CONTACT US 1 
	 Pixelink PL-D757MU-BL, 1.1" 7.1MP, Board Level USB 3.0 Monochrome Camera	Monochrome Camera		#14-165	€2.700,00 Request Quote	CONTACT US 1 
	 Pixelink M-Series M9C-CYL Microscopy Color Camera	Color Microscopy Camera		#17-825	€2.705,00 Request Quote	CONTACT US 1 
	 Pixelink M-Series M9M-CYL Microscopy Monochrome Camera	Monochrome Microscopy Camera		#17-826	€2.705,00 Request Quote	CONTACT US 1 
	 Allied Vision Prosilica GT2050 1" Color CMOS Camera	Color Camera		#87-082	€2.810,00 Request Quote	CONTACT US 1 
	 Pixelink PL-D757CU-T, 1.1" 7.1MP, C-Mount USB 3.0 Color Camera	Color Camera		#14-164	€2.810,00 Request Quote	CONTACT US 1 
	 Allied Vision Prosilica GT2050 1" Monochrome CMOS Camera	Monochrome Camera		#87-081	€2.810,00 Request Quote	CONTACT US 1 

	Title	Type	Compare	Stock Number	Price	Buy
MORE+ 	Pixelink PL-D757MU-T, 1.1" 7.1MP, C-Mount USB 3.0 Monochrome Camera					CONTACT US 1 
MORE+ 	LUCID Vision Labs Atlas™ ATL120S-CC, Sony IMX253, 12.3MP, Color Camera	Color Camera		#13-734	Request Quote	1 In Stock 1 
MORE+ 	LUCID Vision Labs Atlas™ ATL120S-MC, Sony IMX253, 12.3MP, Monochrome Camera	Monochrome Camera		#13-733	€2.880,00 Request Quote	CONTACT US 1 
MORE+ 	Pixelink PL-D7912CU-T, 1.1" 12MP, C-Mount USB 3.0 Color Camera	Color Camera		#38-010	€2.915,00 Request Quote	1 In Stock 1 
MORE+ 	Pixelink PL-D7912MU-T, 1.1" 12MP, C-Mount USB 3.0 Monochrome Camera	Monochrome Camera		#38-009	€2.915,00 Request Quote	1 In Stock 1 
MORE+ 	BFS-U3-89S6C-C USB 3.1 Blackfly® S, Color Camera	Color Camera		#11-514	€2.930,00 Request Quote	2 In Stock 1 
MORE+ 	BFS-U3-89S6M-C USB 3.1 Blackfly® S, Monochrome Camera	Monochrome Camera		#11-513	€2.930,00 Request Quote	1 In Stock 1 
MORE+ 	M4060, 1" Monochrome, Teledyne DALSA Genie Nano 5GigE PoE Camera	Monochrome Camera		#16-030	€2.975,00 Request Quote	1 In Stock 1 
MORE+ 	C4060-IR, 1" Color, Teledyne DALSA Genie Nano 5GigE PoE Camera	Color Camera		#16-031	€2.990,00 Request Quote	13 In Stock 1 
MORE+ 	Basler Ace acA4096-40uc USB 3.0 Color Camera	Color Camera		#37-220	€3.130,00 Request Quote	1 In Stock 1 
MORE+ 	Pixelink PL-D759CU-BL, 1" 8.9MP, Board Level USB 3.0 Color Camera	Color Camera		#11-443	€3.130,00 Request Quote	CONTACT US 1 
MORE+ 	Pixelink M-Series M12BC-CYL Microscopy Color Camera	Color Microscopy Camera		#17-809	€3.130,00 Request Quote	1 In Stock 1 
MORE+ 	Pixelink PL-D759MU-BL, 1" 8.9MP, Board Level USB 3.0 Monochrome Camera	Monochrome Camera		#11-442	€3.130,00 Request Quote	CONTACT US 1 
MORE+ 	Pixelink M-Series M12BM-CYL Microscopy Monochrome Camera	Monochrome Microscopy Camera		#17-810	€3.130,00 Request Quote	1 In Stock 1 
MORE+ 	Oryx® ORX-10G-71S7C-C Color 10GigE	Color Camera		#20-251	€3.140,00 Request Quote	1 In Stock 1 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 Oryx® ORX-10G-71S7M-C Monochrome 10GigE	Monochrome			€3.140,00	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL-D759CU-T, 1" 8.9MP, C-Mount USB 3.0 Color Camera					CONTACT US <input type="text" value="1"/> 
MORE+	 Pixelink PL-D759MU-T, 1" 8.9MP, C-Mount USB 3.0 Monochrome Camera	Monochrome Camera		#11-440	€3.240,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 BFS-U3-123S6C-C USB 3.1 Blackfly® S, Color Camera	Color Camera		#11-520	€3.270,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 BFS-U3-123S6M-C USB 3.1 Blackfly® S, Monochrome Camera	Monochrome Camera		#11-519	€3.270,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 M4040, 1.1" Monochrome, Teledyne DALSA Genie Nano GigE PoE Camera	Monochrome Camera		#14-697	€3.315,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 C4040-IR, 1.1" Color, Teledyne DALSA Genie Nano GigE PoE Camera	Color Camera		#14-698	€3.335,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Atlas10 ATX162S-CC, Sony IMX532, 16.2MP, Color Camera	Color Camera		#17-119	€3.350,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Atlas10 ATX162S-MC, Sony IMX532, 16.2MP, Monochrome Camera	Monochrome Camera		#17-118	€3.350,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 GS3-U3-89S6C-C 1" FLIR Grasshopper®3 High Performance USB 3.0 Color Camera	Color Camera		#36-338	€3.395,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+	 GS3-U3-89S6M-C 1" FLIR Grasshopper®3 High Performance USB 3.0 Monochrome Camera	Monochrome Camera		#36-337	€3.395,00 Request Quote	4 In Stock <input type="text" value="1"/> 
MORE+	 M4040, 1.1" Monochrome, Teledyne DALSA Genie Nano 5GigE PoE Camera	Monochrome Camera		#16-028	€3.430,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 C4040-IR, 1.1" Color, Teledyne DALSA Genie Nano 5GigE PoE Camera	Color Camera		#16-029	€3.450,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 GS3-U3-123S6C-C 1.1" FLIR Grasshopper®3 High Performance USB 3.0 Color Camera (Recertified 05-P)	Color Camera		#36-340-RCD-05P RECERTIFIED	€3.470,00 Request Quote	1 In Stock <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
MORE+	 Basler Ace acA4112-30um 3.0 Monochrome Camera				€3.510,00	1 In Stock <input type="text" value="1"/> 
MORE+	 Basler Ace acA4112-30um 3.0 Color Camera					1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL-D7512CU-BL, 1.1" 12.3MP, Board Level USB 3.0 Color Camera	Color Camera		#11-447	€3.560,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Pixelink PL-D7512MU-BL, 1.1" 12.3MP, Board Level USB 3.0 Monochrome Camera	Monochrome Camera		#11-446	€3.560,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 GS3-U3-123S6C-C 1.1" FLIR Grasshopper®3 High Performance USB 3.0 Color Camera	Color Camera		#36-340	€3.635,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 GS3-U3-123S6M-C 1.1" FLIR Grasshopper®3 High Performance USB 3.0 Monochrome Camera	Monochrome Camera		#36-339	€3.635,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL-D7512CU-T, 1.1" 12.3MP, C-Mount USB 3.0 Color Camera	Color Camera		#11-445	€3.670,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink PL-D7512MU-T, 1.1" 12.3MP, C-Mount USB 3.0 Monochrome Camera	Monochrome Camera		#11-444	€3.670,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink M-Series M12C-CYL Microscopy Color Camera	Color Microscopy Camera		#17-811	€3.780,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Pixelink M-Series M12M-CYL Microscopy Monochrome Camera	Monochrome Microscopy Camera		#17-812	€3.780,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Atlas10 ATX204S-CC, Sony IMX531, 20.4MP, Color Camera	Color Camera		#17-117	€4.015,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 LUCID Vision Labs Atlas10 ATX204S-MC, Sony IMX531, 20.4MP, Monochrome Camera	Monochrome Camera		#17-116	€4.015,00 Request Quote	CONTACT US <input type="text" value="1"/> 
MORE+	 Oryx® ORX-10GS-89S6C-C Color 10GigE	Color Camera		#19-793	€4.310,00 Request Quote	1 In Stock <input type="text" value="1"/> 
MORE+	 Oryx® ORX-10GS-89S6M-C Mono 10GigE	Monochrome Camera		#19-792	€4.310,00 Request Quote	1 In Stock <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

	Title	Type	Compare	Stock Number	Price	Buy
MORE+ 	Oryx® ORX-10GS-89S6M-C Mono 10GigE (Receiver 05-P)				€4.495,00	1 In Stock <input type="text" value="1"/> 
MORE+ 	BFS-PGE-123 Pol. PoE GigE Blackfly® S, Monochrome Camera				Quote	2 In Stock <input type="text" value="1"/> 
MORE+ 	Oryx® ORX-10GS-123S6C-C Color 10GigE	Color Camera		#19-799	€4.665,00 Request Quote	2 In Stock <input type="text" value="1"/> 
MORE+ 	Oryx® ORX-10GS-123S6M-C Mono 10GigE	Monochrome Camera		#19-798	€4.665,00 Request Quote	1 In Stock <input type="text" value="1"/> 

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

Resources

Media Type

- Application Note
- Video
- Trending in Optics
- Published Article
- FAQ
- Glossary
- Technical Tool

APPLICATION NOTE

Anti-Reflection (AR) Coatings

APPLICATION NOTE

An Introduction to Optical Coatings

VIDEO

Wavelength and f#

APPLICATION NOTE

Understanding Focal Length and Field of View

APPLICATION NOTE

Introduction to Modulation Transfer Function

VIDEO

LIGHT TALK - EPISODE 5: Ruggedized Imaging

[View More](#)