


## 20mm Dia x 80mm Focal Length, Spherical Mirror

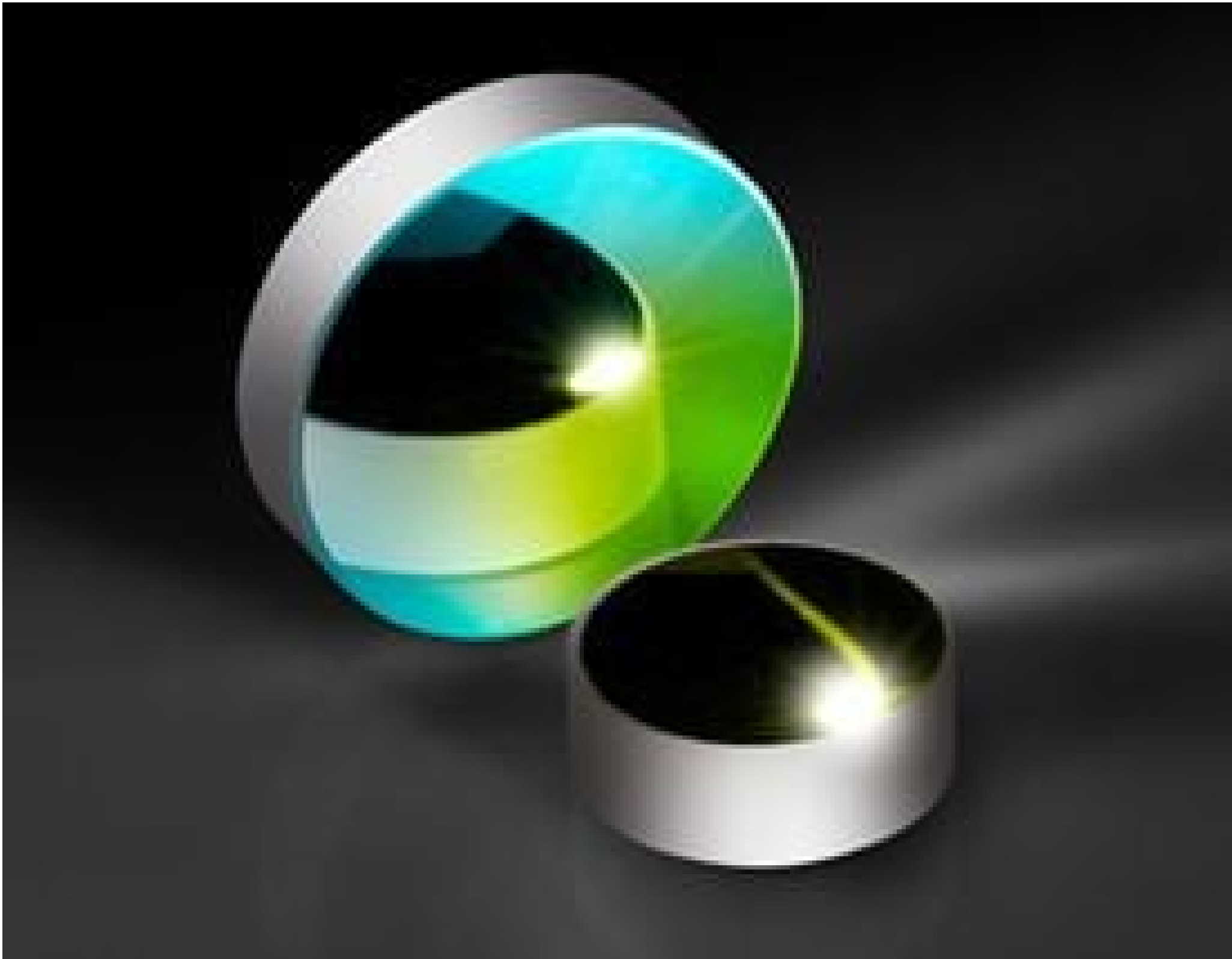

Stock **#46-239** 3-4 DAYS

- 1 + **€46,50**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-49                      |
| €46,50                        |
| Qty 50+                       |
| €42,00                        |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate: ☐  
[N-BK7](#)

Focal Length Tolerance (%):  
±2

Surface Quality:  
60-40

Surface Accuracy:

|                                                                                                              |
|--------------------------------------------------------------------------------------------------------------|
| N/4                                                                                                          |
| <b>Diameter (mm):</b><br>20.00 +0.00/-0.30                                                                   |
| <b>Effective Focal Length EFL (mm):</b><br>80.00                                                             |
| <b>Radius of Curvature (mm):</b><br>160.00                                                                   |
| <b>Aperture (f/#):</b><br>f/4                                                                                |
| <b>Coating:</b><br>Protected Aluminum (400-2000nm)                                                           |
| <b>Coating Specification:</b><br>R <sub>avg</sub> >85% @ 400 - 700nm<br>R <sub>avg</sub> >90% @ 400 - 2000nm |
| <b>Coating Type:</b><br>Metal                                                                                |
| <b>Back Surface:</b><br>Ground                                                                               |
| <b>Center Thickness CT (mm):</b><br>3.00                                                                     |
| <b>Center Thickness Tolerance (mm):</b><br>±0.30                                                             |
| <b>Edge Thickness ET (mm):</b><br>3.31                                                                       |
| <b>Edges:</b><br>Ground                                                                                      |
| <b>Radius R (mm):</b><br>160.0                                                                               |
| <b>Type:</b><br>Spherical Mirror                                                                             |
| <b>Wavelength Range (nm):</b><br>400 - 2000                                                                  |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 235:</b><br><a href="#">Compliant</a>             |