


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

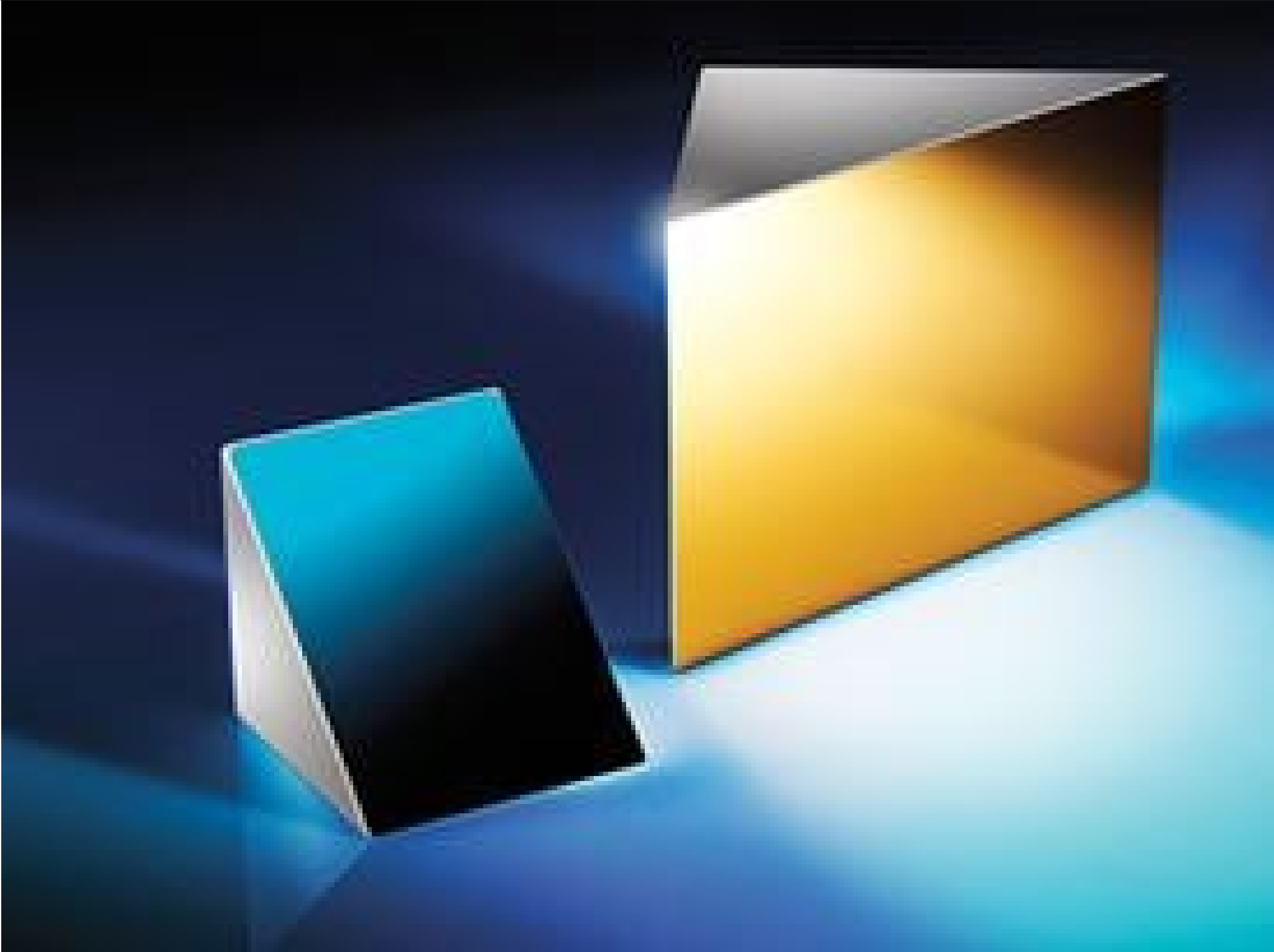

Stock #24-181

CONTACT US



1



€105,00

ADD TO CART

Qty 1-5

€105,00

Qty 6+

€84,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Substrate: [N-BK7](#)

Surface Quality:
60-40

Length of Legs (mm):
20.00

Dimensional Tolerance (mm): ±0.1
Coating Specification: R _{avg} >85% @ 250 - 700nm R _{avg} >89% @ 250 - 450nm
Coating: Enhanced Aluminum (250-700nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 25.45 x 18.00
Length of Hypotenuse (mm): 28.30
Type: Right Angle Mirror
Wavelength Range (µm): 0.25 - 0.7
Wavelength Range (nm): 250 - 700
Damage Threshold, Reference: ☐ 0.5 J/cm² @ 355nm, 10ns
Power (fringes) @ 632.8nm: 1.25
Irregularity (fringes) @ 632.8nm: 0.50

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant