 



In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

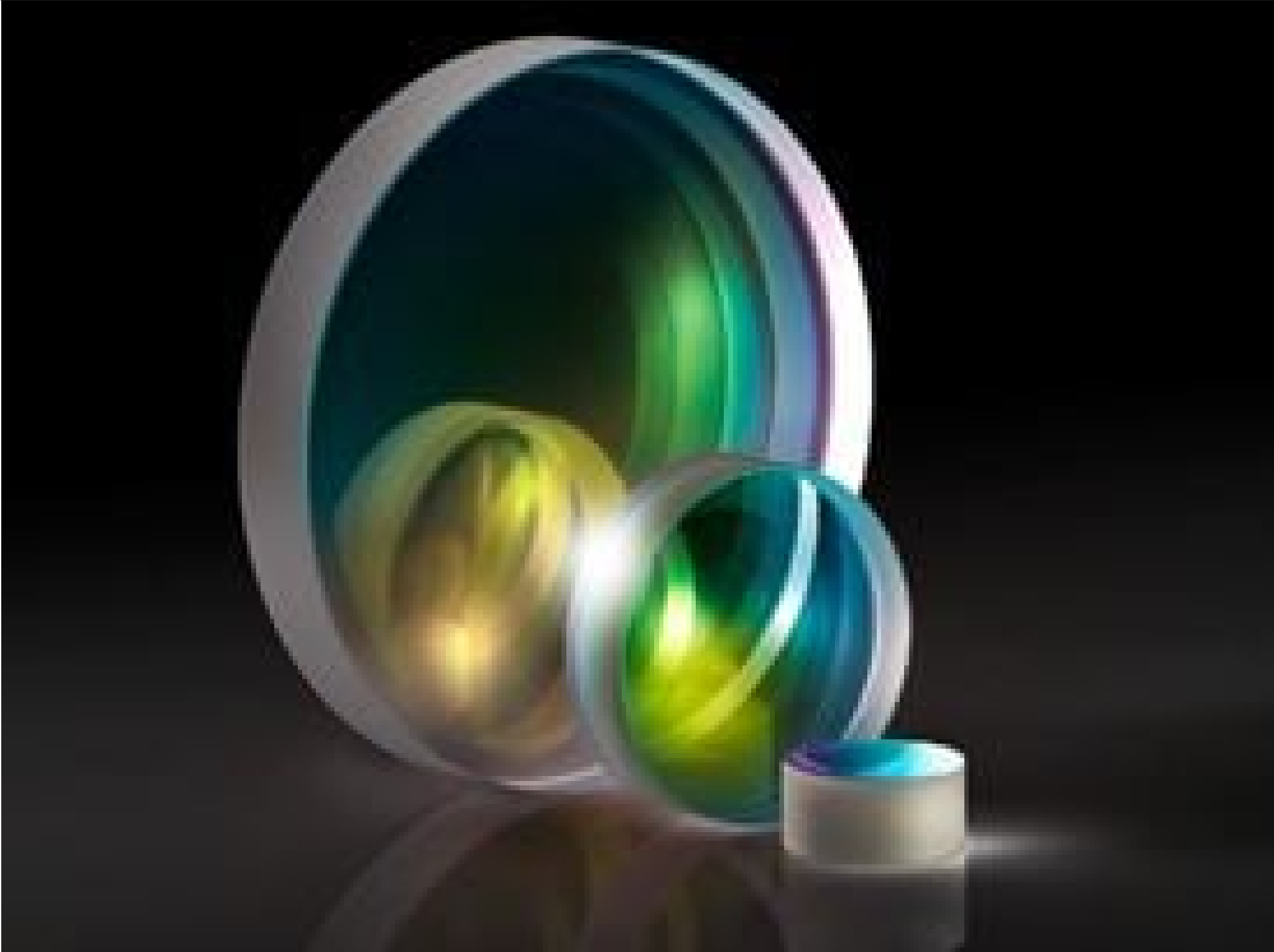

Stock #21-040 3-4 DAYS



1



€149,00

ADD TO CART

Qty 1-5

€149,00

Qty 6+

€119,25

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.00 +0.0/-0.025

Effective Focal Length EFL (mm):
-150.00

Substrate: Fused Silica (Coming 7980)
f#: 6.00
Numerical Aperture NA: 0.08
Coating: 1064nm V-Coat
Type: Plano-Concave Lens
Back Focal Length BFL (mm): -151.71
Center Thickness CT (mm): 2.50
Center Thickness Tolerance (mm): ±0.10
Centering (arcmin): <1
Clear Aperture CA (mm): 24
Coating Specification: R_{abs} <0.25% @ 1064nm
Design Wavelength DWL (nm): 1064
Edge Thickness ET (mm): 3.59
Focal Length Specification Wavelength (nm): 587.6
Focal Length Tolerance (%): ±1
Note: Max. Flat Annulus is 0.3mm
Radius R₁ (mm): -68.76
Surface Quality: 40-20
Damage Threshold, By Design: 15 J/cm² @ 1064nm, 10ns
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant