


25.4mm Dia. 532nm 45°, Low Cost Laser Line Mirror

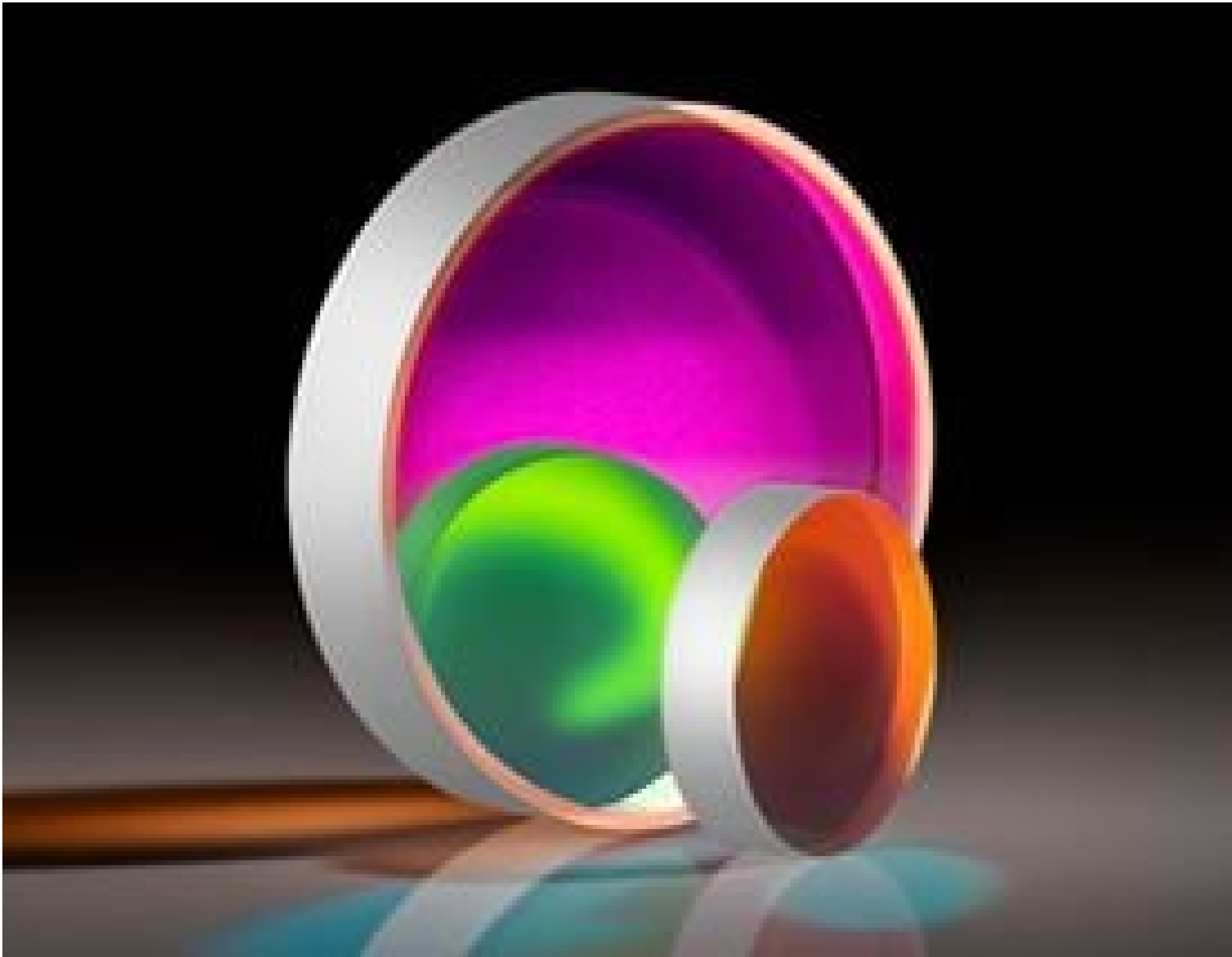

Stock #11-073 3-4 DAYS

⊖ 1 ⊕

€118,00

ADD TO CART

Qty 1-10
€118,00
Qty 11+
€105,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%) : 90
Durability : ML-C-675C
Back Surface : Commercial Polish
Reflection at DWL (%) : 99
Coating Specification : Rabs >99% @532nm
Surface Flatness (P-V) : λ/10
Coating Type : Dielectric
Coating : Laser Mirror (532nm)
Design Wavelength DWL (nm) : 532
Diameter (mm) : 25.40 +0.0/-0.1
Thickness (mm) : 6.35 ±0.2
Angle of Incidence (°) : 45
Substrate : ☐ N-BK7
Damage Threshold, By Design : ☐ 3 J/cm² @532nm, 20ns, 20Hz

Regulatory Compliance

RoHS 2015 : Compliant
Reach 223 : Compliant
Certificate of Conformance : View