


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

25.4mm Dia. 980nm 0°, Low Cost Laser Line Mirror

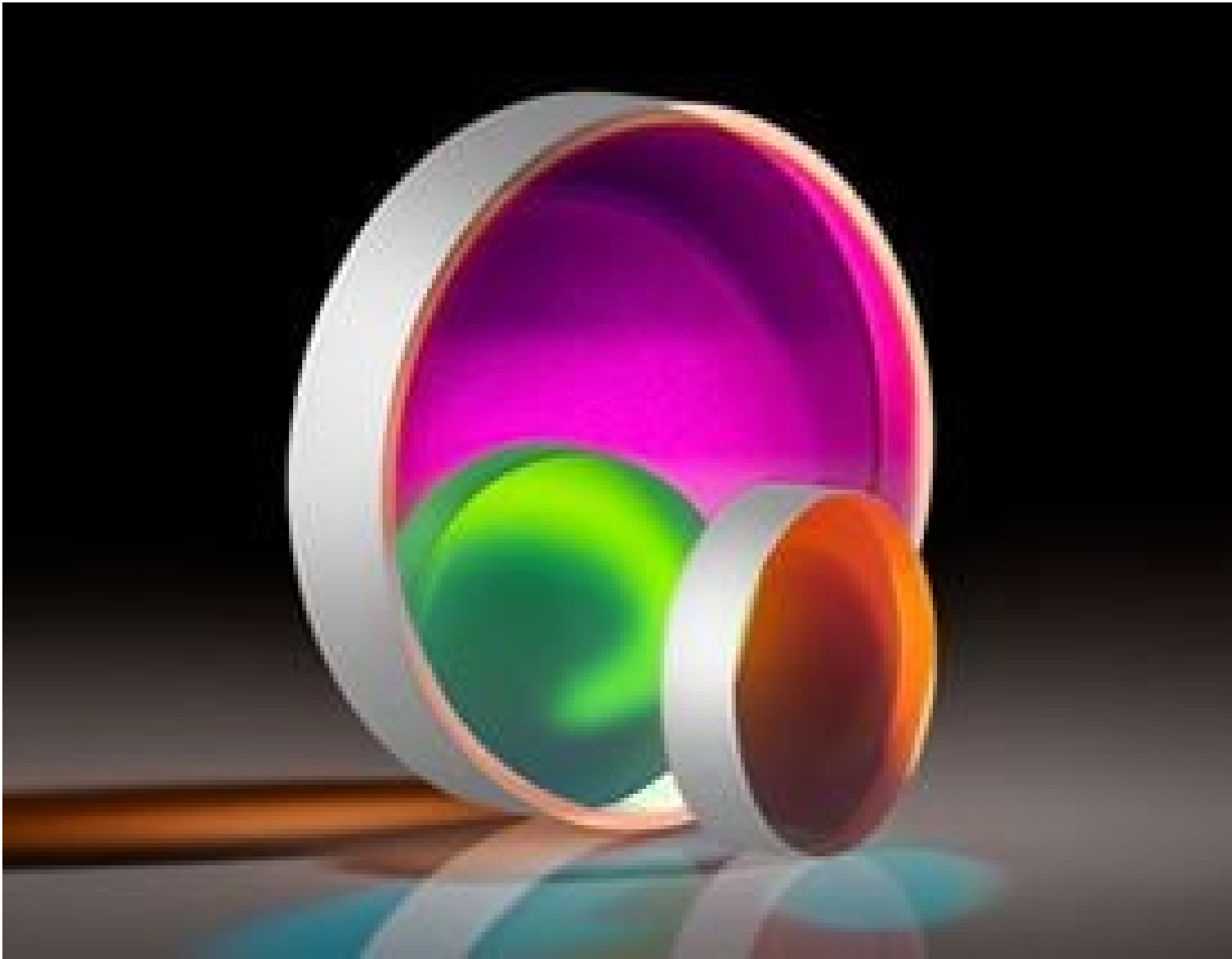

Stock #11-102 3-4 DAYS



1



€118,00

ADD TO CART

Qty 1-10

€118,00

Qty 11+

€105,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%): 90
Durability: ML-C-675C
Back Surface: Commercial Polish
Reflection at DWL (%): 99
Coating Specification: Rabs >99% @ 980nm
Surface Flatness (P-V): λ/10
Coating Type: Dielectric
Coating: Laser Mirror (980nm)
Design Wavelength DWL (nm): 980
Diameter (mm): 25.40 +0.0/-0.1
Thickness (mm): 6.35 ±0.2
Angle of Incidence (°): 0
Substrate: N-BK7

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View